
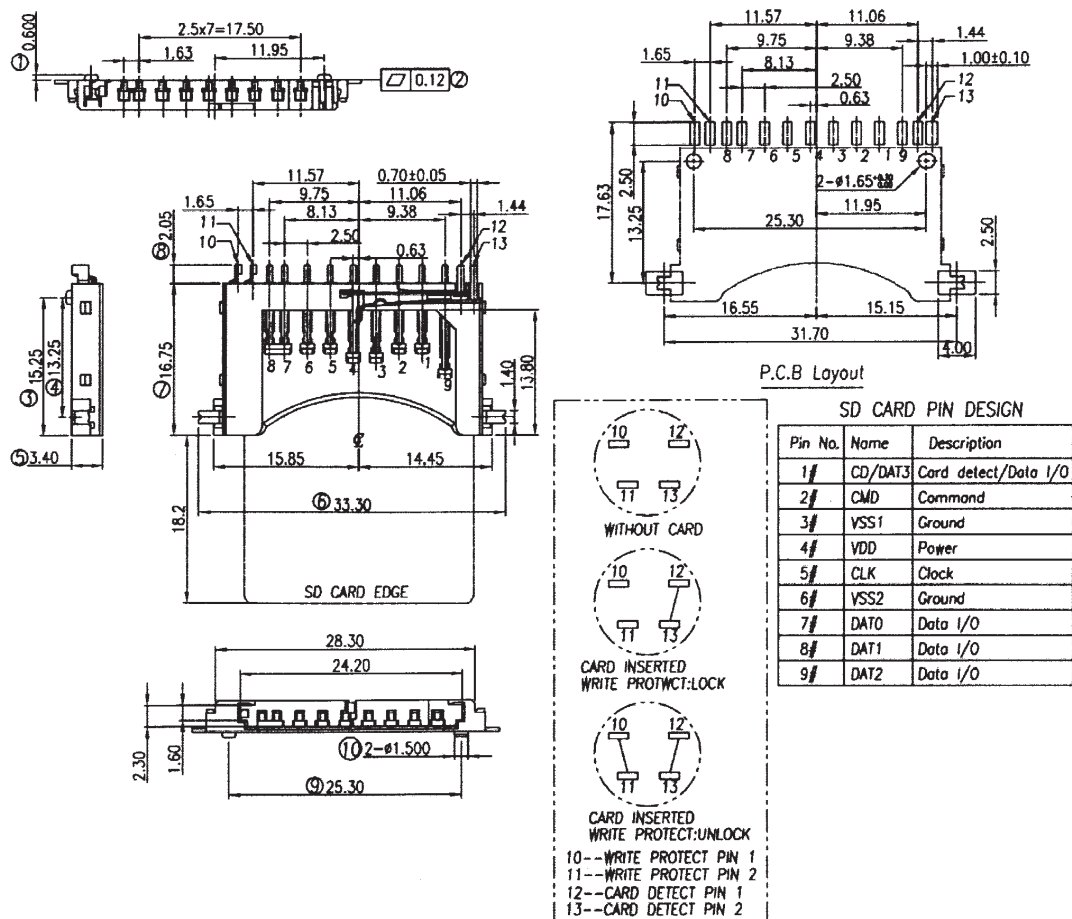


## SD (Secure Digital) Card Receptacle 412D02F-09PC003-SV Series

Unshielded plastic type with card detection function  
Push / Push function type

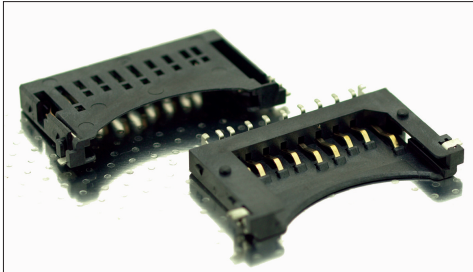

### Ordering Information:

412D02F-09PC003-SV

### Specification for 412D02F-09PC003-SV

Insulator Material: LCP UL94V-0  
 Contact Material: Copper Alloy  
 Current Rating: 0.5A AC/DC  
 Contact Plating: 1 (micro) u" Gold flash over 50u" Ni underplate  
 Solder Tail Plating: 100u"min. Sn plated  
 DWV: 500V AC for 1 minute  
 Insulation Resistance: 1000MΩ min. @ 500V DC  
 Contact Resistance: 40mΩ Max.  
 Operating Temperature: -20°C to +60°C