




Sample Kit

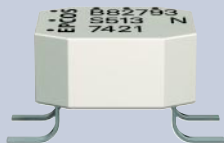

SMT Data Line Chokes

Series B82793, Ring Core \varnothing 4 mm

SMT Data Line Chokes

Series B82793, ring core \varnothing 4 mm

L_R	μH	11	25	51	470	1000	2200	4700
I_R	mA	800	800	800	700	700	500	400
$L_{stray, typ}$	nH	50	1400	2300	100	70	120	250
R_{typ}	m Ω	80	110	140	170	140	400	550
Ordering code B82793		C0113 N201	S0253 N201	S0513 N201	C0474 N215	C0105 N265	C0225 N265	C0475 N265

- Rated current I_R referred to = 60 °C ambient temperature ($T_{Amax} = 125$ °C)
- Rated voltage $V_R = 42$ V AC / 80 V DC
- Data line chokes are used in telecommunications, automotive electronics as well as building management and automation technology
- Chokes with higher rated currents, rated voltages and for higher ambient temperatures are available on request