



ROUGHNECK®
TOUGH TOOLS FOR A TOUGH WORLD™



ROUGHNECK PROFESSIONAL CAULKING GUNS

HEAVY DUTY CAULKING GUN

For cartridges up to 400ml

- Heavy duty push rod and ratchet action
- Robust frame with ergonomic grip
- Double injected soft grip
- Quick release trigger
- Built-in spout cutter
- Hook end

BEST



GOOD



SKELETON TYPE CAULKING GUNS

Dedicated 310ml or up to 400ml cartridges

- Solid frame and ratchet action
- Lightweight and economical
- Built-in Nozzle cleaner
- Quick release trigger
- Hook end

BETTER




SEMI-BARREL TYPE CAULKING GUN

For cartridges up to 400ml

- Heavy duty push rod and ratchet action
- Robust frame with ergonomic grip
- Built-in Nozzle cleaner
- Quick release trigger
- Hook end



Built-in nozzle cleaner in skeleton and semi-barrel type models

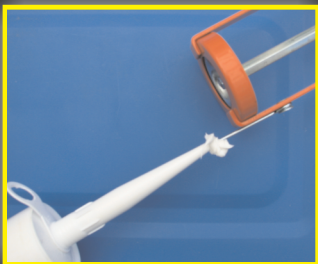

Built-in spout cutter in heavy duty model



Stock No	Description
32-200	Roughneck Caulking Gun - Skeleton Type - 9"
32-210	Roughneck Caulking Gun - Skeleton Type - 11"
32-230	Roughneck Caulking Gun - Professional Semi Barrel Type - 10½"
32-250	Roughneck Caulking Gun - Heavy Duty Professional Semi Barrel Type - 10½"



Please download QR Reader app for your smart phone and scan the code on the left to visit our website

Olympia Tools (UK) Ltd

69, Honey End Lane, Reading, Berkshire, RG30 4EL.

Tel: 0118-951 1942
Fax: 0118-957 6463

info@Olympia-Tools.co.uk
www.Olympia-Tools.co.uk