


SO63-4-9030 Product Details

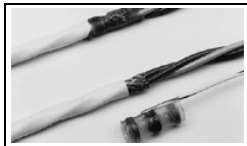

SO63-4-9030

Shield Terminators

[Not EU RoHS or ELV Compliant](#)

Product Highlights:

- Shield Terminator
- Terminator Type = Solder Sleeve
- Fluid Resistance = Splash Protection
- Cable Temperature Rating = 125 °C
- Jacket Outer Diameter = 6.45 mm

[View all Features](#)

TE Internal Number: 482943-000

 [Active](#)

Documentation & Additional Information

Product Drawings:

- [SolderSleeve Device Shield Terminator, with Braid](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Shield Terminator

Mechanical Attachment:

- Inside Diameter (mm [in]) = 5.95 [0.235]

Body Related Features:

- Terminator Type = Solder Sleeve
- Fluid Resistance = Splash Protection
- [Jacket Outer Diameter \(mm \[in\]\)](#) = 6.45 [0.255]

Housing Related Features:

- [Shield O.D. \(Min.\) \(mm \[in\]\)](#) = 3.30 [0.130]
- [Preinstalled Lead](#) = With
- Preinstalled Lead Wire Size (mm² [AWG]) = Braid Strap [CMA 1000]
- MIL or NAS Specification (MIL-S-83519) (NAS 1747) = Yes
- Length (Max.) (mm [in]) = 19.10 [0.750]

Configuration Related Features:

- Temperature Indication System = With
- Temperature Indication System Type = Fusible Ring

Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Conditions for Usage:

- [Cable Temperature Rating \(°C\)](#) = 125
- Operating Temperature (Max.) (°C) = 150

Other:

- Brand = Raychem