


INTERFACE MODULES & SUPPORTS

Male and Female D-Connector Interface Modules

- D Sub male and female to screw terminals
- Terminals marked 1 2 3 etc (+ Shield)
- Separate shield connection
- 35mm DIN rail mounting
- Option for 32mm (G) rail mounting
- Available with optional wall mounting plates
- 45° terminals for easy access
- RoHS compliant
- SVHC free (2012)

CIM/XXW-DMFS

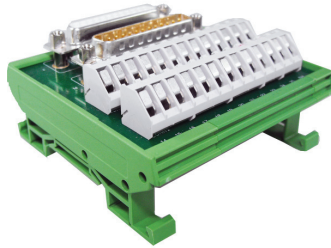

SPECIFICATION

Rating	50V DC 100mA		
Cable entry	0.2-4mm ² (30-12 AWG)		
Terminal screw	M3		
Strip length	6mm (0.24")		
Max terminal torque	0.5Nm (4lb-in)		
Dimensions:	Height:	Width:	Length:
CIM/9W-DMFS	39mm (1.54")	83mm (3.27")	35mm (1.38")
CIM/15W-DMFS	39mm (1.54")	83mm (3.27")	58mm (2.28")
CIM/25W-DMFS	39mm (1.54")	83mm (3.27")	78mm (3.07")
CIM/37W-DMFS	39mm (1.54")	83mm (3.27")	114mm (4.49")
CIM/50W-DMFS	37mm (1.46")	83mm (3.27")	136mm (5.36")

TYPE NO.	DESCRIPTION
CIM/9W-DMFS	9 way male and female D Sub screw terminal interface. 35 mm din rail mounting
CIM/15W-DMFS	15 way male and female D Sub screw terminal interface. 35 mm din rail mounting
CIM/25W-DMFS	25 way male and female D Sub screw terminal interface. 35 mm din rail mounting
CIM/37W-DMFS	37 way male and female D Sub screw terminal interface. 35 mm din rail mounting
CIM/50W-DMFS	50 way male and female D Sub screw terminal interface. 35 mm din rail mounting

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

ENCLOSURES

BATTERIES

TRANS-
FORMERS



+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com

We operate a constant improvement policy,
our products are subject to change without notice.

Ver 1.0 Iss 1

CAMDENBOSS
ELECTRONICS & ENCLOSURES