

Epson Expression Home XP-305



The Epson Expression Home XP-305 is part of the Small-in-One range - Epson's smallest ever range of all-in-one home inkjets. This printer, scanner and copier offers cost-effective printing for home users who are looking for the added benefit of Wi-Fi connectivity, LCD screen as well as mobile printing.

The Epson Expression Home XP-305 comes with Epson Connect¹, offering even more flexibility and freedom. It allows users to quickly and easily print documents and photos wirelessly from smartphones and tablet PCs. Additionally, users can print from anywhere in the world by emailing documents and photos directly to the printer.

The XP-305 is Apple AirPrint ready and makes it simple to print emails, photos, web pages and documents directly from iOS devices².


Meanwhile, Google Cloud Print is also supported and allows users to print on the go from a smartphone or computer.

The automatic Wi-Fi set-up³ makes configuring laptops and computers to print and scan wirelessly extremely easy, as the XP-305 automatically finds the relevant connection settings in order to configure itself. In addition, a 3.6cm colour LCD screen and accompanying memory card slot offers easy-to-use printing with helpful menu prompts.

Epson's new, Claria Home Ink is ideal for affordable reliable printing, producing crisp, clear text documents and glossy, lab-quality photos. With individual ink cartridges you only have to replace the colour used, saving you money.


Claria Home Ink cartridges are available in standard and XL sizes, with page yields displayed clearly on each pack. Identifying the right ink cartridge for your printer couldn't be simpler – just look out for the Daisy image.

DATASHEET

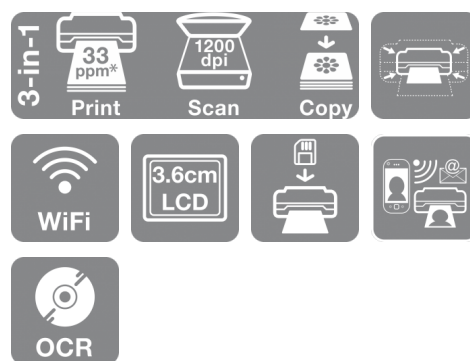

KEY FEATURES

- Save space, save money, save time
- PC-free printing
- Mobile printing over Wi-Fi and email
- Easy to connect wirelessly
- Only replace the colour used

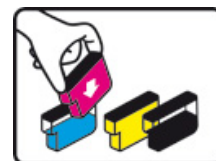

PRODUCT SPECIFICATIONS

TECHNOLOGY	
Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	180 Nozzles black, 59 Nozzles per colour
Minimum Droplet Size	3 pl, With Variable-Sized Droplet Technology
Ink Technology	Epson Claria™ Home Ink
Printing Resolution	5,760 x 1,440 dpi
Category	Consumer
All-in-One Functions	Scan, Copy

PRINT	
Draft printing speed	33 Pages/min Monochrome (plain paper 75 g/m²), 15 Pages/min Color (plain paper 75 g/m²), 38 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper)
Printing Speed ISO/IEC 24734	8.7 Pages/min Monochrome, 4.5 Pages/min Color
Colours	Black, Cyan, Yellow, Magenta
For detailed information on printing speeds please visit http://www.epson.eu/testing .	

SCAN	
Scan speed black A4	300 dpi 2.4 msec/line, 600 dpi 7.2 msec/line
Scan speed colour A4	300 dpi 9.5 msec/line, 600 dpi 14.3 msec/line
Scanning Resolution	1,200 dpi x 2,400 dpi (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

PAPER / MEDIA HANDLING	
Number of paper trays	1
Paper Formats	A4, A5, A6, B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter Legal, 9 x 13 cm, 10 x 15 cm, 13 x 18 cm, 13 x 20 cm, 20 x 25 cm, 100 x 148 mm, 16:9
Duplex	Manual
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets

GENERAL	
Energy Use	13 W (standalone copying, ISO/IEC 24712 pattern), 2.7 W (sleep mode), ENERGY STAR® qualified all-in-one
Supply Voltage	AC 100 V - 240 V, 50 Hz - 60 Hz
Product dimensions	390 x 300 x 145 mm (Width x Depth x Height)
Product weight	4.2 kg
Noise Level	5.1 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 37 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode
Compatible Operating Systems	Mac OS 10.5.8 or later, Windows 7, Windows Vista, Windows XP, Windows XP x64

LOGISTICS INFORMATION

SKU	C11CC09304
Barcode	8715946511306
Dimensions Single Carton	464 x 200 x 380 mm
Carton Weight	5.2 Kg
Country of Origin	Indonesia, Thailand
Pallet Size Euro	40 Units (4 x 10)
Pallet Size Block	60 Units (6 x 10)



For more information please contact:

Telephone: 0871 222 6702 (UK)+
01 436 7742 (Republic of Ireland)
E-mail: enquiries@epson.co.uk
Chat: etalk.epson-europe.com
Fax: 0871 222 6740

Web: www.epson.co.uk
www.epson.ie

+ Calls cost 10p per minute plus network extras.

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

WHAT'S IN THE BOX

- Warranty document
- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges

INK CARTRIDGE COMPATIBILITY

INK YIELD DATA

	18	18XL
	175 pages*	470 pages*
	180 pages*	450 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit www.epson.eu/pageyield

1. Requires a wireless connection to the internet. For more information, supported languages and supported devices please visit www.epsonconnect.eu
2. iOS 5 and above. AirPrint and the AirPrint logo are trademarks of Apple Inc
3. Automatic set-up compatible with Windows 7, Windows Vista and Mac OS. This printer and original ink cartridges are for sale and use in EMEAR only

