


Part # CB-30, Double Contact Candelabra Bayonet Lampholders

Steel Zinc Plated shell and bracket with steel zinc plated spring, brass nickel plated contacts, 18 Awg UL 200C wires. UL rated 125V 75W.
With 1/8" NPSM threaded bushing 1/4" long

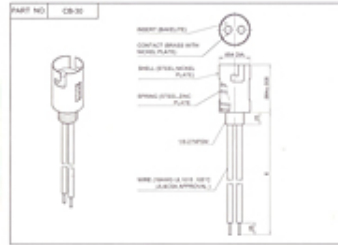

SPECIFICATIONS

Bulb Base	BA15D
Wattage Rating	75 W
Voltage Rating	125 V
Wire	18AWG 105C
UL Approved	✓
Minimum Order	20