


Part # SCB-275, Single Contact Bayonet Lampholder

Zinc plated steel shell and bracket with spring loaded center wire, phenolic contact insert, ceramic insulator available for extreme outdoor use. Standard wires 18 Awg UL 105C.

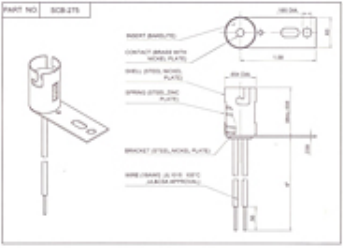

SPECIFICATIONS

Bulb Base	BA15S
Wattage Rating	75 W
Voltage Rating	125 V
Wire	18AWG 105C
UL Approved	✓
Minimum Order	1