



[Back](#)
Selected Cable: 17537**Cord View**

End View	Plug	Cord	Connector	End View
NONE	3"STRIP	SJT	2"STRIP	C13

Part Number	17537
Category	3 conductor plastic original equipment cords
Shielding	unshielded
Jacket Color	black
Length Feet	9'10"
Length Meters	3
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
AWG Stranding	18 (41x34)
Nominal OD Inch	0.315
Nominal OD millimeter	8
Rating	1250 Watts 10A-125V (*)
Notes	(*)Dual rated at 10A-250V. See 17536 for 6'7" version. See 17539 for 16 gauge version.

**Approvals**

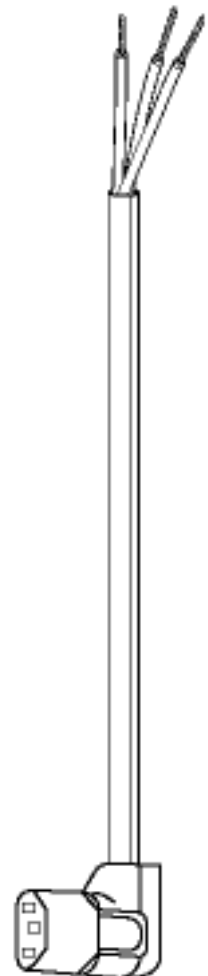

Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

