




[Back](#)

Selected Cable: 17625				
End View	Plug	Cord	Connector	End View
				
C14	388B	SJT BELDFOIL SHIELDED	386E	C13

Part Number	17625
Category	3 conductor plastic detachable
Shielding	Beldfoil Shielded
Jacket Color	black
Length Feet	3'3"
Length Meters	1
Temperature Rating	60 C°C
Packaging Units Per Carton	H-100,H-25
Color Coding	International
AWG Stranding	16 (65x34)
Nominal OD Inch	0.353
Nominal OD millimeter	8.97
Rating	1625 Watts 13A-125V (*)
Notes	(*)Dual rated at 13A-250V. See 17624 for 18 gauge version. See 17525 for unshielded version.

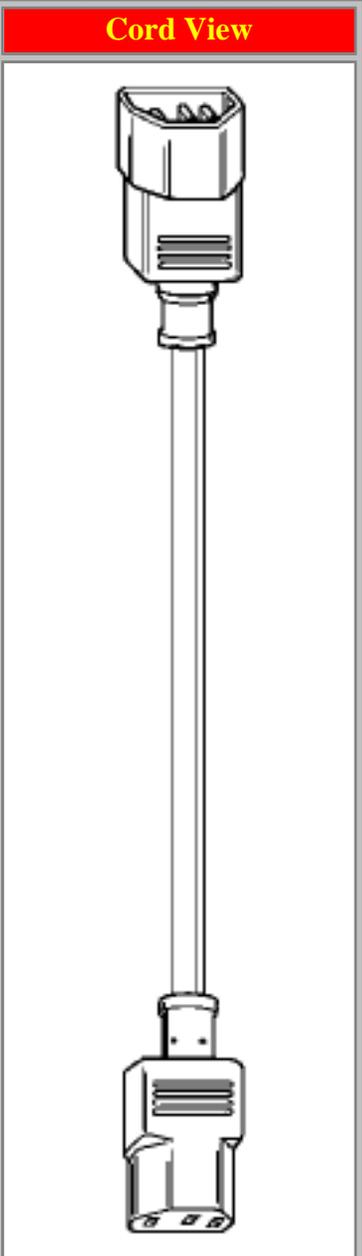

Approvals



Qty:

Back

Volex Power Cord Products Division, 5350 Lakeview Parkway S. Drive #D Indianapolis, IN 46268
800-246-CORD. info@volexpowercords.com

Proposition 65 warning for California residents: This product contains chemicals, including lead, known to the State of California to cause (cancer, and) birth defects or other reproductive harm. Wash hands after handling.

