

**H0,5/12 OR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

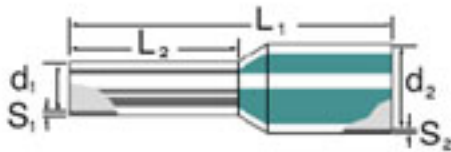

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code

**General ordering data**

Order No.	<a href="#">0409500000</a>
Type	H0,5/12 OR
Version	Wire end ferrule, 0.5 mm <sup>2</sup> , 6 mm, Colour code: Weidmüller, Orange
GTIN (EAN)	4008190090456
Qty.	500 pc(s).

**H0,5/12 OR****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Dimensions and weights**

Length	12 mm	Net weight	0.062 g
--------	-------	------------	---------

**Product data**

Conductor cross-section	0.5 mm <sup>2</sup>	Wire connection cross section AWG, max.	AWG 20
Contact surface length (L2)	6 mm	Contact surface diameter (D1)	1 mm
Collar diameter (D2)	2.6 mm	Metal sleeve thickness (S1)	0.15 mm
Plastic collar thickness (S2)	0.25 mm		

**Classifications**

ETIM 2.0	EC000005	ETIM 3.0	EC000005
UNSPSC	31-16-31-02	eClass 4.1	27-06-07-01
eClass 5.1	27-40-02-01	eClass 6.0	27-40-02-01
eClass 7.0	27-40-02-01		

**Product information**

Description of article	Wire end ferrule with plastic collar, orange
------------------------	--

**Approvals**

Approvals

