
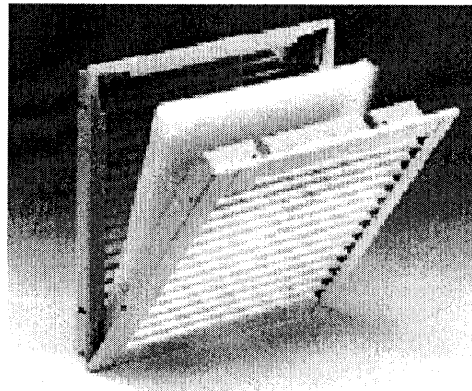


2.0 IP rated Filter Fan units

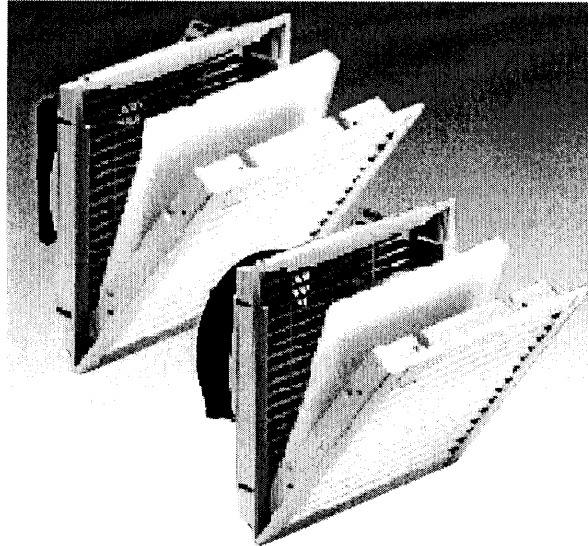

Part Number	Voltage / Colour	Power	Free air flow (Cubic	Airflow when used in combination with PFA	Installation cutout in mm's	IP Rating
-------------	------------------	-------	----------------------	---	-----------------------------	-----------

			metres)			
PF 1000	115v & 230v AC RAL 7032	12w	24	15	92 x 92	IP 43
PF 2000	115v & 230v AC RAL 7032	19w	58	43	125 x 125	IP 54
PF 2500	115v & 230v AC RAL 7032	18w	155	108	223 x 223	IP 54
PF 3000	115v & 230v AC RAL 7032	43 / 48w	255	231	223 x 223	IP 54
PF 5000	115v & 230v AC RAL 7032	63w	478	368	291 x 291	IP 54
PF 6000	115v & 230v AC RAL 7032	173 / 122w	606	437	291 x 291	IP 54

Part Number	Height width & depth in mm's	Weight
PF 1000	105 x 105 x 52	0.55Kg
PF 2000	150 x 150 x 72	0.74Kg
PF 2500	250 x 250 x 111	1.75Kg
PF 3000	250 x 250 x 121	1.75Kg
PF 5000	325 x 325 x 157	3.00Kg
PF 6000	325 x 325 x 157	3.50Kg

Fan and Filter unit Features and Benefits

- 'Click and Fit' no fastening screws required
- 115v AC and 230v AC versions available
- Available in RAL 7032 as standard, RAL 7035 and 9011 to order
- IP 54 protection rating as standard
- 6 sizes within the range
- Slimline versions available to special order
- UL approval across the range
- Terminal connection