

FIBOX accessory range provides excellent selection of cable glands, membrane glands, flanges and cable entry solutions to easily manage cables with high IP rating.



Cable management



Plastic and membrane gland plates



Plastic and membrane glands



RoHS compliant and halogen-free

COVER PLATES

Order symbol	Code	Dimensions mm	Description
--------------	------	---------------	-------------

Polycarbonate (PC), IP 66 (EN 60529), Grey RAL 7035, Flame resistance UL 94-V1

MB 10215	3530215	140 x 49 x 10	Cover plate ▪ size 1
MB 10546	3530546	216 x 85 x 10	Cover plate ▪ size 2
MB 10324	3530324	332 x 127 x 15	Cover plate ▪ size 3

METRIC FLANGE PLATES

Order symbol	Code	Dimensions mm	Description
--------------	------	---------------	-------------

Cable gland plates, Polycarbonate (PC), IP 65 (EN 60529), Grey RAL 7035, Flame resistance UL 94-V1

MB 10892	3530892	140 x 49 x 10	Size 1 ▪ 4xM20
MB 10537	3530537	140 x 49 x 10	Size 1 ▪ 1xM40
MB 10892 SET	3590892		Size 1 ▪ incl. flange, gasket and connector set
MB 10891	3530891	216 x 85 x 10	Size 2 ▪ 12xM20
MB 10860	3530860	216 x 85 x 10	Size 2 ▪ 5xM25+6xM20 PUR gasket
MB 10861	3530861	216 x 85 x 10	Size 2 ▪ 2xM50+4xM20, PUR gasket
MB 10862	3530862	216 x 85 x 10	Size 2 ▪ 2xM16+3xM20+2xM25+2xM32, PUR gasket
MB 10891 SET	3590891		Size 2 ▪ incl. flange, gasket and connector set
MB 10860 SET	3590860		Size 2 ▪ incl. flange, gasket and connector set
MB 10861 SET	3590861		Size 2 ▪ incl. flange, gasket and connector set
MB 10862 SET	3590862		Size 2 ▪ incl. flange, gasket and connector set

Knock-out plates, Polycarbonate (PC), IP 65 (EN 60529), Grey RAL 7035, Flame resistance UL 94-V1

MB 10857	3530857	216 x 85 x 10	Size 2 ▪ 4xM12+4xM12/M20+4xM16/M25
MB 10889	3530889	216 x 85 x 10	Size 2 ▪ 8xM20+5xM25/M16
MB 10890	3530890	216 x 85 x 10	Size 2 ▪ 2xM32/M20+2xM40/M25
MB 10857 SET	3590857		Size 2 ▪ incl. flange, gasket and connector set
MB 10889 SET	3590889		Size 2 ▪ incl. flange, gasket and connector set
MB 10890 SET	3590890		Size 2 ▪ incl. flange, gasket and connector set

PG FLANGE PLATES

Order symbol	Code	Dimensions mm	Description
--------------	------	---------------	-------------

Cable gland plates, Polycarbonate (PC), IP 66 (EN 60529), Grey RAL 7035, Flame resistance UL 94-V1

MB 10151	3530151	140 x 49 x 10	Size 1 ▪ 4x PG13.5
MB 10149	3530149	140 x 49 x 10	Size 1 ▪ 4x PG16
MB 10214	3530214	140 x 49 x 10	Size 1 ▪ 3x PG21
MB 10014	3530014	216 x 85 x 10	Size 2 ▪ 12x PG16
MB 10015	3530015	216 x 85 x 10	Size 2 ▪ 12x PG13.5
MB 10016	3530016	216 x 85 x 10	Size 2 ▪ 6x PG16+4x PG21
MB 10017	3530017	216 x 85 x 10	Size 2 ▪ 4x PG16+3x PG29
MB 10019	3530019	216 x 85 x 10	Size 2 ▪ 4x PG16+2x PG36

Knock-out plates, Polycarbonate (PC), IP 66 (EN 60529), Grey RAL 7035, Flame resistance UL 94-V1

MB 10593	3530593	216 x 85 x 10	Size 2 ▪ 9x PG11+5x PG9/16
MB 10594	3530594	216 x 85 x 10	Size 2 ▪ 4x PG21/29
MB 10595	3530595	216 x 85 x 10	Size 2 ▪ 13x PG16
MB 10596	3530596	216 x 85 x 10	Size 2 ▪ 4x PG11/21+7x PG16

MEMBRANE FLANGE PLATES

Order symbol	Description
--------------	-------------

TPE (Thermo Plastic Elastomer), IP 65 (EN 60529), Flame resistance UL 94HB, Grey RAL 7035, Temperature range -40°...+120°C

FMB 5F	Size 1, Lead-through 8 (Ø2.5-25mm) ▪ Optional RJ-45 lead-through
FMC 3F	Size 2, Lead-through 7 (Ø3-55mm)
FMC 25F	Size 2, Lead-through 29 (Ø3-26mm) ▪ Optional RJ-45 lead-through
FMC 35F	Size 2, Lead-through 43 (Ø3-30mm) ▪ Optional RJ-45 lead-through

Set includes: Flange and MB 10670/10671 plate connectors with screws

FMB 5F-SET	Flange set, Size 1
FMC 3F-SET	Flange set, Size 2
FMC 25F-SET	Flange set, Size 2
FMC 35F-SET	Flange set, Size 2

Set includes: flange and quick connectors (4 + 4 plugs) for plastic enclosures and for sheet steel cabinets

FMC 3FQ-SET	Flange set, Size 2
FMC 25FQ-SET	Flange set, Size 2
FMC 35FQ-SET	Flange set, Size 2



PLATE CONNECTORS AND GASKETS

Order symbol	Code	Dimensions mm	Description
Plate connector sets			
MB 10671	3570671		Connector set, size 1 ▪ incl. 4 screws
MB 10670	3570670		Connector set, size 2 ▪ incl. 4 screws
MB 10672	3570672		Connector set, size 3 ▪ incl. 4 screws
EKZA 7	3770472		Plastic screw, lock nut, flange gasket ▪ size 1
EKZA 8	3770474		Plastic screw, lock nut, flange gasket ▪ size 2
EKZA 9	3770347		Plastic screw, lock nut, flange gasket ▪ size 3
QlockP-SET	3534903		Push-in connector set of membrane flange plates for plastic enclosures ▪ Incl. 4 plugs, size 2
QlockM-SET	3544903		Push-in connector set of membrane flange plates for sheet steel cabinets ▪ Incl. 4 plugs, size 2
Gaskets (EPDM Rubber)			
MK 10437	3510437		Flange gasket ▪ size 1
MK 10438	3510438		Flange gasket ▪ size 2
MK 10439	3510439		Flange gasket ▪ size 3
MK 10440	3510440		Flange gasket, size 1 ▪ for smooth side
MK 10441	3510441		Flange gasket, size 2 ▪ for smooth side
Plastic head screws			
MB 10345	3570345		Plastic head screw (M6x25) ▪ for size 1 flange
MB 10346	3570346		Plastic head screw (M8x25) ▪ for size 2 flange
MB 10347	3570347		Plastic head screw (M10x30) ▪ for size 3 flange
Lock nuts			
M-6	3570576		Lock nut for plastic head screws ▪ (Size M6)
M-8	3570577		Lock nut for plastic head screws ▪ (Size M8)
M-10	3570578		Lock nut for plastic head screws ▪ (Size M10)
Plate extension			
MB 10391	3530391		Extension flange (height 25 mm) ▪ Mounting with 4x MB 10392
MB 10392	3570392		Plastic head screw, size M8x50



CABLE ENTRIES AND BOXES

Order symbol	Code	Dimensions mm	Description
Cable entries			
EPA 1130	3550385		Cable entry, size 1 ▪ 1 cable, 1x10-31mm
EPA 1230	3550386		Cable entry, size 1 ▪ 2 cable, 2x10-31mm
EPA 2160	3550387		Cable entry, size 2 ▪ 1 cable, 1x28-60mm
EPA 2260	3550388		Cable entry, size 2 ▪ 2 cables, 2x28-60mm
EPA 1130 SET	3550055		Cable entry set ▪ Includes: Cable entry, rubber cushion, mounting screws and lock nuts
EPA 1230 SET	3550049		Cable entry set ▪ Includes: Cable entry, 2 rubber cushions, mounting screws and lock nuts
EPA 2160 SET	3550056		Cable entry set ▪ Includes: Cable entry, rubber cushion, mounting screws and lock nuts
EPA 2260 SET	3550052		Cable entry set ▪ Includes: Cable entry, 2 rubber cushions, mounting screws and lock nuts
HIBOX 16	4712221		Cable entry ▪ with cable gasket
DSHIBOX 26	4712223		Cable entry ▪ with two cable gasket
Cable entry boxes			
MB 2260	3730260		Including: base, cover, cover screws, 1 blind plug, 1 pull-off ▪ hose clamp with screws, membrane cable gland, and plate connector set.
MB 2260A	3730261		Cable entry accessory set ▪ Including: membrane cable gland, pull-off, and hose clamp with screws.
EPA-OE	3530700	280 x 280 x 100	Cable entry box
EPA-PL	3530702	380 x 280 x 150	Cable entry box
Other Accessories			
MK 10426	3510426		Rubber cushion for cable Ø 10-31 mm, size 1 ▪ for cable entry
MK 10428	3510428		Rubber cushion for cable Ø 28-60 mm, size 2 ▪ for cable entry
MK 10704	3510704		Membrane cable gland for EPA-OE and EPA-PL enclosures
MB 10717	3530717		Connection bridge and gasket ▪ size 2
MB 10718	3530718		Connection bridge and gasket ▪ size 3
MK 12198	4512198		Cable entry gasket for MB 2260, F2/12102 and F3/12101
MR 12198	3512198		Hose clamp for MK 12198



POLYAMIDE CABLE GLANDS

Order symbol	Code	Description
--------------	------	-------------

Standard connecting threads, Grey RAL 7035, Temperature range -20°...+100°C

GPA M12	7016400	Cable gland (IP 68 - 5 bar), M12x1,5 ▪ for cable 3-6 mm
GPA M16	7016401	Cable gland (IP 68 - 5 bar), M16x1,5 ▪ for cable 5-10 mm
GPA M20	7016402	Cable gland (IP 68 - 5 bar), M20x1,5 ▪ for cable 8-13 mm
GPA M25	7016403	Cable gland (IP 68 - 5 bar), M25x1,5 ▪ for cable 11-17 mm
GPA M32	7016404	Cable gland (IP 68 - 5 bar), M32x1,5 ▪ for cable 15-21 mm
GPA M40	7016405	Cable gland (IP 68 - 5 bar), M40x1,5 ▪ for cable 19-28 mm
GPA M50	7016406	Cable gland (IP 68 - 5 bar), M50x1,5 ▪ for cable 27-35 mm
GPA M63	7016407	Cable gland (IP 68 - 5 bar), M63x1,5 ▪ for cable 32-42 mm

Long connecting threads, Grey RAL 7035, Temperature range -20°...+100°C

GPA M12-L	7016533	Cable gland (IP 68 - 5 bar), M12x1,5 ▪ for cable 3-6 mm
GPA M16-L	7016534	Cable gland (IP 68 - 5 bar), M16x1,5 ▪ for cable 5-10 mm
GPA M20-L	7016535	Cable gland (IP 68 - 5 bar), M20x1,5 ▪ for cable 8-13 mm
GPA M25-L	7016536	Cable gland (IP 68 - 5 bar), M25x1,5 ▪ for cable 11-17 mm
GPA M32-L	7016537	Cable gland (IP 68 - 5 bar), M32x1,5 ▪ for cable 15-21 mm
GPA M40-L	7016538	Cable gland (IP 68 - 5 bar), M40x1,5 ▪ for cable 19-28 mm
GPA M50-L	7016539	Cable gland (IP 68 - 5 bar), M50x1,5 ▪ for cable 27-35 mm
GPA M63-L	7016540	Cable gland (IP 68 - 5 bar), M63x1,5 ▪ for cable 32-42 mm

Lock nuts for cable glands, Grey RAL 7035

GPA M12-B	7016408	Hexagonal lock nut ▪ M12x1,5
GPA M16-B	7016409	Hexagonal lock nut ▪ M16x1,5
GPA M20-B	7016410	Hexagonal lock nut ▪ M20x1,5
GPA M25-B	7016411	Hexagonal lock nut ▪ M25x1,5
GPA M32-B	7016412	Hexagonal lock nut ▪ M32x1,5
GPA M40-B	7016413	Hexagonal lock nut ▪ M40x1,5
GPA M50-B	7016414	Hexagonal lock nut ▪ M50x1,5
GPA M63-B	7016415	Hexagonal lock nut ▪ M63x1,5



MEMBRANE CABLE GLANDS

Order symbol	Description
--------------	-------------

EPDM Rubber, RAL 7035 Grey, IP 66/IP 67 (EN 60529:1991+ A1:2000), Flame resistance UL 94-V2, Wall thickness (C) 1,5 -5 mm, Temperature range -40°...+120°C

FEM 3-5	EPDM Cable gland M12 ▪ for cable 3-5 mm
FEM 5-7	EPDM Cable gland M16 ▪ for cable 5-7 mm
FEM 7-10	EPDM Cable gland M20 ▪ for cable 7-10 mm
FEM 10-14/23	EPDM Cable gland M23/PG16 ▪ for cable 10-14 mm
FEM 10-14/25	EPDM Cable gland M25 ▪ for cable 10-14 mm
FEM 14-20	EPDM Cable gland M32 ▪ for cable 14-20 mm
FEM 20-26	EPDM Cable gland M40 ▪ for cable 20-26 mm
FEM 26-35	EPDM Cable gland M50 ▪ for cable 26-35 mm
FEM 30-45	EPDM Cable gland M60 ▪ for cable 30-45 mm
MFM 8-12	EPDM Multi-Fem M50 ▪ for cable 3x6-10 mm, 3x10-14 mm



Accessories expand scope of use for enclosures by adding new features. Fibox accessory range covers variety of inspection windows and ventilation and pressure equalizer devices.



General accessories



Inspection windows



Ventilation devices




RoHS compliant and halogen-free

INSPECTION WINDOWS


Order symbol	Code	Dimensions mm	Description
Polycarbonate (PC), IP 54			
L 02	3730660	60 x 77	Window for 2 modules ▪ Clear cover
L 04	3730661	96 x 77	Window for 4 modules ▪ Clear cover
L 06	3730662	130 x 77	Window for 6 modules ▪ Clear cover
L 08	3730663	162 x 77	Window for 8 modules ▪ Clear cover
L 10	3730664	199 x 77	Window for 10 modules ▪ Clear cover
Polycarbonate (PC), IP 65			
L 12	3730589	248 x 128	Window for 12 modules ▪ Low clear cover
L 12 II	3730775	248 x 128	Window for 12 modules ▪ Smoked transparent cover
L 13	3730692	257 x 108	Window for 13 modules ▪ Clear cover
L 24	3730588	248 x 218	Window for 24 modules ▪ Low clear cover
L 24 II	3730776	248 x 218	Window for 24 modules ▪ Smoked transparent cover
L 43 II	4512298	331 x 277	Window for 26 modules ▪ Smoked transparent cover
L 44 II	4512299	377 x 331	Window for 36 modules ▪ Smoked transparent cover
Front plates for windows L 12, L 12 II, L 24 and L 24 II			
B12 10621-45	3730621		Front plate for window 12 modules
B24 10620-45	3730620		Front plate for window 2x12 modules

L 02 – L 10

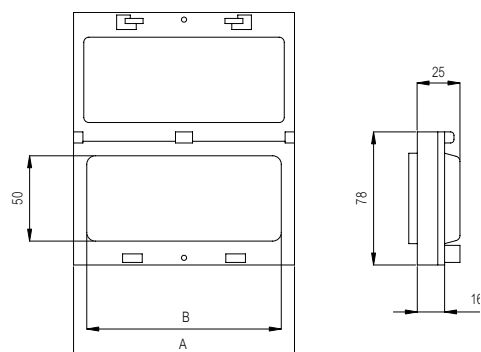


TYPE	A	B
L02	59	44
L04	94.5	78
L06	129.5	114
L08	163	146
L10	200	183


L 12

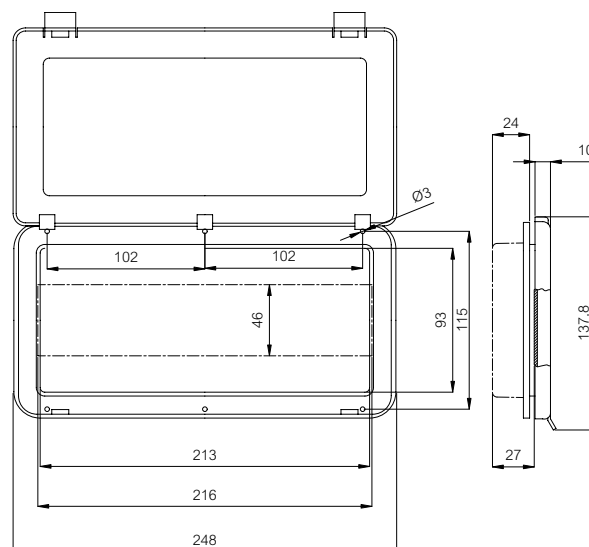


L 13

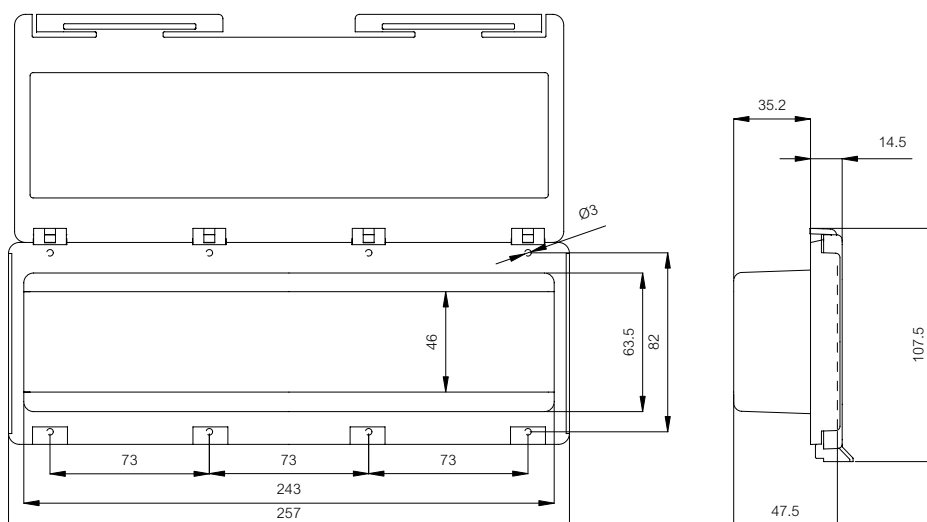


L 24

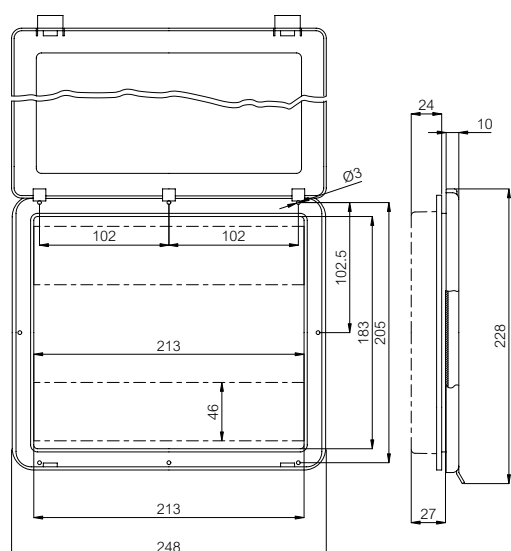

L 43

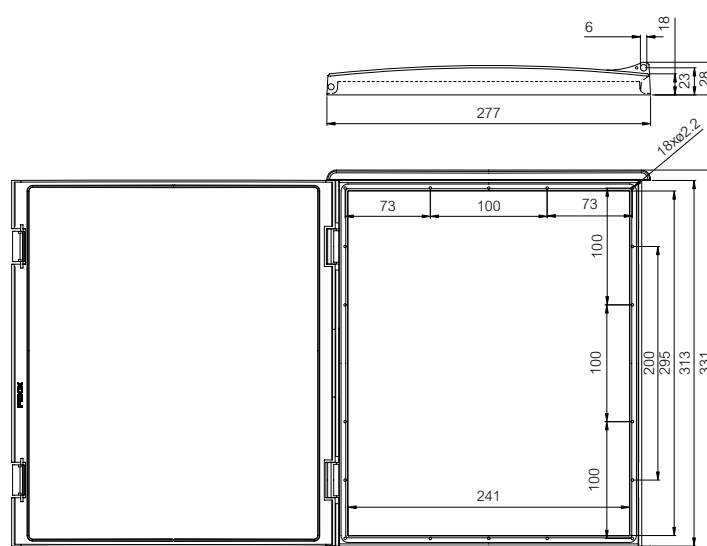

L 44

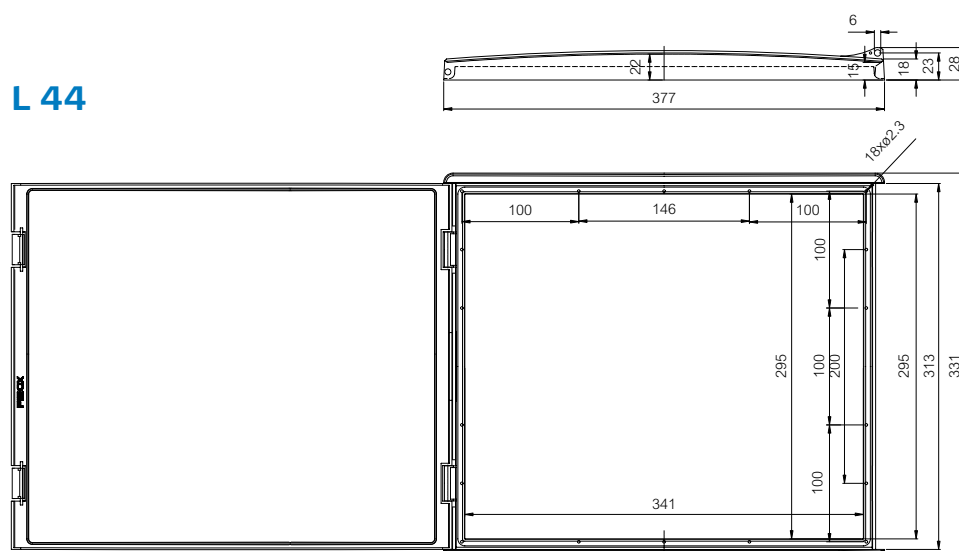

VENTILATION DEVICES

Order symbol	Code	Dimensions mm	Description
MB 10564 II	3541564	70 x 50 x 20	Ventilation device IP 44 • Gasketed, incl. screws
MB 10858 II	3540858		Grille/filter holder • for MB 10564 II
MB 10859 II	3540859		Holder for fan • incl. screws
MB 10894	3540894		Pressure equalizer plug, IP 68 • light grey, thread M12 x 1,5
MB 10631	3540631		Ventilation device IP 33
MB 12189	4512189		Draining plug IP 34



Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
50 x 45 x 32	AL 050503	ALU	74	110 x 80 x 65	PC B 65 T	PICCOLO	144
50 x 45 x 32	ALX 050503	ATEX	218	110 x 80 x 65	ABS B 65 G	PICCOLO	144
52 x 50 x 40	PC 050504	EURONORD	110	110 x 80 x 65	ABS B 65 T	PICCOLO	144
52 x 50 x 40	AB 050504	EURONORD	110	110 x 80 x 85	PC B 85 G	PICCOLO	144
65 x 50 x 45	PC 050705	EURONORD	111	110 x 80 x 85	PC B 85 T	PICCOLO	144
65 x 50 x 45	PCT 050705	EURONORD	111	110 x 80 x 85	ABS B 85 G	PICCOLO	144
65 x 50 x 45	AB 050705	EURONORD	111	110 x 80 x 85	ABS B 85 T	PICCOLO	144
66 x 60 x 46	ALN 060605	ALU	75	120 x 80 x 55	PC 081206	EURONORD	114
66 x 60 x 46	ALX 060605	ATEX	218	120 x 80 x 55	PCT 081206	EURONORD	114
80 x 75 x 55	P 080806	EURONORD	130	120 x 80 x 55	AB 081206	EURONORD	114
80 x 75 x 55	PEX 080806	ATEX	220	120 x 80 x 60	PC 081206H	EURONORD	114
82 x 77 x 57	ALN 080806	ALU	78	120 x 80 x 60	PCT 081206H	EURONORD	114
82 x 77 x 57	ALX 080806	ATEX	218	120 x 80 x 60	AB 081206H	EURONORD	114
82 x 80 x 55	PC 080806	EURONORD	113	120 x 80 x 85	PC 081209	EURONORD	114
82 x 80 x 55	PCT 080806	EURONORD	113	120 x 80 x 85	PCT 081209	EURONORD	114
82 x 80 x 55	AB 080806	EURONORD	113	120 x 80 x 85	AB 081209	EURONORD	114
82 x 80 x 65	PC 080807	EURONORD	113	120 x 80 x 90	PC 081209H	EURONORD	114
82 x 80 x 65	PCT 080807	EURONORD	113	120 x 80 x 90	PCT 081209H	EURONORD	114
82 x 80 x 65	AB 080807	EURONORD	113	120 x 80 x 90	AB 081209H	EURONORD	114
82 x 80 x 85	PC 080809	EURONORD	113	122 x 120 x 65	PC 121207	EURONORD	116
82 x 80 x 85	PCT 080809	EURONORD	113	122 x 120 x 65	PCT 121207	EURONORD	116
82 x 80 x 85	AB 080809	EURONORD	113	122 x 120 x 65	AB 121207	EURONORD	116
82 x 80 x 95	PC 080810	EURONORD	113	122 x 120 x 75	PC 121208	EURONORD	116
82 x 80 x 95	PCT 080810	EURONORD	113	122 x 120 x 75	PCT 121208	EURONORD	116
82 x 80 x 95	AB 080810	EURONORD	113	122 x 120 x 75	AB 121208	EURONORD	116
98 x 66 x 41	PC 071004	EURONORD	112	122 x 120 x 90	P 121209	EURONORD	134
98 x 66 x 41	PCT 071004	EURONORD	112	122 x 120 x 90	PEX 121209	ATEX	220
98 x 66 x 41	PCQ 071004	EURONORD	112	122 x 120 x 95	PC 121210	EURONORD	116
98 x 66 x 41	PCTQ 071004	EURONORD	112	122 x 120 x 95	PCT 121210	EURONORD	116
98 x 66 x 41	AB 071004	EURONORD	112	122 x 120 x 95	AB 121210	EURONORD	116
98 x 66 x 41	ABQ 071004	EURONORD	112	122 x 120 x 105	PC 121211	EURONORD	116
100 x 66 x 46	ALN 061005	ALU	76	122 x 120 x 105	PCT 121211	EURONORD	116
100 x 66 x 46	ALX 061005	ATEX	218	122 x 120 x 105	AB 121211	EURONORD	116
100 x 100 x 35	PC 95/35 LG	MNX	15	125 x 124 x 81	ALN 121208	ALU	82
100 x 100 x 35	PC 95/35 LT	MNX	15	125 x 124 x 81	ALX 121208	ATEX	218
100 x 100 x 35	ABS 95/35 LG	MNX	15	127 x 81 x 57	ALN 081306	ALU	79
100 x 100 x 35	ABS 95/35 LT	MNX	15	127 x 81 x 57	ALX 081306	ATEX	218
100 x 100 x 50	PC 95/50 LG	MNX	15	130 x 80 x 35	PC 100/35 LG	MNX	17
100 x 100 x 50	PC 95/50 LT	MNX	15	130 x 80 x 35	PC 100/35 LT	MNX	17
100 x 100 x 50	ABS 95/50 LG	MNX	15	130 x 80 x 35	ABS 100/35 LG	MNX	17
100 x 100 x 50	ABS 95/50 LT	MNX	15	130 x 80 x 35	ABS 100/35 LT	MNX	17
100 x 100 x 60	PC 95/60 HG	MNX	16	130 x 80 x 50	PC 100/50 LG	MNX	17
100 x 100 x 60	PC 95/60 HT	MNX	16	130 x 80 x 50	PC 100/50 LT	MNX	17
100 x 100 x 60	ABS 95/60 HG	MNX	16	130 x 80 x 50	ABS 100/50 LG	MNX	17
100 x 100 x 60	ABS 95/60 HT	MNX	16	130 x 80 x 50	ABS 100/50 LT	MNX	17
100 x 100 x 60	PCM 95/60 G	MNX	28	130 x 80 x 60	PC 100/60 HG	MNX	18
100 x 100 x 60	PCM 95/60 T	MNX	28	130 x 80 x 60	PC 100/60 HT	MNX	18
100 x 100 x 75	PC 95/75 HG	MNX	16	130 x 80 x 60	ABS 100/60 HG	MNX	18
100 x 100 x 75	PC 95/75 HT	MNX	16	130 x 80 x 60	ABS 100/60 HT	MNX	18
100 x 100 x 75	ABS 95/75 HG	MNX	16	130 x 80 x 60	PCM 100/60 G	MNX	29
100 x 100 x 75	ABS 95/75 HT	MNX	16	130 x 80 x 60	PCM 100/60 T	MNX	29
100 x 100 x 75	PCM 95/75 G	MNX	28	130 x 80 x 75	PC 100/75 LG	MNX	17
100 x 100 x 75	PCM 95/75 T	MNX	28	130 x 80 x 75	PC 100/75 LT	MNX	17
110 x 75 x 55	P 081106	EURONORD	131	130 x 80 x 75	ABS 100/75 LG	MNX	17
110 x 75 x 55	PEX 081106	ATEX	220	130 x 80 x 75	ABS 100/75 LT	MNX	17
110 x 80 x 65	PC B 65 G	PICCOLO	144	130 x 80 x 75	PC 100/75 HG	MNX	18

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
130 x 80 x 75	PC 100/75 HT	MNX	18	130 x 130 x 125	PC 125/125 HT	MNX	20
130 x 80 x 75	ABS 100/75 HG	MNX	18	130 x 130 x 125	ABS 125/125 HG	MNX	20
130 x 80 x 75	ABS 100/75 HT	MNX	18	130 x 130 x 125	ABS 125/125 HT	MNX	20
130 x 80 x 75	PCM 100/75 G	MNX	29	130 x 130 x 125	PCM 125/125 G	MNX	30
130 x 80 x 75	PCM 100/75 T	MNX	29	130 x 130 x 125	PCM 125/125 T	MNX	30
130 x 80 x 100	PC 100/100 LG	MNX	17	140 x 80 x 65	PC C 65 G	PICCOLO	145
130 x 80 x 100	PC 100/100 LT	MNX	17	140 x 80 x 65	PC C 65 T	PICCOLO	145
130 x 80 x 100	ABS 100/100 LG	MNX	17	140 x 80 x 65	ABS C 65 G	PICCOLO	145
130 x 80 x 100	ABS 100/100 LT	MNX	17	140 x 80 x 65	ABS C 65 T	PICCOLO	145
130 x 80 x 100	PC 100/100 HG	MNX	18	140 x 80 x 85	PC C 85 G	PICCOLO	145
130 x 80 x 100	PC 100/100 HT	MNX	18	140 x 80 x 85	PC C 85 T	PICCOLO	145
130 x 80 x 100	ABS 100/100 HG	MNX	18	140 x 80 x 85	ABS C 85 G	PICCOLO	145
130 x 80 x 100	ABS 100/100 HT	MNX	18	140 x 80 x 85	ABS C 85 T	PICCOLO	145
130 x 80 x 100	PCM 100/100 G	MNX	29	150 x 150 x 110	CAB PC 151511 G	CAB	64
130 x 80 x 100	PCM 100/100 T	MNX	29	150 x 150 x 110	CAB PC 151511 T	CAB	64
130 x 80 x 125	PC 100/125 HG	MNX	18	150 x 150 x 110	CAB ABS 151511 G	CAB	64
130 x 80 x 125	PC 100/125 HT	MNX	18	150 x 150 x 110	CAB ABS 151511 T	CAB	64
130 x 80 x 125	ABS 100/125 HG	MNX	18	152 x 66 x 46	AL 061505	ALU	77
130 x 80 x 125	ABS 100/125 HT	MNX	18	152 x 66 x 46	ALX 061505	ATEX	218
130 x 80 x 125	PCM 100/125 G	MNX	29	160 x 75 x 55	P 081606	EURONORD	132
130 x 80 x 125	PCM 100/125 T	MNX	29	160 x 75 x 55	PEX 081606	ATEX	220
130 x 130 x 35	PC 125/35 LG	MNX	19	160 x 80 x 55	PC 081606	EURONORD	115
130 x 130 x 35	PC 125/35 LT	MNX	19	160 x 80 x 55	PCT 081606	EURONORD	115
130 x 130 x 35	ABS 125/35 LG	MNX	19	160 x 80 x 55	AB 081606	EURONORD	115
130 x 130 x 35	ABS 125/35 LT	MNX	19	160 x 80 x 65	PC 081607	EURONORD	115
130 x 130 x 50	PC 125/50 LG	MNX	19	160 x 80 x 65	PCT 081607	EURONORD	115
130 x 130 x 50	PC 125/50 LT	MNX	19	160 x 80 x 65	AB 081607	EURONORD	115
130 x 130 x 50	ABS 125/50 LG	MNX	19	160 x 80 x 85	PC 081609	EURONORD	115
130 x 130 x 50	ABS 125/50 LT	MNX	19	160 x 80 x 85	PCT 081609	EURONORD	115
130 x 130 x 60	PC 125/60 HG	MNX	20	160 x 80 x 85	AB 081609	EURONORD	115
130 x 130 x 60	PC 125/60 HT	MNX	20	160 x 80 x 95	PC 081610	EURONORD	115
130 x 130 x 60	ABS 125/60 HG	MNX	20	160 x 80 x 95	PCT 081610	EURONORD	115
130 x 130 x 60	ABS 125/60 HT	MNX	20	160 x 80 x 95	AB 081610	EURONORD	115
130 x 130 x 60	PCM 125/60 G	MNX	30	160 x 120 x 90	PC 121609	EURONORD	117
130 x 130 x 60	PCM 125/60 T	MNX	30	160 x 120 x 90	PCT 121609	EURONORD	117
130 x 130 x 75	PC 125/75 LG	MNX	19	160 x 120 x 90	AB 121609	EURONORD	117
130 x 130 x 75	PC 125/75 LT	MNX	19	160 x 120 x 140	PC 121614	EURONORD	117
130 x 130 x 75	ABS 125/75 LG	MNX	19	160 x 120 x 140	PCT 121614	EURONORD	117
130 x 130 x 75	ABS 125/75 LT	MNX	19	160 x 120 x 140	AB 121614	EURONORD	117
130 x 130 x 75	PC 125/75 HG	MNX	20	160 x 160 x 91	P 161609	EURONORD	136
130 x 130 x 75	PC 125/75 HT	MNX	20	160 x 160 x 91	PEX 161609	ATEX	220
130 x 130 x 75	ABS 125/75 HG	MNX	20	163 x 162 x 91	ALN 161609	ALU	85
130 x 130 x 75	ABS 125/75 HT	MNX	20	163 x 162 x 91	ALX 161609	ATEX	218
130 x 130 x 75	PCM 125/75 G	MNX	30	166 x 160 x 80	PC 17/16-LC3	CARDMASTER	208
130 x 130 x 75	PCM 125/75 T	MNX	30	166 x 160 x 80	ABS 17/16-LC3	CARDMASTER	208
130 x 130 x 100	PC 125/100 LG	MNX	19	166 x 160 x 89	PC 17/16-LFC3	CARDMASTER	208
130 x 130 x 100	PC 125/100 LT	MNX	19	166 x 160 x 108	PC 17/16-C3	CARDMASTER	209
130 x 130 x 100	ABS 125/100 LG	MNX	19	166 x 160 x 108	ABS 17/16-C3	CARDMASTER	209
130 x 130 x 100	ABS 125/100 LT	MNX	19	166 x 160 x 118	PC 17/16-FC3	CARDMASTER	209
130 x 130 x 100	PC 125/100 HG	MNX	20	170 x 80 x 65	PC D 65 G	PICCOLO	146
130 x 130 x 100	PC 125/100 HT	MNX	20	170 x 80 x 65	PC D 65 T	PICCOLO	146
130 x 130 x 100	ABS 125/100 HG	MNX	20	170 x 80 x 65	ABS D 65 G	PICCOLO	146
130 x 130 x 100	ABS 125/100 HT	MNX	20	170 x 80 x 65	ABS D 65 T	PICCOLO	146
130 x 130 x 100	PCM 125/100 G	MNX	30	170 x 80 x 85	PC D 85 G	PICCOLO	146
130 x 130 x 100	PCM 125/100 T	MNX	30	170 x 80 x 85	PC D 85 T	PICCOLO	146
130 x 130 x 125	PC 125/125 HG	MNX	20	170 x 80 x 85	ABS D 85 G	PICCOLO	146

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
170 x 80 x 85	ABS D 85 T	PICCOLO	146	180 x 130 x 125	PC 150/125 LT	MNX	21
170 x 140 x 95	PC H 95 G	PICCOLO	148	180 x 130 x 125	ABS 150/125 LG	MNX	21
170 x 140 x 95	PC H 95 T	PICCOLO	148	180 x 130 x 125	ABS 150/125 LT	MNX	21
170 x 140 x 95	ABS H 95 G	PICCOLO	148	180 x 130 x 125	PC 150/125 HG	MNX	22
170 x 140 x 95	ABS H 95 T	PICCOLO	148	180 x 130 x 125	PC 150/125 HT	MNX	22
177 x 81 x 57	ALN 081806	ALU	80	180 x 130 x 125	ABS 150/125 HG	MNX	22
177 x 81 x 57	ALX 081806	ATEX	218	180 x 130 x 125	ABS 150/125 HT	MNX	22
180 x 130 x 35	PC 150/35 LG	MNX	21	180 x 130 x 125	PC 150/125 XHG	MNX	23
180 x 130 x 35	PC 150/35 LT	MNX	21	180 x 130 x 125	PC 150/125 XHT	MNX	23
180 x 130 x 35	ABS 150/35 LG	MNX	21	180 x 130 x 125	ABS 150/125 XHG	MNX	23
180 x 130 x 35	ABS 150/35 LT	MNX	21	180 x 130 x 125	ABS 150/125 XHT	MNX	23
180 x 130 x 50	PC 150/50 LG	MNX	21	180 x 130 x 125	PCM 150/125 G	MNX	31
180 x 130 x 50	PC 150/50 LT	MNX	21	180 x 130 x 125	PCM 150/125 T	MNX	31
180 x 130 x 50	ABS 150/50 LG	MNX	21	180 x 130 x 125	PCM 150/125 XG	MNX	32
180 x 130 x 50	ABS 150/50 LT	MNX	21	180 x 130 x 125	PCM 150/125 XT	MNX	32
180 x 130 x 60	PC 150/60 HG	MNX	22	180 x 130 x 150	PC 150/150 HG	MNX	22
180 x 130 x 60	PC 150/60 HF	MNX	22	180 x 130 x 150	PC 150/150 HT	MNX	22
180 x 130 x 60	PC 150/60 HT	MNX	22	180 x 130 x 150	ABS 150/150 HG	MNX	22
180 x 130 x 60	ABS 150/60 HG	MNX	22	180 x 130 x 150	ABS 150/150 HT	MNX	22
180 x 130 x 60	ABS 150/60 HT	MNX	22	180 x 130 x 150	PC 150/150 XHG	MNX	23
180 x 130 x 60	PCM 150/60 G	MNX	31	180 x 130 x 150	PC 150/150 XHT	MNX	23
180 x 130 x 60	PCM 150/60 T	MNX	31	180 x 130 x 150	ABS 150/150 XHG	MNX	23
180 x 130 x 75	PC 150/75 LG	MNX	21	180 x 130 x 150	ABS 150/150 XHT	MNX	23
180 x 130 x 75	PC 150/75 LT	MNX	21	180 x 130 x 150	PCM 150/150 G	MNX	31
180 x 130 x 75	ABS 150/75 LG	MNX	21	180 x 130 x 150	PCM 150/150 T	MNX	31
180 x 130 x 75	ABS 150/75 LT	MNX	21	180 x 130 x 150	PCM 150/150 XG	MNX	32
180 x 130 x 75	PC 150/75 HG	MNX	22	180 x 130 x 150	PCM 150/150 XT	MNX	32
180 x 130 x 75	PC 150/75 HT	MNX	22	180 x 130 x 175	PC 150/175 XHG	MNX	23
180 x 130 x 75	ABS 150/75 HG	MNX	22	180 x 130 x 175	PC 150/175 XHT	MNX	23
180 x 130 x 75	ABS 150/75 HT	MNX	22	180 x 130 x 175	ABS 150/175 XHG	MNX	23
180 x 130 x 75	PCM 150/75 G	MNX	31	180 x 130 x 175	ABS 150/175 XHT	MNX	23
180 x 130 x 75	PCM 150/75 T	MNX	31	180 x 130 x 175	PCM 150/175 XG	MNX	32
180 x 130 x 85	PC 150/85 XHG	MNX	23	180 x 130 x 175	PCM 150/175 XT	MNX	32
180 x 130 x 85	PC 150/85 XHF	MNX	23	180 x 180 x 60	PC 175/60 HG	MNX	24
180 x 130 x 85	PC 150/85 XHT	MNX	23	180 x 180 x 60	PC 175/60 HT	MNX	24
180 x 130 x 85	ABS 150/85 XHG	MNX	23	180 x 180 x 60	ABS 175/60 HG	MNX	24
180 x 130 x 85	ABS 150/85 XHT	MNX	23	180 x 180 x 60	ABS 175/60 HT	MNX	24
180 x 130 x 85	PCM 150/85 XG	MNX	32	180 x 180 x 60	PCM 175/60 G	MNX	33
180 x 130 x 85	PCM 150/85 XT	MNX	32	180 x 180 x 60	PCM 175/60 T	MNX	33
180 x 130 x 100	PC 150/100 LG	MNX	21	180 x 180 x 75	PC 175/75 HG	MNX	24
180 x 130 x 100	PC 150/100 LT	MNX	21	180 x 180 x 75	PC 175/75 HT	MNX	24
180 x 130 x 100	ABS 150/100 LG	MNX	21	180 x 180 x 75	ABS 175/75 HG	MNX	24
180 x 130 x 100	ABS 150/100 LT	MNX	21	180 x 180 x 75	ABS 175/75 HT	MNX	24
180 x 130 x 100	PC 150/100 HG	MNX	22	180 x 180 x 75	PCM 175/75 G	MNX	33
180 x 130 x 100	PC 150/100 HT	MNX	22	180 x 180 x 75	PCM 175/75 T	MNX	33
180 x 130 x 100	ABS 150/100 HG	MNX	22	180 x 180 x 100	PC 175/100 HG	MNX	24
180 x 130 x 100	ABS 150/100 HT	MNX	22	180 x 180 x 100	PC 175/100 HT	MNX	24
180 x 130 x 100	PC 150/100 XHG	MNX	23	180 x 180 x 100	ABS 175/100 HG	MNX	24
180 x 130 x 100	PC 150/100 XHT	MNX	23	180 x 180 x 100	ABS 175/100 HT	MNX	24
180 x 130 x 100	ABS 150/100 XHG	MNX	23	180 x 180 x 100	PCM 175/100 G	MNX	33
180 x 130 x 100	ABS 150/100 XHT	MNX	23	180 x 180 x 100	PCM 175/100 T	MNX	33
180 x 130 x 100	PCM 150/100 G	MNX	31	180 x 180 x 125	PC 175/125 HG	MNX	24
180 x 130 x 100	PCM 150/100 T	MNX	31	180 x 180 x 125	PC 175/125 HT	MNX	24
180 x 130 x 100	PCM 150/100 XG	MNX	32	180 x 180 x 125	ABS 175/125 HG	MNX	24
180 x 130 x 100	PCM 150/100 XT	MNX	32	180 x 180 x 125	ABS 175/125 HT	MNX	24
180 x 130 x 125	PC 150/125 LG	MNX	21	180 x 180 x 125	PCM 175/125 G	MNX	33

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
180 x 180 x 125	PCM 175/125 T	MNX	33	190 x 190 x 180	EKHA 180 T-2FSH	EK	173
180 x 180 x 150	PC 175/150 HG	MNX	24	190 x 190 x 180	EKHS 180 G	EK	173
180 x 180 x 150	PC 175/150 HT	MNX	24	190 x 190 x 180	EKHS 180 G-2FSH	EK	173
180 x 180 x 150	ABS 175/150 HG	MNX	24	190 x 190 x 180	EKHS 180 T	EK	173
180 x 180 x 150	ABS 175/150 HT	MNX	24	190 x 190 x 180	EKHS 180 T-2FSH	EK	173
180 x 180 x 150	PCM 175/150 G	MNX	33	200 x 116 x 105	MCE PC 5 MF/M	MCE	165
180 x 180 x 150	PCM 175/150 T	MNX	33	200 x 120 x 75	PC 122008	EURONORD	118
187 x 122 x 90	TA191209	TEMPO	156	200 x 120 x 75	PCT 122008	EURONORD	118
187 x 122 x 90	TA191209T	TEMPO	156	200 x 120 x 75	AB 122008	EURONORD	118
188 x 160 x 106	PC 17/16-L3	CARDMASTER 208		200 x 120 x 90	PC 122009	EURONORD	118
188 x 160 x 106	PC 17/16-L3TT	CARDMASTER 208		200 x 120 x 90	PCT 122009	EURONORD	118
188 x 160 x 106	ABS 17/16-L3	CARDMASTER 208		200 x 120 x 90	AB 122009	EURONORD	118
188 x 160 x 106	ABS 17/16-L3TT	CARDMASTER 208		200 x 190 x 105	MCE PC 9 MF/M	MCE	166
188 x 160 x 134	PC 17/16-3	CARDMASTER 209		200 x 300 x 40	EKI 23/40G	SPACE LINK	197
188 x 160 x 134	PC 17/16-3TT	CARDMASTER 209		200 x 300 x 40	EKI 23/40T	SPACE LINK	197
188 x 160 x 134	ABS 17/16-3	CARDMASTER 209		200 x 300 x 130	EKI 23-2	SPACE LINK	197
188 x 160 x 134	ABS 17/16-3TT	CARDMASTER 209		200 x 300 x 130	EKI 23-4	SPACE LINK	197
188 x 188 x 130	PC 1919 13 G	SOLID	98	200 x 300 x 170	EKI 23-2-170 G	SPACE LINK	197
188 x 188 x 130	PC 1919 13 G-2FSH	SOLID	98	200 x 300 x 170	EKI 23-4-170 G	SPACE LINK	197
188 x 188 x 130	PC 1919 13 T	SOLID	98	200 x 300 x 170	EKI 23-2-170 T	SPACE LINK	197
188 x 188 x 130	PC 1919 13 T-2FSH	SOLID	98	200 x 300 x 170	EKI 23-4-170 T	SPACE LINK	197
188 x 188 x 130	ABS 1919 13 G	SOLID	98	201 x 151 x 80	PC 152008	EURONORD	120
188 x 188 x 130	ABS 1919 13 G-2FSH	SOLID	98	201 x 151 x 80	PCT 152008	EURONORD	120
188 x 188 x 130	ABS 1919 13 T	SOLID	98	201 x 151 x 80	AB 152008	EURONORD	120
188 x 188 x 130	ABS 1919 13 T-2FSH	SOLID	98	201 x 163 x 98	TA201610	TEMPO	157
188 x 188 x 130	FEX 1919 13 G	ATEX	219	201 x 163 x 98	TA201610T	TEMPO	157
188 x 188 x 130	FEX 1919 13 T	ATEX	219	213 x 185 x 90	PC 21/18-C3	CARDMASTER 210	
188 x 188 x 180	PC 1919 18 G	SOLID	98	213 x 185 x 90	ABS 21/18-C3	CARDMASTER 210	
188 x 188 x 180	PC 1919 18 G-2FSH	SOLID	98	213 x 185 x 102	PC 21/18-FC3	CARDMASTER 210	
188 x 188 x 180	PC 1919 18 T	SOLID	98	220 x 120 x 90	P 122209	EURONORD	135
188 x 188 x 180	PC 1919 18 T-2FSH	SOLID	98	220 x 120 x 90	PEX 122209	ATEX	220
188 x 188 x 180	ABS 1919 18 G	SOLID	98	222 x 125 x 81	ALN 122208	ALU	83
188 x 188 x 180	ABS 1919 18 G-2FSH	SOLID	98	222 x 125 x 81	ALX 122208	ATEX	218
188 x 188 x 180	ABS 1919 18 T	SOLID	98	230 x 80 x 65	PC F 65 G	PICCOLO	147
188 x 188 x 180	ABS 1919 18 T-2FSH	SOLID	98	230 x 80 x 65	PC F 65 T	PICCOLO	147
188 x 188 x 180	FEX 1919 18 G	ATEX	219	230 x 80 x 65	ABS F 65 G	PICCOLO	147
188 x 188 x 180	FEX 1919 18 T	ATEX	219	230 x 80 x 65	ABS F 65 T	PICCOLO	147
190 x 75 x 55	P 081906	EURONORD	133	230 x 80 x 85	PC F 85 G	PICCOLO	147
190 x 75 x 55	PEX 081906	ATEX	220	230 x 80 x 85	PC F 85 T	PICCOLO	147
190 x 190 x 30	EKH 30-G	EK	173	230 x 80 x 85	ABS F 85 G	PICCOLO	147
190 x 190 x 30	EKH 30-T	EK	173	230 x 80 x 85	ABS F 85 T	PICCOLO	147
190 x 190 x 80	EKH 80-G	EK	173	230 x 140 x 95	PC M 95 G	PICCOLO	149
190 x 190 x 80	EKH 80-T	EK	173	230 x 140 x 95	PC M 95 T	PICCOLO	149
190 x 190 x 100	EKHA	EK	173	230 x 140 x 95	ABS M 95 G	PICCOLO	149
190 x 190 x 100	EKHS	EK	173	230 x 140 x 95	ABS M 95 T	PICCOLO	149
190 x 190 x 130	EKHA 130 G	EK	173	230 x 140 x 125	PC MH 125 G	PICCOLO	149
190 x 190 x 130	EKHA 130 G-2FSH	EK	173	230 x 140 x 125	PC MH 125 T	PICCOLO	149
190 x 190 x 130	EKHA 130 T	EK	173	230 x 140 x 125	ABS MH 125 G	PICCOLO	149
190 x 190 x 130	EKHA 130 T-2FSH	EK	173	230 x 140 x 125	ABS MH 125 T	PICCOLO	149
190 x 190 x 130	EKHS 130 G	EK	173	230 x 200 x 110	ALN 232011	ALU	89
190 x 190 x 130	EKHS 130 G-2FSH	EK	173	230 x 200 x 180	AL 232018	ALU	89
190 x 190 x 130	EKHS 130 T	EK	173	235 x 185 x 119	PC 21/18-3	CARDMASTER 210	
190 x 190 x 130	EKHS 130 T-2FSH	EK	173	235 x 185 x 119	PC 21/18-3TT	CARDMASTER 210	
190 x 190 x 180	EKHA 180 G	EK	173	235 x 185 x 119	ABS 21/18-3	CARDMASTER 210	
190 x 190 x 180	EKHA 180 G-2FSH	EK	173	235 x 185 x 119	ABS 21/18-3TT	CARDMASTER 210	
190 x 190 x 180	EKHA 180 T	EK	173	240 x 191 x 107	TA241911	TEMPO	158

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
240 x 191 x 107	TA241911T	TEMPO	158	255 x 180 x 100	PCM 200/100 G	MNX	34
244 x 124 x 102	PC 122410	EURONORD	119	255 x 180 x 100	PCM 200/100 T	MNX	34
244 x 124 x 102	PCT 122410	EURONORD	119	255 x 180 x 100	PCM 200/100 XG	MNX	35
244 x 124 x 102	PCQ 122410	EURONORD	119	255 x 180 x 100	PCM 200/100 XT	MNX	35
244 x 124 x 102	PCTQ 122410	EURONORD	119	255 x 180 x 125	PC 200/125 XHG	MNX	26
244 x 124 x 102	AB 122410	EURONORD	119	255 x 180 x 125	PC 200/125 XHT	MNX	26
244 x 124 x 102	ABQ 122410	EURONORD	119	255 x 180 x 125	ABS 200/125 XHG	MNX	26
244 x 164 x 90	PC 162409	EURONORD	122	255 x 180 x 125	ABS 200/125 XHT	MNX	26
244 x 164 x 90	PCT 162409	EURONORD	122	255 x 180 x 125	PCM 200/125 XG	MNX	35
244 x 164 x 90	PCQ 162409	EURONORD	122	255 x 180 x 125	PCM 200/125 XT	MNX	35
244 x 164 x 90	PCTQ 162409	EURONORD	122	255 x 180 x 150	PC 200/150 HG	MNX	25
244 x 164 x 90	AB 162409	EURONORD	122	255 x 180 x 150	PC 200/150 HT	MNX	25
244 x 164 x 90	ABQ 162409	EURONORD	122	255 x 180 x 150	ABS 200/150 HG	MNX	25
244 x 164 x 120	PC 162412	EURONORD	122	255 x 180 x 150	ABS 200/150 HT	MNX	25
244 x 164 x 120	PCT 162412	EURONORD	122	255 x 180 x 150	PCM 200/150 G	MNX	34
244 x 164 x 120	PCQ 162412	EURONORD	122	255 x 180 x 150	PCM 200/150 T	MNX	34
244 x 164 x 120	PCTQ 162412	EURONORD	122	255 x 180 x 175	PC 200/175 XHG	MNX	26
244 x 164 x 120	AB 162412	EURONORD	122	255 x 180 x 175	PC 200/175 XHT	MNX	26
244 x 164 x 120	ABQ 162412	EURONORD	122	255 x 180 x 175	ABS 200/175 XHG	MNX	26
250 x 160 x 90	PC 162509	EURONORD	123	255 x 180 x 175	ABS 200/175 XHT	MNX	26
250 x 160 x 90	PCT 162509	EURONORD	123	255 x 180 x 175	PCM 200/175 XG	MNX	35
250 x 160 x 90	AB 162509	EURONORD	123	255 x 180 x 175	PCM 200/175 XT	MNX	35
250 x 160 x 125	PC 162513	EURONORD	123	256 x 251 x 121	P 252612	EURONORD	139
250 x 160 x 125	PCT 162513	EURONORD	123	256 x 251 x 121	PEX 252612	ATEX	220
250 x 160 x 125	AB 162513	EURONORD	123	257 x 219 x 122	PC 25/22-C3	CARDMASTER	211
250 x 160 x 150	PC 162515	EURONORD	123	257 x 219 x 122	ABS 25/22-C3	CARDMASTER	211
250 x 160 x 150	PCT 162515	EURONORD	123	257 x 219 x 135	PC 25/22-FC3	CARDMASTER	211
250 x 160 x 150	AB 162515	EURONORD	123	260 x 160 x 92	P 162609	EURONORD	137
252 x 81 x 57	AL 082506	ALU	81	260 x 160 x 92	PEX 162609	ATEX	220
252 x 81 x 57	ALX 082506	ATEX	218	263 x 162 x 91	ALN 162609	ALU	86
255 x 180 x 63	PC 200/63 HG	MNX	25	263 x 162 x 91	ALX 162609	ATEX	218
255 x 180 x 63	PC 200/63 HT	MNX	25	278 x 188 x 130	PC 2819 13 G	SOLID	99
255 x 180 x 63	ABS 200/63 HG	MNX	25	278 x 188 x 130	PC 2819 13 G-2FSH	SOLID	99
255 x 180 x 63	ABS 200/63 HT	MNX	25	278 x 188 x 130	PC 2819 13 T	SOLID	99
255 x 180 x 63	PCM 200/63 G	MNX	34	278 x 188 x 130	PC 2819 13 T-2FSH	SOLID	99
255 x 180 x 63	PCM 200/63 T	MNX	34	278 x 188 x 130	ABS 2819 13 G	SOLID	99
255 x 180 x 75	PC 200/75 HG	MNX	25	278 x 188 x 130	ABS 2819 13 G-2FSH	SOLID	99
255 x 180 x 75	PC 200/75 HT	MNX	25	278 x 188 x 130	ABS 2819 13 T	SOLID	99
255 x 180 x 75	ABS 200/75 HG	MNX	25	278 x 188 x 130	ABS 2819 13 T-2FSH	SOLID	99
255 x 180 x 75	ABS 200/75 HT	MNX	25	278 x 188 x 130	FEX 2819 13 G	ATEX	219
255 x 180 x 75	PCM 200/75 G	MNX	34	278 x 188 x 130	FEX 2819 13 T	ATEX	219
255 x 180 x 75	PCM 200/75 T	MNX	34	278 x 188 x 180	PC 2819 18 G	SOLID	99
255 x 180 x 88	PC 200/88 XHG	MNX	26	278 x 188 x 180	PC 2819 18 G-2FSH	SOLID	99
255 x 180 x 88	PC 200/88 XHT	MNX	26	278 x 188 x 180	PC 2819 18 T	SOLID	99
255 x 180 x 88	ABS 200/88 XHG	MNX	26	278 x 188 x 180	PC 2819 18 T-2FSH	SOLID	99
255 x 180 x 88	ABS 200/88 XHT	MNX	26	278 x 188 x 180	ABS 2819 18 G	SOLID	99
255 x 180 x 88	PCM 200/88 XG	MNX	35	278 x 188 x 180	ABS 2819 18 G-2FSH	SOLID	99
255 x 180 x 88	PCM 200/88 XT	MNX	35	278 x 188 x 180	ABS 2819 18 T	SOLID	99
255 x 180 x 100	PC 200/100 HG	MNX	25	278 x 188 x 180	ABS 2819 18 T-2FSH	SOLID	99
255 x 180 x 100	PC 200/100 HT	MNX	25	278 x 188 x 180	FEX 2819 18 G	ATEX	219
255 x 180 x 100	ABS 200/100 HG	MNX	25	278 x 188 x 180	FEX 2819 18 T	ATEX	219
255 x 180 x 100	ABS 200/100 HT	MNX	25	278 x 278 x 130	PC 2828 13 G	SOLID	101
255 x 180 x 100	PC 200/100 XHG	MNX	26	278 x 278 x 130	PC 2828 13 G-2FSH	SOLID	101
255 x 180 x 100	PC 200/100 XHT	MNX	26	278 x 278 x 130	PC 2828 13 T	SOLID	101
255 x 180 x 100	ABS 200/100 XHG	MNX	26	278 x 278 x 130	PC 2828 13 T-2FSH	SOLID	101
255 x 180 x 100	ABS 200/100 XHT	MNX	26	278 x 278 x 130	ABS 2828 13 G	SOLID	101

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
278 x 278 x 130	ABS 2828 13 G-2FSH	SOLID	101	300 x 200 x 170	CAB PCQ 302017 T	QUICK	186
278 x 278 x 130	ABS 2828 13 T	SOLID	101	300 x 200 x 170	CAB ABSQ 302017 G	QUICK	186
278 x 278 x 130	ABS 2828 13 T-2FSH	SOLID	101	300 x 200 x 170	CAB ABSQ 302017 T	QUICK	186
278 x 278 x 130	FEX 2828 13 G	ATEX	219	300 x 200 x 180	CAB PC 203018 G	CAB	65
278 x 278 x 130	FEX 2828 13 T	ATEX	219	300 x 200 x 180	CAB PC 302018 G	CAB	65
278 x 278 x 180	PC 2828 18 G	SOLID	101	300 x 200 x 180	CAB PC 302018 G3B	CAB	65
278 x 278 x 180	PC 2828 18 G-2FSH	SOLID	101	300 x 200 x 180	CAB PC 203018 T	CAB	65
278 x 278 x 180	PC 2828 18 T	SOLID	101	300 x 200 x 180	CAB PC 302018 T	CAB	65
278 x 278 x 180	PC 2828 18 T-2FSH	SOLID	101	300 x 200 x 180	CAB PC 302018 T3B	CAB	65
278 x 278 x 180	ABS 2828 18 G	SOLID	101	300 x 200 x 180	CAB ABS 203018 G	CAB	65
278 x 278 x 180	ABS 2828 18 G-2FSH	SOLID	101	300 x 200 x 180	CAB ABS 302018 G	CAB	65
278 x 278 x 180	ABS 2828 18 T	SOLID	101	300 x 200 x 180	CAB ABS 302018 G3B	CAB	65
278 x 278 x 180	ABS 2828 18 T-2FSH	SOLID	101	300 x 200 x 180	CAB ABS 203018 T	CAB	65
278 x 278 x 180	FEX 2828 18 G	ATEX	219	300 x 200 x 180	CAB ABS 302018 T	CAB	65
278 x 278 x 180	FEX 2828 18 T	ATEX	219	300 x 200 x 180	CAB ABS 302018 T3B	CAB	65
280 x 190 x 30	EKJ 30-G	EK	174	300 x 230 x 87	PC 233009	EURONORD	126
280 x 190 x 30	EKJ 30-T	EK	174	300 x 230 x 87	PCT 233009	EURONORD	126
280 x 190 x 80	EKJ 80-G	EK	174	300 x 230 x 87	AB 233009	EURONORD	126
280 x 190 x 80	EKJ 80-T	EK	174	300 x 230 x 110	PC 233011	EURONORD	126
280 x 190 x 100	EKJB	EK	174	300 x 230 x 110	PCT 233011	EURONORD	126
280 x 190 x 130	EKJB 130 G	EK	174	300 x 230 x 110	AB 233011	EURONORD	126
280 x 190 x 130	EKJB 130 G-2FSH	EK	174	300 x 300 x 40	EKI 33/40G	SPACE LINK	198
280 x 190 x 130	EKJB 130 T	EK	174	300 x 300 x 40	EKI 33/40T	SPACE LINK	198
280 x 190 x 130	EKJB 130 T-2FSH	EK	174	300 x 300 x 130	EKI 33-2	SPACE LINK	198
280 x 190 x 180	EKJB 180 G	EK	174	300 x 300 x 130	EKI 33-4	SPACE LINK	198
280 x 190 x 180	EKJB 180 G-2FSH	EK	174	300 x 300 x 170	CAB PCQ 303017 G	QUICK	187
280 x 190 x 180	EKJB 180 T	EK	174	300 x 300 x 170	CAB PCQ 303017 T	QUICK	187
280 x 190 x 180	EKJB 180 T-2FSH	EK	174	300 x 300 x 170	CAB ABSQ 303017 G	QUICK	187
280 x 190 x 180	EKMB 180 T	EK	175	300 x 300 x 170	CAB ABSQ 303017 T	QUICK	187
280 x 190 x 180	EKMB 180 T-2FSH	EK	175	300 x 300 x 170	EKI 33-2-170 G	SPACE LINK	198
280 x 192 x 110	DGP 281911	DG	152	300 x 300 x 170	EKI 33-4-170 G	SPACE LINK	198
280 x 192 x 110	DGM 281911	DG	152	300 x 300 x 170	EKI 33-2-170 T	SPACE LINK	198
280 x 192 x 110	DGA 281911	DG	152	300 x 300 x 170	EKI 33-4-170 T	SPACE LINK	198
280 x 219 x 156	PC 25/22-3	CARDMASTER	211	300 x 300 x 180	CAB PC 303018 G	CAB	66
280 x 219 x 156	PC 25/22-3TT	CARDMASTER	211	300 x 300 x 180	CAB PC 303018 G3B	CAB	66
280 x 219 x 156	ABS 25/22-3	CARDMASTER	211	300 x 300 x 180	CAB PC 303018 T	CAB	66
280 x 219 x 156	ABS 25/22-3TT	CARDMASTER	211	300 x 300 x 180	CAB PC 303018 T3B	CAB	66
280 x 230 x 110	ALN 232811	ALU	90	300 x 300 x 180	CAB ABS 303018 G	CAB	66
280 x 280 x 30	EKO 30-G	EK	176	300 x 300 x 180	CAB ABS 303018 G3B	CAB	66
280 x 280 x 30	EKO 30-T	EK	176	300 x 300 x 180	CAB ABS 303018 T	CAB	66
280 x 280 x 80	EKO 80-G	EK	176	300 x 300 x 180	CAB ABS 303018 T3B	CAB	66
280 x 280 x 80	EKO 80-T	EK	176	314 x 260 x 95	PC 30/25-C3	CARDMASTER	212
280 x 280 x 100	EKOE	EK	176	314 x 260 x 95	ABS 30/25-C3	CARDMASTER	212
280 x 280 x 130	EKOE 130 G	EK	176	314 x 260 x 110	PC 30/25-FC3	CARDMASTER	212
280 x 280 x 130	EKOE 130 G-2FSH	EK	176	315 x 215 x 170	CAB P 302017	CAB	53
280 x 280 x 130	EKOE 130 T	EK	176	320 x 260 x 129	PC 30/25-3	CARDMASTER	212
280 x 280 x 130	EKOE 130 T-2FSH	EK	176	320 x 260 x 129	PC 30/25-3TT	CARDMASTER	212
280 x 280 x 180	EKOE 180 G	EK	176	320 x 260 x 129	ABS 30/25-3	CARDMASTER	212
280 x 280 x 180	EKOE 180 G-2FSH	EK	176	320 x 260 x 129	ABS 30/25-3TT	CARDMASTER	212
280 x 280 x 180	EKOE 180 T	EK	176	330 x 230 x 110	ALN 233311	ALU	91
280 x 280 x 180	EKOE 180 T-2FSH	EK	176	330 x 230 x 180	ALN 233318	ALU	91
280 x 306 x 145	MCE PC 14 MF/M	MCE	167	340 x 150 x 101	PC 153410	EURONORD	121
280 x 306 x 145	MCE PC 14 MF/FL	MCE	167	340 x 150 x 101	PCT 153410	EURONORD	121
289 x 239 x 107	TA292411	TEMPO	159	340 x 150 x 101	PCQ 153410	EURONORD	121
289 x 239 x 107	TA292411T	TEMPO	159	340 x 150 x 101	PCTQ 153410	EURONORD	121
300 x 200 x 170	CAB PCQ 302017 G	QUICK	186	340 x 150 x 101	AB 153410	EURONORD	121

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
340 x 150 x 101	ABQ 153410	EURONORD	121	378 x 278 x 130	ABS 3828 13 G	SOLID	102
340 x 150 x 121	PC 153412	EURONORD	121	378 x 278 x 130	ABS 3828 13 G-2FSH	SOLID	102
340 x 150 x 121	PCT 153412	EURONORD	121	378 x 278 x 130	ABS 3828 13 T	SOLID	102
340 x 150 x 121	PCQ 153412	EURONORD	121	378 x 278 x 130	ABS 3828 13 T-2FSH	SOLID	102
340 x 150 x 121	PCTQ 153412	EURONORD	121	378 x 278 x 130	FEX 3828 13 G	ATEX	219
340 x 150 x 121	AB 153412	EURONORD	121	378 x 278 x 130	FEX 3828 13 T	ATEX	219
340 x 150 x 121	ABQ 153412	EURONORD	121	378 x 278 x 180	PC 3828 18 G	SOLID	102
344 x 289 x 117	TA342912	TEMPO	160	378 x 278 x 180	PC 3828 18 G-2FSH	SOLID	102
344 x 289 x 117	TA342912T	TEMPO	160	378 x 278 x 180	PC 3828 18 T	SOLID	102
360 x 160 x 90	ALN 163609	ALU	87	378 x 278 x 180	PC 3828 18 T-2FSH	SOLID	102
360 x 160 x 101	PC 163610	EURONORD	124	378 x 278 x 180	ABS 3828 18 G	SOLID	102
360 x 160 x 101	PCT 163610	EURONORD	124	378 x 278 x 180	ABS 3828 18 G-2FSH	SOLID	102
360 x 160 x 101	PCQ 163610	EURONORD	124	378 x 278 x 180	ABS 3828 18 T	SOLID	102
360 x 160 x 101	PCTQ 163610	EURONORD	124	378 x 278 x 180	ABS 3828 18 T-2FSH	SOLID	102
360 x 160 x 101	AB 163610	EURONORD	124	378 x 278 x 180	FEX 3828 18 G	ATEX	219
360 x 160 x 101	ABQ 163610	EURONORD	124	378 x 278 x 180	FEX 3828 18 T	ATEX	219
360 x 200 x 151	PC 203615	EURONORD	125	380 x 190 x 30	EKM 30-T	EK	175
360 x 200 x 151	PCT 203615	EURONORD	125	380 x 190 x 30	EKM 30-G	EK	175
360 x 200 x 151	PCQ 203615	EURONORD	125	380 x 190 x 80	EKM 80-T	EK	175
360 x 200 x 151	PCTQ 203615	EURONORD	125	380 x 190 x 80	EKM 80-G	EK	175
360 x 200 x 151	AB 203615	EURONORD	125	380 x 190 x 100	EKMB	EK	175
360 x 200 x 151	ABQ 203615	EURONORD	125	380 x 190 x 100	EKMR	EK	175
360 x 255 x 152	PC 300/150 ZG	MNX	27	380 x 190 x 130	EKMB 130 G	EK	175
360 x 255 x 152	PC 300/150 ZT	MNX	27	380 x 190 x 130	EKMB 130 G-2FSH	EK	175
360 x 255 x 152	ABS 300/150 ZG	MNX	27	380 x 190 x 130	EKMB 130 T	EK	175
360 x 255 x 152	ABS 300/150 ZT	MNX	27	380 x 190 x 130	EKMB 130 T-2FSH	EK	175
360 x 255 x 152	PCM 300/150 ZG	MNX	36	380 x 190 x 130	EKMR 130 G	EK	175
360 x 255 x 152	PCM 300/150 ZT	MNX	36	380 x 190 x 130	EKMR 130 G-2FSH	EK	175
361 x 160 x 91	P 163609	EURONORD	138	380 x 190 x 130	EKMR 130 T	EK	175
361 x 160 x 91	PEX 163609	ATEX	220	380 x 190 x 130	EKMR 130 T-2FSH	EK	175
362 x 125 x 81	AL 123608	ALU	84	380 x 190 x 180	EKMB 180 G	EK	175
362 x 125 x 81	ALX 123608	ATEX	218	380 x 190 x 180	EKMB 180 G-2FSH	EK	175
378 x 188 x 130	PC 3819 13 G	SOLID	100	380 x 190 x 180	EKMR 180 G	EK	175
378 x 188 x 130	PC 3819 13 G-2FSH	SOLID	100	380 x 190 x 180	EKMR 180 G-2FSH	EK	175
378 x 188 x 130	PC 3819 13 T	SOLID	100	380 x 190 x 180	EKMR 180 T	EK	175
378 x 188 x 130	PC 3819 13 T-2FSH	SOLID	100	380 x 190 x 180	EKMR 180 T-2FSH	EK	175
378 x 188 x 130	ABS 3819 13 G	SOLID	100	380 x 280 x 30	EKP 30-G	EK	177
378 x 188 x 130	ABS 3819 13 G-2FSH	SOLID	100	380 x 280 x 30	EKP 30-T	EK	177
378 x 188 x 130	ABS 3819 13 T	SOLID	100	380 x 280 x 30	EKP 30-G	EK	178
378 x 188 x 130	ABS 3819 13 T-2FSH	SOLID	100	380 x 280 x 30	EKP 30-T	EK	178
378 x 188 x 130	FEX 3819 13 G	ATEX	219	380 x 280 x 80	EKP 80-G	EK	177
378 x 188 x 130	FEX 3819 13 T	ATEX	219	380 x 280 x 80	EKP 80-T	EK	177
378 x 188 x 180	PC 3819 18 G	SOLID	100	380 x 280 x 80	EKP 80-G	EK	178
378 x 188 x 180	PC 3819 18 G-2FSH	SOLID	100	380 x 280 x 80	EKP 80-T	EK	178
378 x 188 x 180	PC 3819 18 T	SOLID	100	380 x 280 x 100	EKPE	EK	177
378 x 188 x 180	PC 3819 18 T-2FSH	SOLID	100	380 x 280 x 100	EKPG	EK	177
378 x 188 x 180	ABS 3819 18 G	SOLID	100	380 x 280 x 130	EKPE 130 G	EK	177
378 x 188 x 180	ABS 3819 18 G-2FSH	SOLID	100	380 x 280 x 130	EKPE 130 G-2FSH	EK	177
378 x 188 x 180	ABS 3819 18 T	SOLID	100	380 x 280 x 130	EKPE 130 T	EK	177
378 x 188 x 180	ABS 3819 18 T-2FSH	SOLID	100	380 x 280 x 130	EKPE 130 T-2FSH	EK	177
378 x 188 x 180	FEX 3819 18 G	ATEX	219	380 x 280 x 130	EKPG 130 G	EK	177
378 x 188 x 180	FEX 3819 18 T	ATEX	219	380 x 280 x 130	EKPG 130 G-2FSH	EK	177
378 x 278 x 130	PC 3828 13 G	SOLID	102	380 x 280 x 130	EKPG 130 T	EK	177
378 x 278 x 130	PC 3828 13 G-2FSH	SOLID	102	380 x 280 x 130	EKPG 130 T-2FSH	EK	177
378 x 278 x 130	PC 3828 13 T	SOLID	102	380 x 280 x 150	EKPK	EK	178
378 x 278 x 130	PC 3828 13 T-2FSH	SOLID	102	380 x 280 x 150	EKPL	EK	178

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
380 x 280 x 180	EKPE 180 G	EK	177	400 x 300 x 180	CAB ABS 403018 T3B	CAB	67
380 x 280 x 180	EKPE 180 G-2FSH	EK	177	400 x 300 x 230	CAB PCQ 403023 G	QUICK	188
380 x 280 x 180	EKPE 180 T	EK	177	400 x 300 x 230	CAB PCQ 403023 T	QUICK	188
380 x 280 x 180	EKPE 180 T-2FSH	EK	177	400 x 300 x 230	CAB ABSQ 403023 G	QUICK	188
380 x 280 x 180	EKPG 180 G	EK	177	400 x 300 x 230	CAB ABSQ 403023 T	QUICK	188
380 x 280 x 180	EKPG 180 G-2FSH	EK	177	400 x 300 x 230	EKI 43-4-230 G	SPACE LINK	199
380 x 280 x 180	EKPG 180 T	EK	177	400 x 300 x 230	EKI 43-5A-230 G	SPACE LINK	199
380 x 280 x 180	EKPG 180 T-2FSH	EK	177	400 x 300 x 230	EKI 43-4-230 T	SPACE LINK	199
380 x 280 x 180	EKPK 180 G	EK	178	400 x 300 x 230	EKI 43-5A-230 T	SPACE LINK	199
380 x 280 x 180	EKPK 180 G-2FSH	EK	178	400 x 360 x 151	AB 364015	EURONORD	127
380 x 280 x 180	EKPK 180 T	EK	178	400 x 360 x 151	ABQ 364015	EURONORD	127
380 x 280 x 180	EKPK 180 T-2FSH	EK	178	400 x 400 x 40	EKI 44/40G	SPACE LINK	200
380 x 280 x 180	EKPL 180 G	EK	178	400 x 400 x 40	EKI 44/40T	SPACE LINK	200
380 x 280 x 180	EKPL 180 G-2FSH	EK	178	400 x 400 x 130	EKI 44-4	SPACE LINK	200
380 x 280 x 180	EKPL 180 T	EK	178	400 x 400 x 170	CAB PCQ 404017 G	QUICK	189
380 x 280 x 180	EKPL 180 T-2FSH	EK	178	400 x 400 x 170	CAB PCQ 404017 T	QUICK	189
380 x 280 x 230	EKPK 230 G	EK	178	400 x 400 x 170	CAB ABSQ 404017 G	QUICK	189
380 x 280 x 230	EKPK 230 G-2FSH	EK	178	400 x 400 x 170	CAB ABSQ 404017 T	QUICK	189
380 x 280 x 230	EKPK 230 T	EK	178	400 x 400 x 170	EKI 44-4-170 G	SPACE LINK	200
380 x 280 x 230	EKPK 230 T-2FSH	EK	178	400 x 400 x 170	EKI 44-4-170 T	SPACE LINK	200
380 x 280 x 230	EKPL 230 G	EK	178	401 x 230 x 110	AL 234011	ALU	92
380 x 280 x 230	EKPL 230 G-2FSH	EK	178	401 x 230 x 180	ALN 234018	ALU	92
380 x 280 x 230	EKPL 230 T	EK	178	402 x 250 x 120	P 254012	EURONORD	140
380 x 280 x 230	EKPL 230 T-2FSH	EK	178	402 x 250 x 120	PEX 254012	ATEX	220
383 x 316 x 134	PC 36/31-C3	CARDMASTER 213		403 x 310 x 110	AL 314011	ALU	94
383 x 316 x 134	ABS 36/31-C3	CARDMASTER 213		403 x 310 x 180	ALN 314018	ALU	94
390 x 316 x 167	PC 36/31-3	CARDMASTER 213		406 x 401 x 120	P 404012	EURONORD	141
390 x 316 x 167	PC 36/31-3TT	CARDMASTER 213		406 x 401 x 120	PEX 404012	ATEX	220
390 x 316 x 167	ABS 36/31-3	CARDMASTER 213		415 x 315 x 170	CAB P 403017	CAB	54
390 x 316 x 167	ABS 36/31-3TT	CARDMASTER 213		415 x 315 x 170	CAB P 403017 T	CAB	54
400 x 300 x 40	EKI 43/40G	SPACE LINK	199	415 x 315 x 170	CAB P 403017 S	CAB	54
400 x 300 x 40	EKI 43/40T	SPACE LINK	199	430 x 306 x 145	MCE PC 28 MF/M	MCE	168
400 x 300 x 100	EKI 43/100G	SPACE LINK	199	430 x 306 x 145	MCE PC 28 MF/FL	MCE	168
400 x 300 x 100	EKI 43/100T	SPACE LINK	199	500 x 400 x 200	CAB PC 405020 G	CAB	68
400 x 300 x 130	EKI 43-2	SPACE LINK	199	500 x 400 x 200	CAB PC 504020 G	CAB	68
400 x 300 x 130	EKI 43-4	SPACE LINK	199	500 x 400 x 200	CAB PC 504020 G3B	CAB	68
400 x 300 x 130	EKI 43-5A	SPACE LINK	199	500 x 400 x 200	CAB PC 405020 T	CAB	68
400 x 300 x 170	CAB PCQ 403017 G	QUICK	188	500 x 400 x 200	CAB PC 504020 T	CAB	68
400 x 300 x 170	CAB PCQ 403017 T	QUICK	188	500 x 400 x 200	CAB PC 504020 T3B	CAB	68
400 x 300 x 170	CAB ABSQ 403017 G	QUICK	188	500 x 400 x 200	CAB ABS 405020 G	CAB	68
400 x 300 x 170	CAB ABSQ 403017 T	QUICK	188	500 x 400 x 200	CAB ABS 504020 G	CAB	68
400 x 300 x 170	EKI 43-4-170 G	SPACE LINK	199	500 x 400 x 200	CAB ABS 504020 G3B	CAB	68
400 x 300 x 170	EKI 43-5A-170 G	SPACE LINK	199	500 x 400 x 200	CAB ABS 405020 T	CAB	68
400 x 300 x 170	EKI 43-4-170 T	SPACE LINK	199	500 x 400 x 200	CAB ABS 504020 T	CAB	68
400 x 300 x 170	EKI 43-5A-170 T	SPACE LINK	199	500 x 400 x 200	CAB ABS 504020 T3B	CAB	68
400 x 300 x 180	CAB PC 304018 G	CAB	67	500 x 500 x 320	CAB PX 505032	CAB	42
400 x 300 x 180	CAB PC 403018 G	CAB	67	500 x 500 x 320	CAB PX 505032 T	CAB	42
400 x 300 x 180	CAB PC 403018 G3B	CAB	67	500 x 750 x 320	CAB PX 507532	CAB	43
400 x 300 x 180	CAB PC 304018 T	CAB	67	500 x 750 x 320	CAB PX 507532 T	CAB	43
400 x 300 x 180	CAB PC 403018 T	CAB	67	515 x 415 x 230	CAB P 504023	CAB	55
400 x 300 x 180	CAB PC 403018 T3B	CAB	67	515 x 415 x 230	CAB P 504023 T	CAB	55
400 x 300 x 180	CAB ABS 304018 G	CAB	67	515 x 415 x 230	CAB P 504023 S	CAB	55
400 x 300 x 180	CAB ABS 403018 G	CAB	67	558 x 278 x 130	PC 5628 13 G	SOLID	103
400 x 300 x 180	CAB ABS 403018 G3B	CAB	67	558 x 278 x 130	PC 5628 13 G-3FSH	SOLID	103
400 x 300 x 180	CAB ABS 304018 T	CAB	67	558 x 278 x 130	PC 5628 13 T	SOLID	103
400 x 300 x 180	CAB ABS 403018 T	CAB	67	558 x 278 x 130	PC 5628 13 T-3FSH	SOLID	103

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
558 x 278 x 130	ABS 5628 13 G	SOLID	103	600 x 400 x 170	EKI 64H-6	SPACE LINK	202
558 x 278 x 130	ABS 5628 13 G-3FSH	SOLID	103	600 x 400 x 170	EKI 64H-4EPA	SPACE LINK	202
558 x 278 x 130	ABS 5628 13 T	SOLID	103	600 x 400 x 210	CAB PCQ 604021 G	QUICK	191
558 x 278 x 130	ABS 5628 13 T-3FSH	SOLID	103	600 x 400 x 210	CAB PCQ 604021 T	QUICK	191
558 x 278 x 130	FEX 5628 13 G	ATEX	219	600 x 400 x 210	CAB ABSQ 604021 G	QUICK	191
558 x 278 x 130	FEX 5628 13 T	ATEX	219	600 x 400 x 210	CAB ABSQ 604021 T	QUICK	191
558 x 378 x 180	PC 5638 18 G	SOLID	104	600 x 400 x 210	EKI 64H-6-210 G	SPACE LINK	202
558 x 378 x 180	PC 5638 18 G-3FSH	SOLID	104	600 x 400 x 210	EKI 64H-4EPA-210 G	SPACE LINK	202
558 x 378 x 180	PC 5638 18 T	SOLID	104	600 x 400 x 210	EKI 64H-6-210 T	SPACE LINK	202
558 x 378 x 180	PC 5638 18 T-3FSH	SOLID	104	600 x 400 x 210	EKI 64H-4EPA-210 T	SPACE LINK	202
558 x 378 x 180	ABS 5638 18 G	SOLID	104	600 x 400 x 220	CAB PC 604022 G	CAB	69
558 x 378 x 180	ABS 5638 18 G-3FSH	SOLID	104	600 x 400 x 220	CAB PC 604022 G3B	CAB	69
558 x 378 x 180	ABS 5638 18 T	SOLID	104	600 x 400 x 220	CAB PC 604022 T	CAB	69
558 x 378 x 180	ABS 5638 18 T-3FSH	SOLID	104	600 x 400 x 220	CAB PC 604022 T3B	CAB	69
558 x 378 x 180	FEX 5638 18 G	ATEX	219	600 x 400 x 220	CAB ABS 604022 G	CAB	69
558 x 378 x 180	FEX 5638 18 T	ATEX	219	600 x 400 x 220	CAB ABS 604022 G3B	CAB	69
560 x 160 x 90	AL 165609	ALU	88	600 x 400 x 220	CAB ABS 604022 T	CAB	69
560 x 280 x 30	EKT 30-G	EK	179	600 x 400 x 220	CAB ABS 604022 T3B	CAB	69
560 x 280 x 30	EKT 30-T	EK	179	600 x 400 x 270	CAB PCQ 604027 G	QUICK	191
560 x 280 x 100	EKTH	EK	179	600 x 400 x 270	CAB PCQ 604027 T	QUICK	191
560 x 280 x 130	EKTH 130 G	EK	179	600 x 400 x 270	CAB ABSQ 604027 G	QUICK	191
560 x 280 x 130	EKTH 130 G-3FSH	EK	179	600 x 400 x 270	CAB ABSQ 604027 T	QUICK	191
560 x 280 x 130	EKTH 130 T	EK	179	600 x 400 x 270	EKI 64H-6-270 G	SPACE LINK	202
560 x 280 x 130	EKTH 130 T-3FSH	EK	179	600 x 400 x 270	EKI 64H-4EPA-270 G	SPACE LINK	202
560 x 380 x 30	EKU 30-G	EK	180	600 x 400 x 270	EKI 64H-6-270 T	SPACE LINK	202
560 x 380 x 30	EKU 30-T	EK	180	600 x 400 x 270	EKI 64H-4EPA-270 T	SPACE LINK	202
560 x 380 x 150	EKUM	EK	180	615 x 415 x 230	CAB P 604023	CAB	56
560 x 380 x 150	EKUH	EK	180	615 x 415 x 230	CAB P 604023 T	CAB	56
560 x 380 x 150	EKUN	EK	180	615 x 415 x 230	CAB P 604023 S	CAB	56
560 x 380 x 180	EKUH 180 G	EK	180	735 x 535 x 270	CAB P 705027	CAB	57
560 x 380 x 180	EKUH 180 G-3FSH	EK	180	735 x 535 x 270	CAB P 705027 T	CAB	57
560 x 380 x 180	EKUH 180 T	EK	180	735 x 535 x 270	CAB P 705027 S	CAB	57
560 x 380 x 180	EKUH 180 T-3FSH	EK	180	750 x 500 x 320	CAB PX 755032	CAB	43
560 x 380 x 180	EKUM 180 G	EK	180	750 x 500 x 320	CAB PX 755032 T	CAB	43
560 x 380 x 180	EKUM 180 G-3FSH	EK	180	750 x 750 x 320	CAB PX 757532	CAB	44
560 x 380 x 180	EKUM 180 T	EK	180	750 x 750 x 320	CAB PX 757532 T	CAB	44
560 x 380 x 180	EKUM 180 T-3FSH	EK	180	750 x 1000 x 320	CAB PX 7510032	CAB	45
560 x 380 x 180	EKUN 180 G	EK	180	750 x 1000 x 320	CAB PX 7510032 T	CAB	45
560 x 380 x 180	EKUN 180 G-3FSH	EK	180	750 x 1250 x 320	CAB PX 7512532-2D	CAB	46
560 x 380 x 180	EKUN 180 T	EK	180	750 x 1250 x 320	CAB PX 7512532-2DT	CAB	46
560 x 380 x 180	EKUN 180 T-3FSH	EK	180	760 x 560 x 100	EKW 100-G	EK	181
580 x 306 x 145	MCE PC 42 MF/M	MCE	169	760 x 560 x 150	EKWH	EK	181
580 x 306 x 145	MCE PC 42 MF/FL	MCE	169	760 x 560 x 250	EKWH 250 G	EK	181
600 x 230 x 110	AL 236011	ALU	93	835 x 635 x 300	CAB P 806030	CAB	58
600 x 300 x 40	EKI 63/40G	SPACE LINK	201	835 x 635 x 300	CAB P 806030 T	CAB	58
600 x 300 x 40	EKI 63/40T	SPACE LINK	201	835 x 635 x 300	CAB P 806030 S	CAB	58
600 x 300 x 130	EKI 63-6	SPACE LINK	201	1000 x 500 x 320	CAB PX 1005032	CAB	47
600 x 300 x 170	CAB PCQ 603017 G	QUICK	190	1000 x 500 x 320	CAB PX 1005032 T	CAB	47
600 x 300 x 170	CAB PCQ 603017 T	QUICK	190	1000 x 750 x 320	CAB PX 1007532	CAB	45
600 x 300 x 170	EKI 63-6-170 G	SPACE LINK	201	1000 x 750 x 320	CAB PX 1007532 T	CAB	45
600 x 300 x 170	EKI 63-6-170 T	SPACE LINK	201	1000 x 1000 x 320	CAB PX 10010032	CAB	48
600 x 310 x 110	ALN 316011	ALU	95	1000 x 1000 x 320	CAB PX 10010032-2D	CAB	48
600 x 400 x 40	EKI 64/40G	SPACE LINK	202	1000 x 1000 x 320	CAB PX 10010032-2DT	CAB	48
600 x 400 x 40	EKI 64/40T	SPACE LINK	202	1000 x 1250 x 320	CAB PX 10012532-2D	CAB	49
600 x 400 x 100	EKI 64/100G	SPACE LINK	202	1000 x 1250 x 320	CAB PX 10012532-2DT	CAB	49
600 x 400 x 100	EKI 64/100T	SPACE LINK	202	1035 x 835 x 300	CAB P 1008030	CAB	59

Enclosure index

Dimensions	Order symbol	Product family	Page	Dimensions	Order symbol	Product family	Page
1035 x 835 x 300	CAB P 1008030 T	CAB	59				
1035 x 835 x 300	CAB P 1008030 S	CAB	59				
1250 x 750 x 320	CAB PX 1257532	CAB	46				
1250 x 750 x 320	CAB PX 1257532 T	CAB	46				
1250 x 1000 x 320	CAB PX 12510032-2D	CAB	49				
1250 x 1000 x 320	CAB PX 12510032-2DT	CAB	49				
1250 x 1000 x 320	CAB PX 12510032-2C	CAB	49				
1250 x 1000 x 320	CAB PX 12510032-2CT	CAB	49				

Enclosure index

Dimensions	Order symbol	Product family	Page
------------	--------------	----------------	------

Dimensions	Order symbol	Product family	Page
------------	--------------	----------------	------