



INDUSTRIAL GRADE CLEANERS, DESIGNED FOR THE TOUGHEST APPLICATIONS.  
**50% QUIETER THAN BEFORE, WITH EVERY FUNCTION YOU WILL EVER NEED..**




MECHANISIMS & PARTS

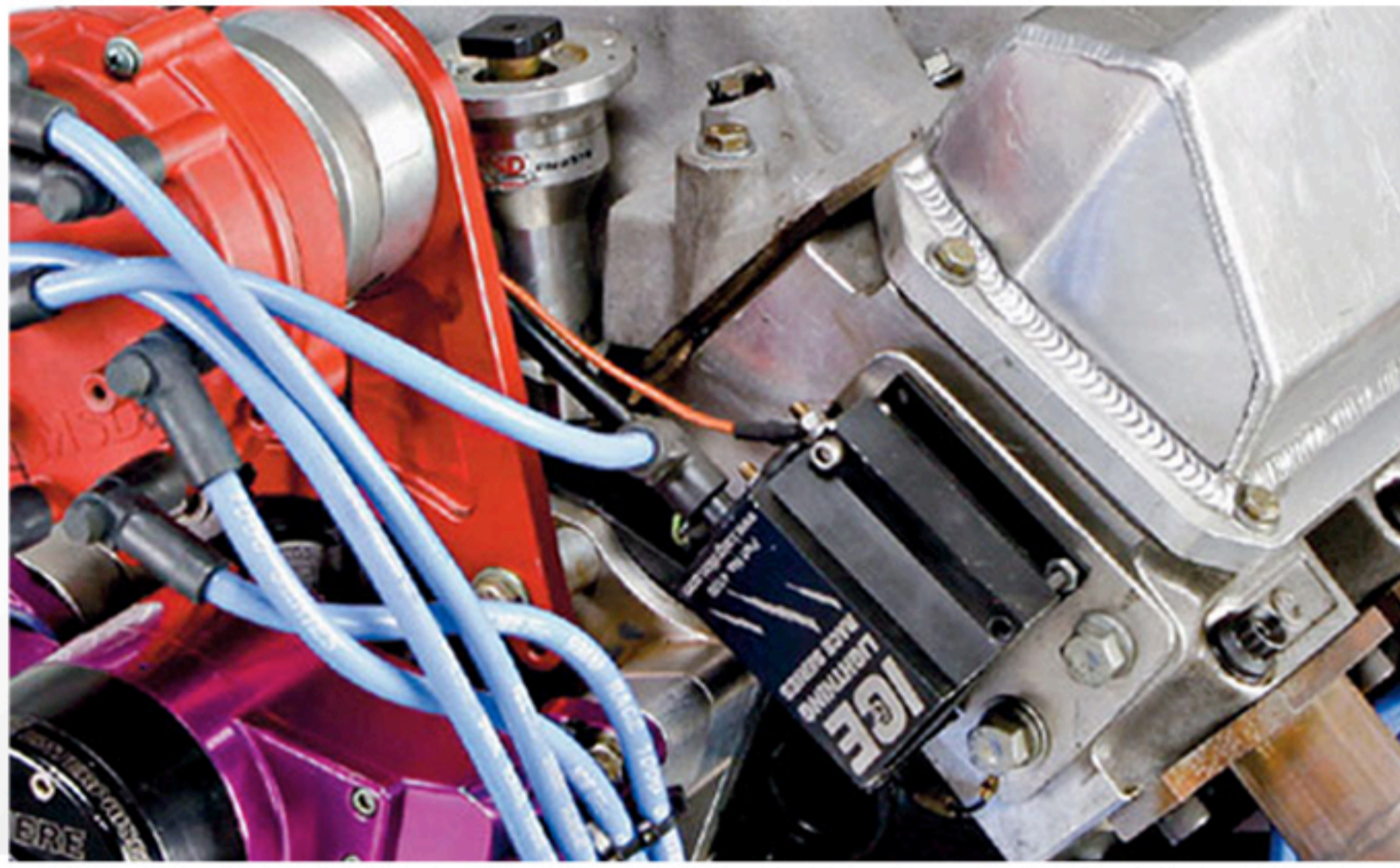

LAB & DENTAL EQUIPMENT

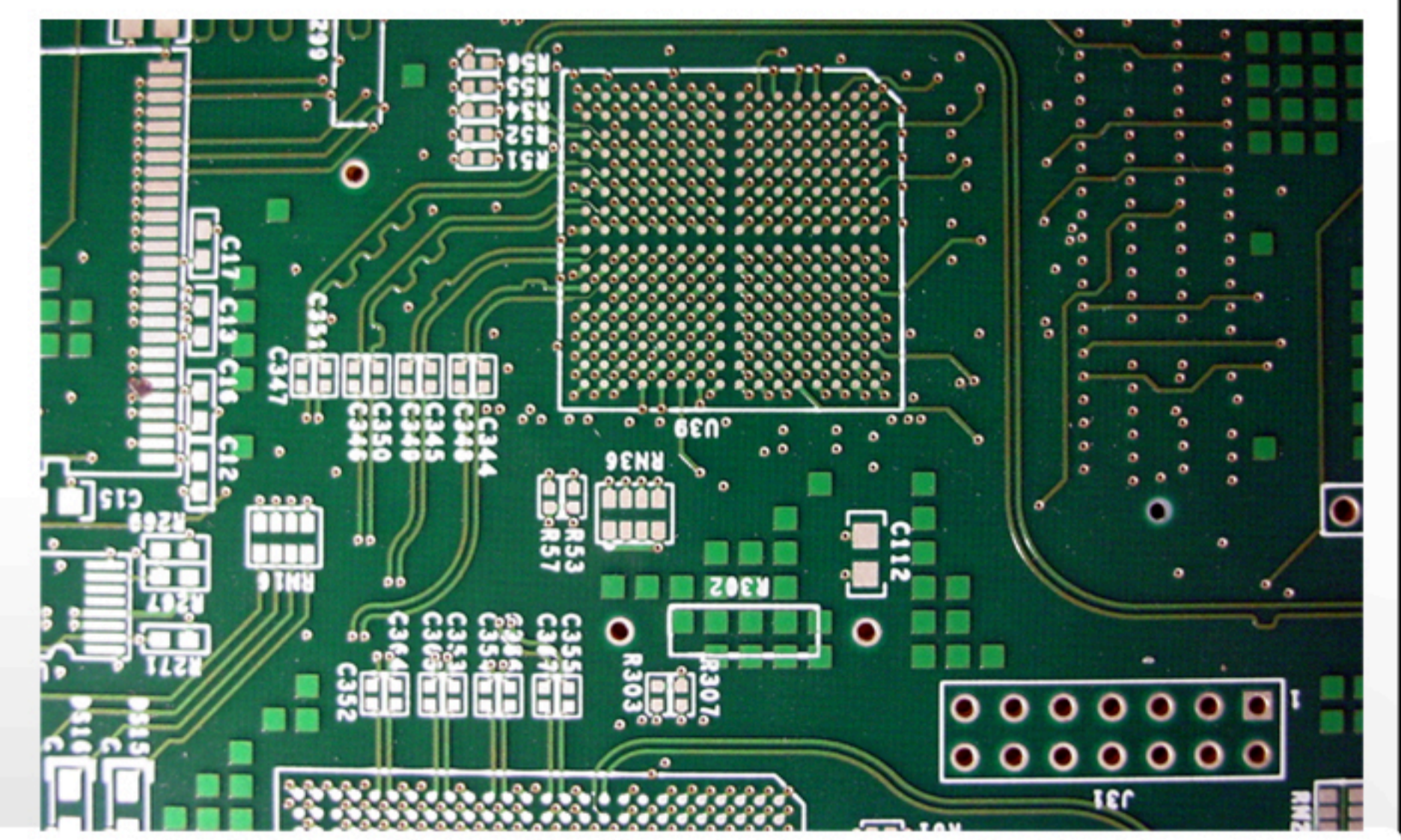

PCB & COMPONENTS

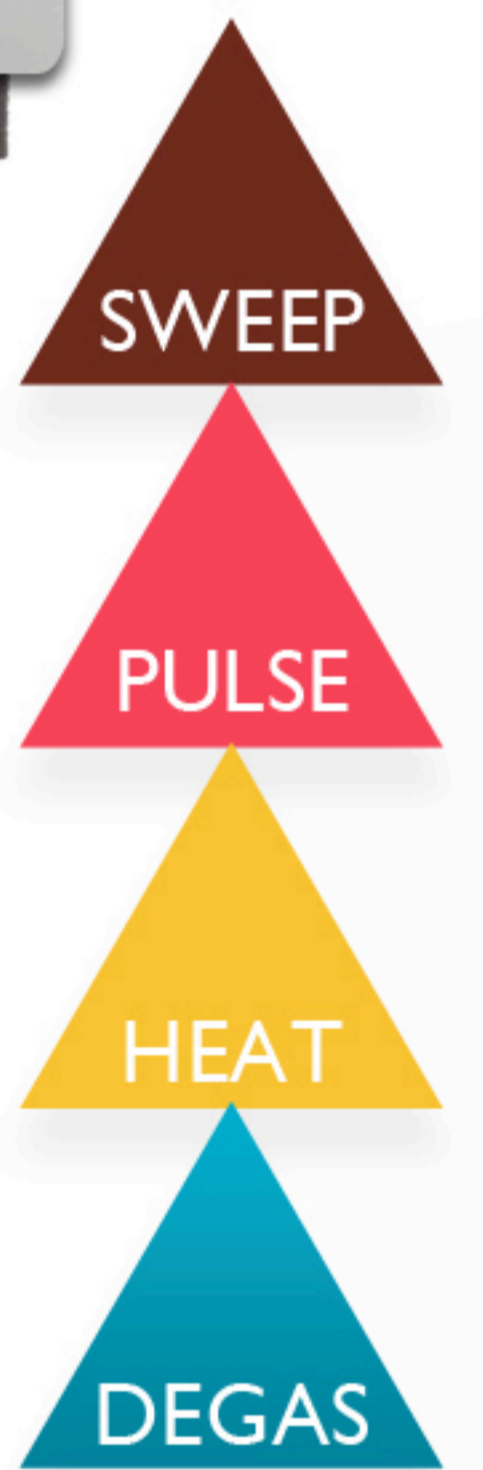

**AS STANDARD ACROSS ALL MODELS IN THIS RANGE**

- BUILT IN HEATER • 304 GRADE STAINLESS STEEL • SEALED ELECTRONICS • SMART LCD DISPLAY
- ULTRA QUIET OPERATION • STAINLESS STEEL BASKET & LID INCLUDED
- QUICK START MEMORY • 2 YEARS WARRANTY

Model	3D	4D	6D	3MX	4.5MX	6MX
Volume Size	3	4	6	3	4.5	6
Tank Internal Dimension	238 x 138 x 100	302 x 152 x 100	302 x 152 x 150	238 x 138 x 100	238 x 138 x 150	302 x 152 x 150
Operation Frequency	40	40	40	37	37	37
Ultrasonic Power	120	120	180	160	160	240
Drainage Tap			✓			✓
Degas	✓	✓	✓	✓	✓	✓



**SEACLEAN2 SOLUTION**  
**2X THE CLEANING POWER**

The ultimate green cleaner, SeaClean2 concentrate will assist the removal of tarnish and dirt from most items to return them to a shiny condition. When used with an ultrasonic cleaner, the cleaning process should take only minutes, removing the need for soaking. Made from a unique formula containing natural products, mixing carefully balanced quantities of seaweed, coconut oils & other fruit extract to create a powerful cleaning solution.