



ECF504 Series

Network Rating: Category 3
Color: Ivory
Gold Plating: 30 microinches
Flammability Rating: 94V-0

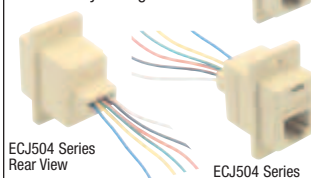



ECJ504 Series

 Color: Ivory
Gold Plating: 30 microinches
Flammability Rating: 94V-0



ECF504B Series

Network Rating: Category 3
Color: Black
Gold Plating: 50 microinches
Flammability Rating: 94V-0

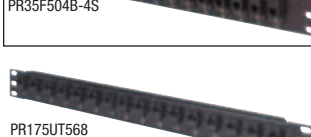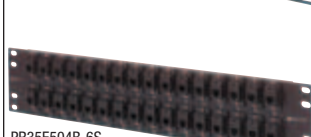

Item #	Description	Color	1-9	10-24	25-99	100-249	250-499
✓RoHS Deluxe Panel Mounted Modular Couplers, 30 Microinches Gold, Ivory Color							
These straight and cross wired modular couplers are available exclusively from L-com. Eight different configurations all fit into the same 0.675" (1.7cm) x 0.900" (2.3cm) rectangular opening. Wire contacts have 30 microinch gold plating for multiple insertions. Plastic is 94V-0 rated. Color: Ivory. Flange accepts #4 or #5 mounting screws to be purchased separately. Category 3 rated.							
ECF504-4C	Modular Coupler, RJ11 (6x4), Crossed, 30µ	Ivory	3.75	3.67	3.52	3.30	2.81
ECF504-6C	Modular Coupler, RJ12 (6x6), Crossed, 30µ	Ivory	3.95	3.87	3.71	3.48	2.96
ECF504-8C	Modular Coupler, RJ45 (8x8), Crossed, 30µ	Ivory	4.95	4.85	4.65	4.36	3.71
ECF504-4S	Modular Coupler, RJ11 (6x4), Straight, 30µ	Ivory	3.75	3.67	3.52	3.30	2.81
ECF504-6S	Modular Coupler, RJ12 (6x6), Straight, 30µ	Ivory	3.95	3.87	3.71	3.48	2.96
ECF504-6SMJ	Modular Coupler, MMJ (6x6), Straight, 30µ	Ivory	3.95	3.87	3.71	3.48	2.96
ECF504-8SK	Modular Coupler, RJ45 (8x8K), Straight, 30µ	Ivory	4.95	4.85	4.65	4.36	3.71
ECF440	Machine Screws, 4-40 x 5/16", Pkg/100		4.35	4.00	3.65	3.31	2.96

✓RoHS Deluxe Panel Mounted Modular Jacks - 10" Wire Leads, 30 Microinches Gold, Ivory Color

One difficulty in using modular jacks is the mounting problem on a panel. L-com's solution to this problem is providing a flange that mounts with two screws in a 0.675" (1.7cm) x 0.900" (2.3cm) rectangular opening. Choice of RJ11/12 (6x6) or RJ45 (8x8K) usable with keyed or non-keyed plugs. Custom versions of other jack types considered in quantities of 500/up. Mounting screws must be purchased separately.

ECJ504-6	Modular Panel Jack, RJ12 (6x6) / Wires, 30µ	Ivory	3.95	3.87	3.71	3.48	2.96
ECJ504-8	Modular Panel Jack, RJ45K (8x8K) / Wires, 30µ	Ivory	4.29	4.20	4.03	3.78	3.22
ECF440	Machine Screws, 4-40 x 5/16", Pkg/100		4.35	4.00	3.65	3.31	2.96

✓RoHS Deluxe Panel Mounted Couplers, 50 Microinches Gold, Black Color

These couplers are similar to the ECF504 Series with two changes. The molding has been changed to a Black color for applications when Ivory is not wanted. Also, the contacts have 50 microinches of gold for superior mating with modular plugs. Mounting screws must be purchased separately. Category 3 rated.

ECF504B-4S	Modular Coupler, RJ11 (6x4), Straight, 50µ	Black	3.75	3.67	3.52	3.30	2.81
ECF504B-6S	Modular Coupler, RJ12 (6x6), Straight, 50µ	Black	3.95	3.87	3.71	3.48	2.96
ECF504B-8SK	Modular Coupler, RJ45K (8x8K), Straight, 50µ	Black	4.95	4.85	4.65	4.36	3.71
ECF440	Machine Screws, 4-40 x 5/16", Pkg/100		4.35	4.00	3.65	3.31	2.96

✓RoHS 19" (48.3cm) Patch Panels - Equipped with 16 or 32 ECF504 Series Modular Couplers


These 19" (48.3cm) patch panels utilize the ECF504 series couplers. For your convenience, two panel heights are offered; 1.75" (4.4cm) with 16 modular adapters or 3.50" (8.9cm) with 32 modular adapters. Panel legend is 1-16 or 1-32. Color: Bone. Available with straight-thru wiring.

PR175F504B-6S	1.75" (4.4cm) 16 Port Panel RJ12 (6x6), Straight-Thru	Black	82.95	76.31	69.68	63.04	CALL
PR175F504B-8SK	1.75" (4.4cm) 16 Port Panel RJ45 (8x8), Straight, Keyed	Black	89.95	82.75	75.56	68.36	CALL
PR35F504B-6S	3.50" (8.9cm) 32 Port Panel RJ12 (6x6), Straight-Thru	Black	144.95	133.35	121.76	110.16	CALL
PR35F504B-8SK	3.50" (8.9cm) 32 Port Panel RJ45 (8x8), Straight, Keyed	Black	169.95	156.35	142.76	129.16	CALL

✓RoHS 19" (48.3cm) Modular Patch Panels - Equipped with 16 or 32 ECF504B Modular Couplers

These panels utilize the ECF504B couplers with 50 microinch plating. 16 and 32 port available. Straight thru pinned only. Color: Black.

PR175F504B-4S	1.75" (4.4cm) 16 Port Panel RJ11 (6x4), Straight-Thru	Black	74.95	68.95	62.96	56.96	CALL
PR175F504B-6S	1.75" (4.4cm) 16 Port Panel RJ12 (6x6), Straight-Thru	Black	82.95	76.31	69.68	63.04	CALL
PR175F504B-8SK	1.75" (4.4cm) 16 Port Panel RJ45 (8x8), Straight, Keyed	Black	89.95	82.75	75.56	68.36	CALL
PR35F504B-4S	3.50" (8.9cm) 32 Port Panel RJ11 (6x4), Straight-Thru	Black	129.95	119.55	109.16	98.76	CALL
PR35F504B-6S	3.50" (8.9cm) 32 Port Panel RJ12 (6x6), Straight-Thru	Black	144.95	133.35	121.76	110.16	CALL
PR35F504B-8SK	3.50" (8.9cm) 32 Port Panel RJ45 (8x8), Straight, Keyed	Black	169.95	156.35	142.76	129.16	CALL

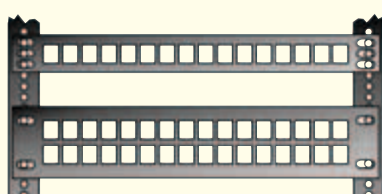How Rack Spaces and Sizes are Measured

Racks are a great way to neaten up wiring closets and labs. Network equipment and rack panels usually come in 1.75" (4.4cm), 3.5" (8.9cm) and 5.25" (13.3cm) heights. (1, 2 and 3 rack spaces).

✓RoHS Premium Keystone Style - 16 and 32 Port Feed-Thru Modular Panels, Category 5E Rated

These 19" (48.3cm) rack panels utilize the UJ5T568 and UJ5T568S couplers. 16 and 32 port versions available in shielded and unshielded configurations. Category 5E rated. Color: Black.

PR175UT568	1.75" (4.4cm) 16 Port Cat. 5E Feed-Thru Panel, Unshielded	Black	179.95	165.55	151.16	136.76	CALL
PR175UT568S	1.75" (4.4cm) 16 Port Cat. 5E Feed-Thru Panel, Shielded	Black	199.95	183.95	167.96	151.96	CALL
PR35UT568	3.50" (8.9cm) 32 Port Cat. 5E Feed-Thru Panel, Unshielded	Black	299.95	275.95	251.96	227.96	CALL
PR35UT568S	3.50" (8.9cm) 32 Port Cat. 5E Feed-Thru Panel, Shielded	Black	379.95	349.55	319.16	288.76	CALL

✓RoHS Keystone Style - 16 and 32 Port Feed-Thru Modular Panels - Category 6 Rated

These rack panels utilize the TDG1026KC6 or TDG1026KS-C6 Category 6 couplers. 16 and 32 port versions are available in shielded and unshielded configurations. Color: Black.

PR175C6-16	1.75" (4.4cm) 16 Port Cat. 6 Feed-Thru Panel, Unshielded	Black	189.95	174.75	159.56	144.36	CALL
PR175C6-16S	1.75" (4.4cm) 16 Port Cat. 6 Feed-Thru Panel, Shielded	Black	239.95	220.75	201.56	182.36	CALL
PR35C6-32	3.50" (8.9cm) 32 Port Cat. 6 Feed-Thru Panel, Unshielded	Black	319.95	294.35	268.76	243.16	CALL
PR35C6-32S	3.50" (8.9cm) 32 Port Cat. 6 Feed-Thru Panel, Shielded	Black	369.95	340.35	310.76	281.16	CALL

✓RoHS Right Angle Keystone Style - 16 and 32 Port Feed-Thru Modular Panels - Category 5E Rated

Unique, high speed network patching is made easy with L-com's right angle Keystone coupler patch panels. L-com's low-profile, 90 degree Keystone couplers are pre-installed into standard 19" rack panels, providing an easy method for addressing tight fit applications. These couplers offer a true 90 Degree exit from the cable entry point.

PR175R5E-16	1.75" (4.4cm) 16 Port, RA, Cat. 5E Feed-Thru Panel, Unshielded	Black	129.98	119.58	109.18	98.78	CALL
PR175SR5E-16	1.75" (4.4cm) 16 Port, RA, Cat. 5E Feed-Thru Panel, Shielded	Black	149.98	137.98	125.98	113.98	CALL
PR35R5E-32	3.50" (8.9cm) 32 Port, RA, Cat. 5E Feed-Thru Panel, Unshielded	Black	229.98	211.58	193.18	174.78	CALL
PR35SR5E-32	3.50" (8.9cm) 32 Port, RA, Cat. 5E Feed-Thru Panel, Shielded	Black	254.98	234.58	214.18	193.78	CALL

