

- Replacement for incandescent 40 W
- Up to 85% energy saving
- Lifetime of 30,000 hrs
- An energy efficient LED solution for general lighting.
It is the ideal light source for all fields of application of 40 W lamps.



Order Code 52112

General Data

Lamp Socket	E27
Design	Frosted

Geometric Data

Length (mm)	112
Diameter (mm)	60
Weight (g)	155

Electric Data

Wattage (W)	7.3
Voltage (V)	220-240
Power Factor	≥ 0.90
Operating Frequency (Hz)	50-60

Photometric Data

Luminous Flux (lm)	480
CRI	≥ 80
CCT (K)	3000 – warm white
Luminous Intensity (cd)	-
Beam Angle (°)	-
Lifetime (hrs)	30,000


Switching cycle	20,000
-----------------	--------

Wattage Equivalent (W)	40
------------------------	----

E27



ø60 mm

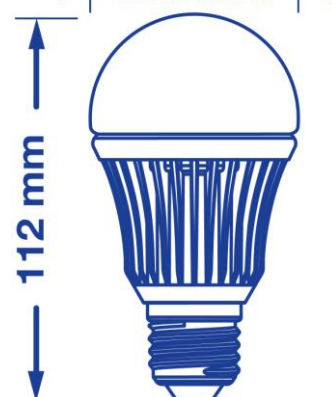



Order Code

52112

Product Description

LED CLASSIC A E27 7.3W 3000K WW 480LM Blister

Technical Packaging Details

Barcode	023942521129
EAN 128	(02)00023942521129(37)04(91)204
EAN 14	50023942521124
Pack Dimensions (HxWxL)	198 mm x 118 mm x 61 mm
Pack Weight	162 g
Carton Qty (Shipping Unit)	4
Carton Dimensions (HxWxL)	208 mm x 135 mm x 248 mm
Cartons/Layer	24
Layers/Pallet	4
Units/Pallet	384

Photometric Diagram

52112

