



PHG.2B.307.CLLD92Z

MECHANICAL DETAILS

Shell Style Model PH* : Free receptacle
cable collet and nut for fitting a
bend relief


Keying 1 key (alpha=0, plug: male
contacts, receptacle: female
contacts)

Housing Material Brass (chrome plated) shell and
collet nut, nickel plated brass
latch sleeve and mid pieces

Cable Fixing 8.3 - 9.2 mm

Variant 2 Z : Nut for fitting a bend relief

	A	L	S1	S2
Mm.	16.5	47	13	12
In.	0.65	1.85	0.51	0.47

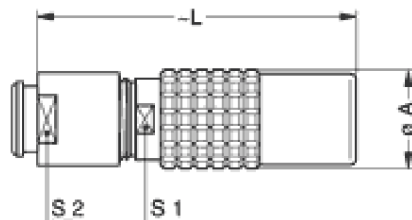

Available Download

[unipole_multipole.pdf](#)

PERFORMANCE DETAIL

Insert 2B.307 : 7 Low Voltage

Insulator L: PEEK

Specifications

Contact Type: Solder

Max. Matings: 5000


Contact Dia.: 1.3 mm (0.051in)

Bucket Dia.: 1 mm (0.039in)

Max. Solid 0.5 mm² (AWG 20)

Max. Stranded 0.5 mm² (AWG 20)

R (max): 3.6 mOhm

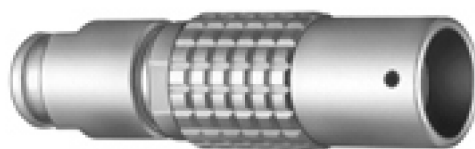

OTHER CHARACTERISTICS

Shell Style/Model Libellé

Humidity (max): <=95% [at 60 deg C /140 F]

Vibration: 15 g [10 Hz - 2000 Hz]

Shock Resistance: 100 g [6 ms]


Salt Spray >144 hr

Climatical 50/175/21

Shielding (min): 75 dB (10 MHz)

Shielding (min): 40 dB (1 GHz)

IP Rating 50

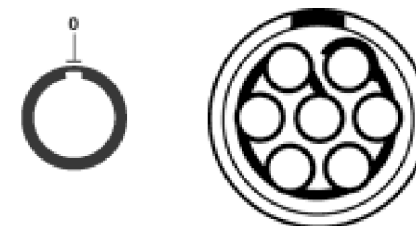

Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)