



PRG.M0.2GL.LC52G

MECHANICAL DETAILS

Shell Style Model PR* : Free receptacle with cable collet


Keying 1 key (alpha=0; Plug: male contact; Receptacle: female contact)

Housing Material PSU (Polysulfone), gray

Cable Fixing 4 - 5.2 mm

Variant 2 G : Gray collet nut

	A	L
Mm.	14	40
In.	0.55	1.57

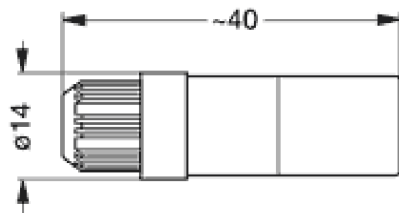

Available Download

 [P_series_catalog.pdf](#)

PERFORMANCE DETAIL

Insert 1P.M02 : 2 Low Voltage

Insulator

Insulator



OTHER CHARACTERISTICS

Shell Style/Model Libellé

F ret (min): 50 N

F ret (max): 150 N

IP Rating 50



Related links

-  [Contact](#)
-  [Quote Request](#)
-  [Catalogs Downloads](#)
-  [Catalogs Requests](#)
-  [Sample Request](#)
-  [3D drawings](#)