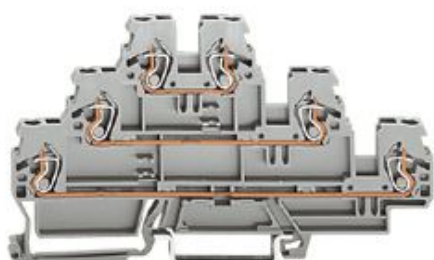

Item no.: 870-551
Product description: TRIPLE DECK TERMINAL BLOCK
THROUGH/THROUGH/THROUGH L/L/L Housing color: gray



Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Product group	16 (RAIL MOUNTED TERMINAL BLOCK WITH CCC)
Number of levels	3
Cross section [mm ²]	0.08 - 2.5 mm ²
Cross section [AWG]	28 - 14 AWG
Wiring method	e+f
Connection method	CAGE CLAMP® COMPACT CONNECTION
Cross section [mm ²]	0.08 - 4 mm ²
Cross section [AWG]	28 - 12 AWG
Wiring method	f
Connection method	CAGE CLAMP® COMPACT CONNECTION
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	24 A
Weight	17 g
Color	gray
Wiring type	Front-entry
No. of connection Points	6

No. of potentials	3
Height	52.5 mm
Height	2.07 in
Width	5 mm



Width	0.197 in
Depth	106 mm
Depth	4.17 in
Strip length from	6 mm
Strip length to	7 mm
Strip length	0.26 in
Mounting	TS 35



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm²]
870-551	ABS	05-HG476175/3-PDA	500	24	2,5
870-551	BV	07436/Co	500	24	2,5
870-551	CCA	NL6826	500	24	2,5
870-551	cURus	E45172	300	20/5	28-12
870-551	DNV	E-9214	500	24	2,5
870-551	GL	17295-00HH	500	24	2,5
870-551	KEMA	2143311.01	500	24	2,5
870-551	LR	91/20112(E6)	500	24	2,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected