

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

09-50-3041

Status:


Active

Overview:

KK® Interconnection System

Description:

3.96mm Pitch KK® Crimp Terminal Housing, Friction Ramp, 4 Circuits

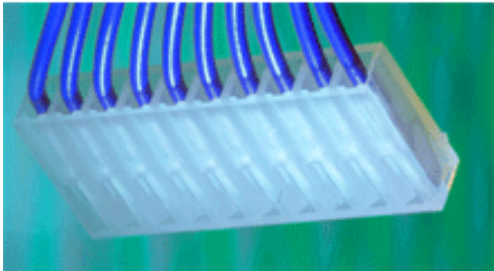

Series

image - Reference only

Documents:

- 3D Model

Packaging Specification PK-2139-001 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-08-50 (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

2139

Application

Power, Wire-to-Board

MolexKits

Yes

Overview

KK® Interconnection System

Product Name

KK®

UPC

800753614024

Physical

Circuits (maximum)

4

Color - Resin

Natural

Flammability

94V-2

Gender

Female

Glow-Wire Compliant

No

Lock to Mating Part

Yes

Material - Resin

Nylon

Net Weight

1.040/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

3.96mm

Temperature Range - Operating

See Product Specification

Material Info

Old Part Number

2139-4A

Reference - Drawing Numbers

Packaging Specification

PK-2139-001

Product Specification

PS-08-50

Sales Drawing

SD-2139

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

2139Series

Use With

2478 Crimp Terminals for 18-24 AWG, 2578 Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION