

- Replacement for 50W PAR16 halogen lamp
- Up to 85% energy saving
- Dimmable
- Lifetime of 35,000 hrs
- Suitable replacement for halogen or incandescent spots. Perfectly highlights the corridors, stairwells, at home and in hospitality areas.



Order Code 52049

#### General Data

Lamp Socket GU10

Design Lens

#### Geometric Data

Length (mm) 58

Diameter (mm) 50

Weight (g) 50

#### Electric Data

Wattage (W) 7

Voltage (V) 220-240

Power Factor  $\geq 0.90$

Operating Frequency (Hz) 50-60

#### Photometric Data

Luminous Flux (lm) 370

CRI  $\geq 80$

CCT (K) 2700 – warm white


Luminous Intensity (cd) 850

Beam Angle (°) 35

Lifetime (hrs) 35,000

Switching cycle 18,000

Wattage Equivalent (W) 50

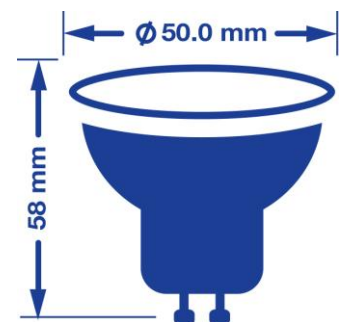



<b>Order Code</b>	52049
<b>Product Description</b>	LED PAR16 GU10 7W 2700K WW 370LM DIM

#### Technical Packaging Details

Barcode	023942520498
EAN 128	(02)00023942520498(37)40(91)162
EAN 14	50023942520493
Pack Dimensions (HxWxL)	62 mm x 50 mm x 50 mm
Pack Weight	77 g
Carton Qty (Shipping Unit)	10
Carton Dimensions (HxWxL)	285 mm x 140 mm x 60 mm
Cartons/Pallet	51
Layers/Pallet	6
Units/Pallet	2040

**Photometric Diagram**

52049

