


## Type H-LL heavy duty, long lip

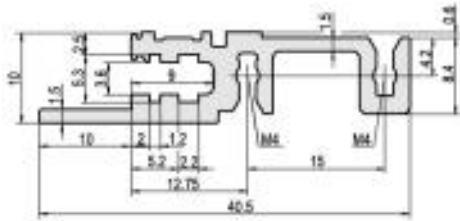

Product illustrations are exemplary illustrations and can deviate from supplied products.

**Part no.:**  
**34560-**  
**384**

**Features:**

- Long lip (H-LL)
- For plug-in units with IEEE handle
- For CPCI and VME64x systems
- Installation at top and bottom

**Standard pack quantity 10**



**Technical information:**

Description	Usable length	Length	Qty/PU
Type H-LL heavy duty, long lip	84 HP	431,8 mm	1 piece

**Delivery comprises:**

Item	Qty	Description
1	1	Horizontal rail, aluminium extrusion, anodised, conductive contact surfaces

**Accessories:**

Part no.	Description	
<b>24571-372</b>	Torx panhead screws M4 × 10, St, zinc-plated, required if guide rail is screwed to slot 1, PU 100 pieces	
<b>24560-155</b>	Countersunk screw with torx M4 x 10, St, zinc-plated; required where guide rail is bolted to slot 1; PU 100 pieces	
<b>24560-130</b>	Panhead screw with torx M4 × 14, St, zinc- plated, PU 100 pieces	

**Note:**

- Delivery is in standard pack multiples. Pricing is per individual item