



The worldwide leader in thermal management solutions.

[News](#) [About Us](#) [Contact Us](#) [Global Manufacturing](#) [Shop Aavid](#)

[Products](#)

[Solutions](#)

[Industries](#)

[Submit Query](#)

[Your Account](#) [Logout](#) [Cart](#)

[Knowledge Center](#)

[Design Help](#)

322400B00000G

TO-18



QTY IN STOCK: 5,790

ENTER QTY:

[VIEW PRICE](#)

Low cost push on heat sink

Cross Reference: 2224B
Height: 5.84
Mount Orientation: Vertical
Finish: Black Anodize
RoHS: compliant
[Download PCN](#)

Thermal Resistance: 99.99

Need assistance?

Call us: 1-855-32-AAVID
 Email: estore@aavid.com

[» Help Page](#)

Check Distributor Stock

Enter a part number for pricing and availability.



[go!](#)

Learn More

- [>Request a Sample](#)
- [>Request a Quote](#)
- [>Ask an Engineer](#)

The Fine Print

- [Product Return Policy](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

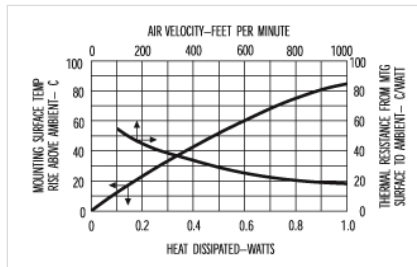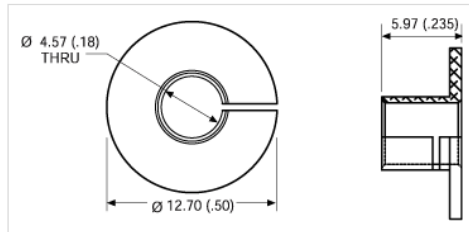

Customer Assistance

- [Contact Us](#)
- [Get Design Assistance](#)
- [Find a Distributor](#)
- [Find a Sales Rep](#)
- [Request a Quote](#)
- [Placing an Order](#)
- [Terms and Conditions](#)
- [Returns](#)

Popular Products

- [Fans](#)
- [Extrusions](#)
- [Board Level](#)
- [Liquid Cooling](#)
- [Heat Pipe Technology](#)
- [Heat Sink Accessories](#)
- [Interface Materials](#)

Our Company

- [News and Events](#)
- [Management Team](#)
- [Worldwide Locations](#)
- [Directions to Headquarters](#)
- [Disclaimer](#)
- [Customer Survey](#)
- [Privacy Policy](#)

Connect with Aavid

Sign up for Aavid News & Alerts

[GO!](#)

Like / Follow / Connect



© Copyright 2013 Aavid Thermalloy, LLC.

USA: 1.855.32.AAVID Europe: 39.051.764002 Asia: 86.21.6115.2000 x 8122