




PRODUCT SPECIFICATION

Controlled Document - Engineering Drive

CATALOG NUMBER: See table below
DESCRIPTION: POLAR/SOLAR Plus™ SJEOOW extension cord with power indicator light in the cord connector
APPROVALS: UL Listed and CSA Certified (16-12 ga) Outdoor Use Cord Set

CONSTRUCTION PARAMETERS:

Conductor: See table below
 Cable jacket material: TPE, yellow
 Overall cable O.D. (nom): See table below
 Cord rating: Hard Usage per the National Electrical Code
 Cable legend type: Indent print

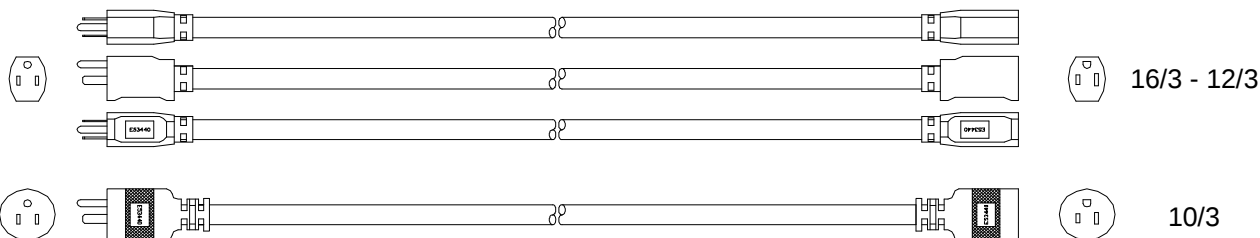

Attachment plug configuration: NEMA 5-15P
 Cord connector configuration: NEMA 5-15R
 Plug and connector material: Clear PVC, with neon power indicator lamp in the cord connector

ELECTRICAL AND ENVIRONMENTAL PROPERTIES:

Cable temperature rating: -50 to +105 °C
 Nominal operating voltage: 125 VAC
 Maximum operating current: See table below

Catalog no.	Gauge	Length	Conductor	Cable O.D.	Current rating
01284	16/3	10 ft	26/30 BC	0.316 in	13A
01287		25 ft			
01288		50 ft			10A
01289		100 ft			
01484	14/3	10 ft	41/30 BC	0.352 in	15A
01487		25 ft			
01488		50 ft			13A
01489		100 ft			
01687	12/3	25 ft	65/30 BC	0.420 in	15A
01688		50 ft			
01689		100 ft			
01787	10/3	25 ft	104/30 BC	0.567 in	
01788		50 ft			
01789		100 ft			

This product complies with European Directive 2011/65/EU (RoHS-2)

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Inc. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Inc.