







Product Sheet

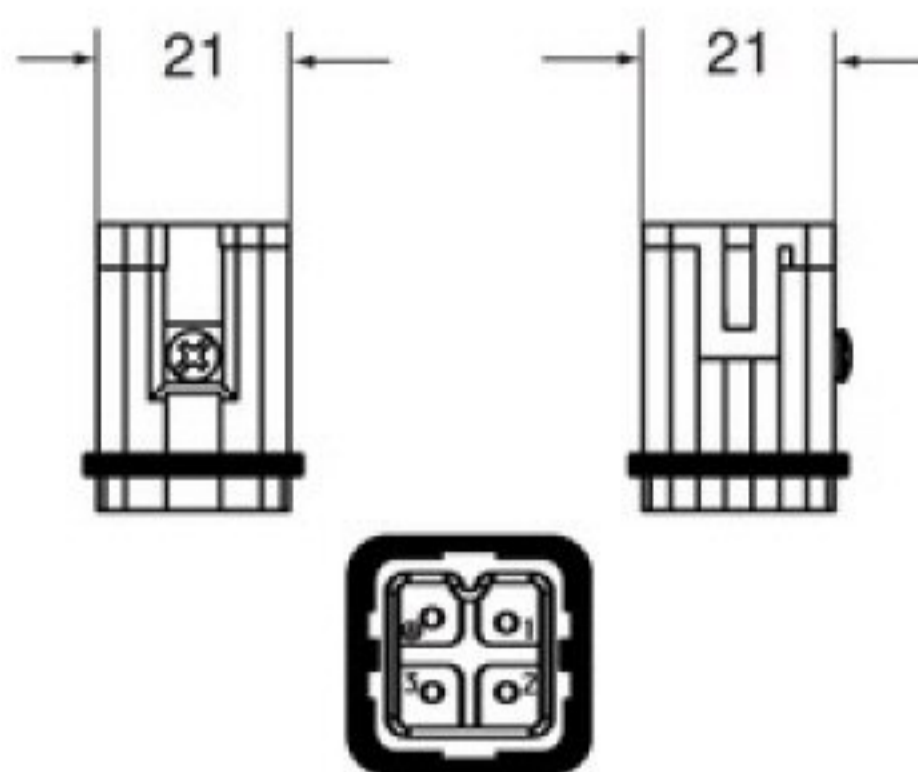

www.ilme.com

Part Number: CKSM 03



Family	inserts
Version	spring terminal connections
Series	CKS
Product type	with male contacts
Execution	white colour coded
Model	male insert
Reference standard	EN 61984 (2001-11)
Contact type	silver plated
No. of poles	3 poles + 
Voltage (V)	400V
Current (A)	10A (A.C./D.C.)
Wire section	0,14mm ² - 2,5mm ²
Awg size	26 - 14
Quality mark	 600V   GOST 
IP degree of protection	IP20 degree of protection without enclosure, IP44, IP66 / IP67 and IP68 with enclosure (EN 60529)
Fixing centre distance	size "21.21"
Impulse withstand voltage	4kV
Pollution degree	3

The information and the dimensions contained are not binding and may be changed without prior notice.
The drawing's dimensions are in mm.