

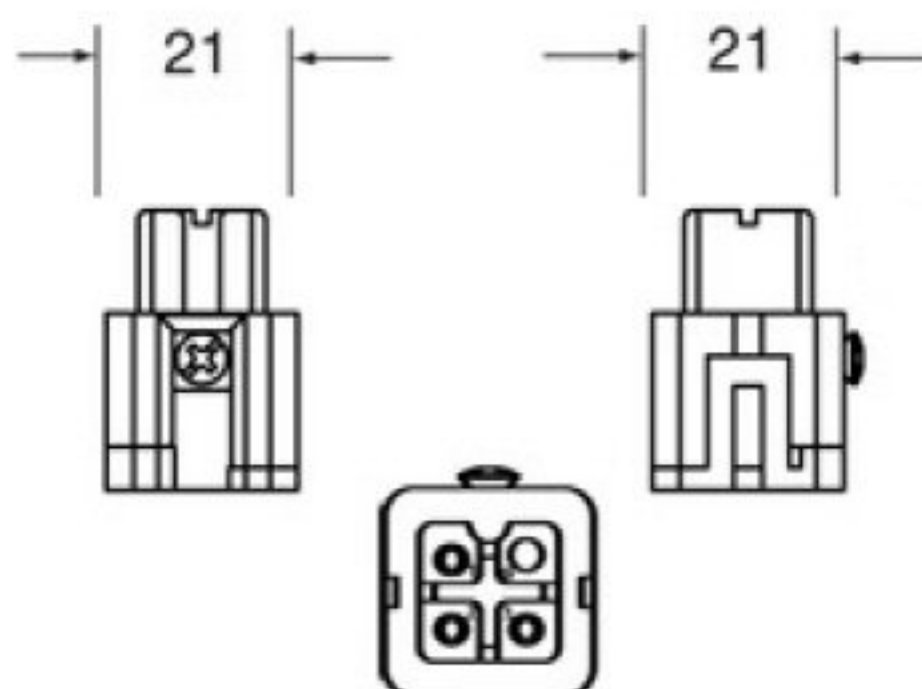
# Product Sheet








www.ilme.com

Part Number:

CKSF 03



|                                  |   |
|----------------------------------|---|
| <b>Family</b>                    | inserts   |
| <b>Version</b>                   | spring terminal connections   |
| <b>Series</b>                    | CKS   |
| <b>Product type</b>              | with female contacts  |
| <b>Execution</b>                 | white colour coded  |
| <b>Model</b>                     | female insert   |
| <b>Reference standard</b>        | EN 61984 (2001-11)  |
| <b>Contact type</b>              | silver plated   |
| <b>No. of poles</b>              | 3 poles +    |
| <b>Voltage (V)</b>               | 400V  |
| <b>Current (A)</b>               | 10A (A.C./D.C.)   |
| <b>Wire section</b>              | 0,14mm <sup>2</sup> - 2,5mm <sup>2</sup>  |
| <b>Awg size</b>                  | 26 - 14   |
| <b>Quality mark</b>              |  600V   GOST  |
| <b>IP degree of protection</b>   | IP20 degree of protection without enclosure, IP44, IP66 / IP67 and IP68 with enclosure (EN 60529)   |
| <b>Fixing centre distance</b>    | size "21.21"  |
| <b>Impulse withstand voltage</b> | 4kV   |
| <b>Pollution degree</b>          | 3   |

The information and the dimensions contained are not binding and may be changed without prior notice.  
The drawing's dimensions are in mm.