


# Product Sheet






Part Number:

CKSF 04

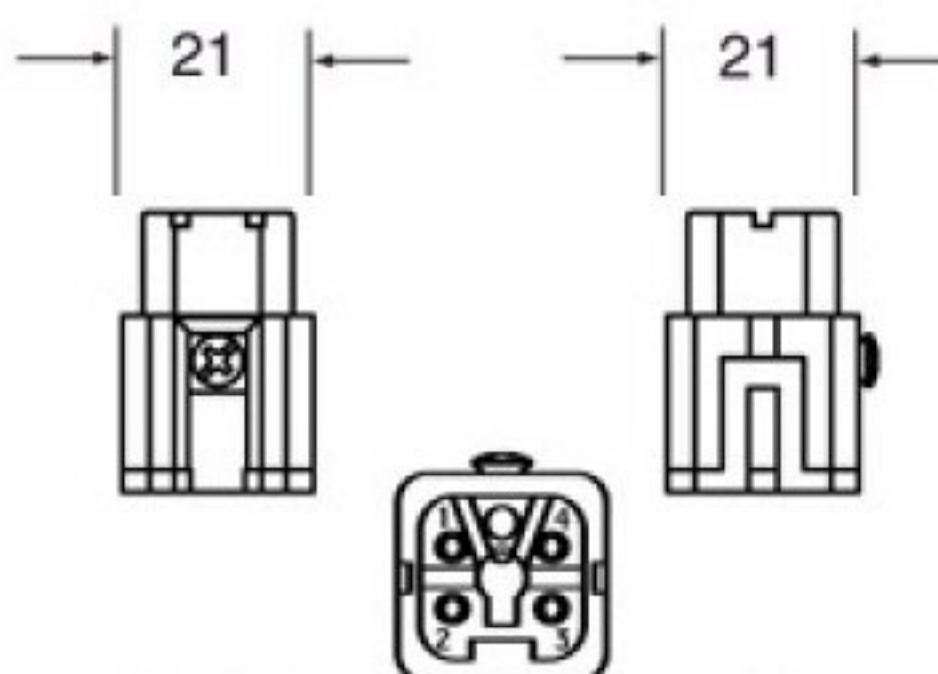

www.ilme.com



<b>Family</b>	inserts
<b>Version</b>	spring terminal connections
<b>Series</b>	CKS
<b>Product type</b>	with female contacts
<b>Execution</b>	white colour coded
<b>Model</b>	female insert
<b>Reference standard</b>	EN 61984 (2001-11)
<b>Contact type</b>	silver plated
<b>No. of poles</b>	4 poles + 
<b>Voltage (V)</b>	400V
<b>Current (A)</b>	10A (A.C./D.C.)
<b>Wire section</b>	0,14mm <sup>2</sup> - 2,5mm <sup>2</sup>
<b>Awg size</b>	26 - 14
<b>Quality mark</b>	 600V   GOST 
<b>IP degree of protection</b>	IP20 degree of protection without enclosure, IP44, IP66 / IP67 and IP68 with enclosure (EN 60529)
<b>Fixing centre distance</b>	size "21.21"
<b>Impulse withstand voltage</b>	4kV
<b>Pollution degree</b>	3

The information and the dimensions contained are not binding and may be changed without prior notice.  
The drawing's dimensions are in mm.