





Product Sheet



Part Number: MKAX VG20

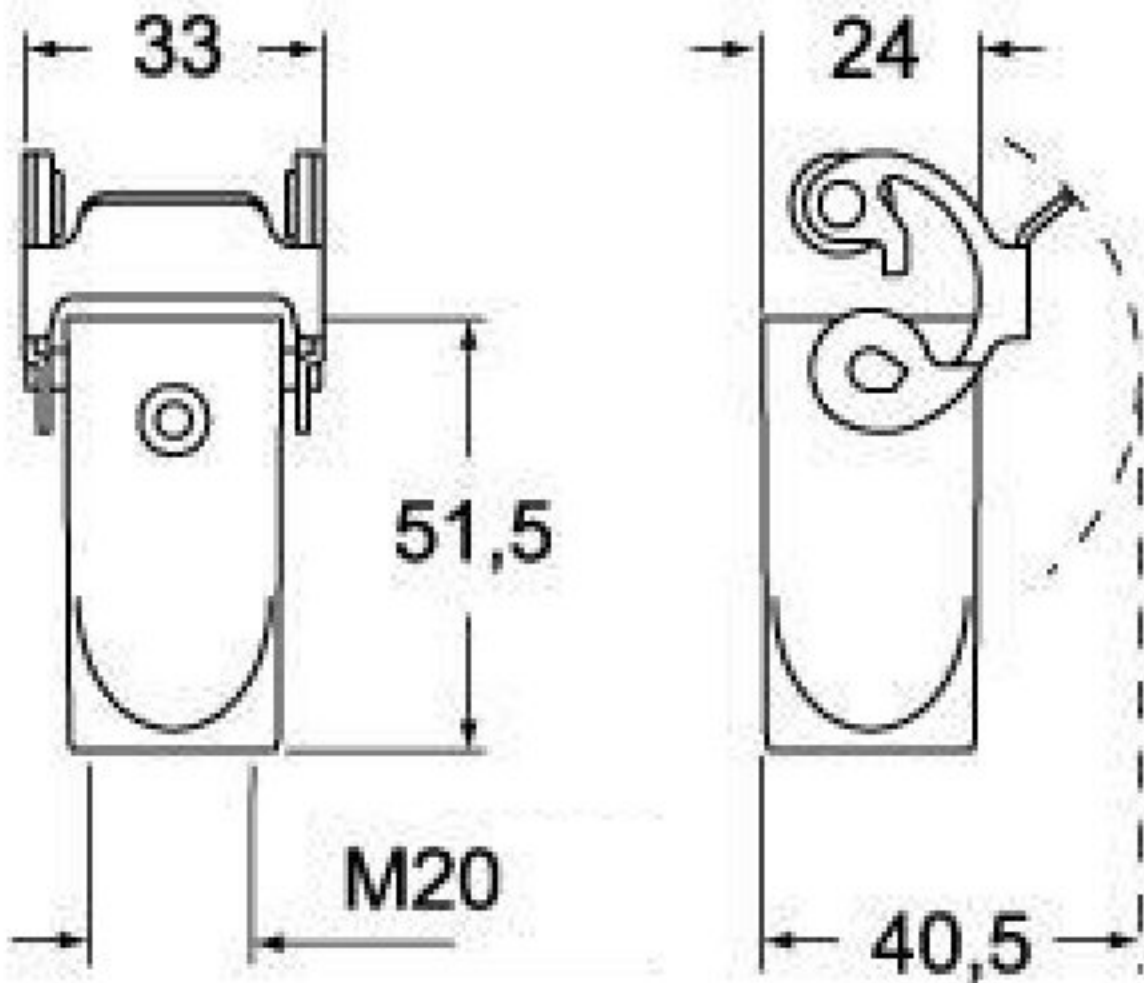

| | |
|-------------------------|---|
| Family | CK and MK enclosures |
| Version | metal version |
| Series | Hoods with single lever |
| Product type | with stainless steel lever |
| Type | top entry |
| Quality mark | C [®]  US type: 12,(type 4/4X only with kit CKR 65 or CKR 65 D),   |
| IP degree of protection | IP44 (EN 60529) degree of protection, IP66/67 degree of protection with CKR 65 kit or CKR 65 D kit. |
| Cable entry | M20 |
| Fixing centre distance | size "21.21" |
| Material | metal |

The information and the dimensions contained are not binding and may be changed without prior notice.
The drawing's dimensions are in mm.