

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [50133-8000](#)
Status: **Active**
Overview: [PicoBlade™](#)
Description: 1.25mm Pitch PicoBlade™ Crimp Terminal, Male, 28-32 AWG, Reel

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-51021-009 \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	50133
Application	Signal
Crimp Quality Equipment	Yes
Overview	PicoBlade™
Product Name	PicoBlade™
UPC	800753576131

Physical

Gender	Male
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	40.000/mg
Packaging Type	Reel
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-1.00mm
Wire Size AWG	28, 30, 32
Wire Size mm²	N/A

Electrical

Current - Maximum per Contact	0.8A, 1A
Voltage - Maximum	125V

Material Info

Reference - Drawing Numbers

Product Specification	PS-51021-009, RPS-51021-033, RPS-51021-110
Sales Drawing	SD-50133-8*00

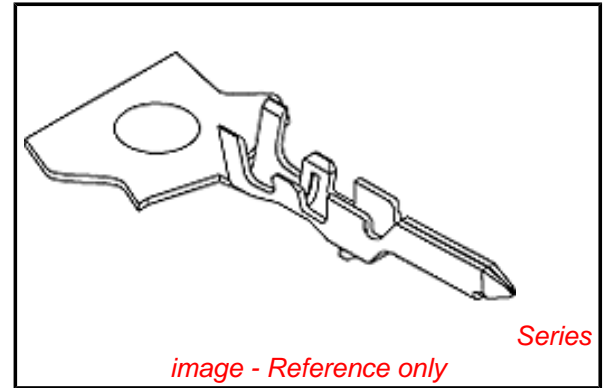


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[50133Series](#)

Mates With

[50058 Crimp Terminal](#), [50079 Crimp Terminal](#)

Use With

[51047 Crimp Housing](#)

Application Tooling | [FAQ](#)

*Tooling specifications and manuals are
 found by selecting the products below.
 Crimp Height Specifications are then
 contained in the Application Tooling
 Specification document.*

Global

Description	Product #
Extraction Tool	0011030043
T2 Terminator	0639104200
Tooling Die	
Hand Crimp Tool for 1.25mm Pitch Crimp	0638190400

Terminals, 26-32
AWG Wire
FineAdjust™ 0639004200
Applicator for
1.25mm Pitch Board
In, Wire-to-Board
and Wire-to-Wire
Terminal, 26-32
AWG

Japan	
Description	Product #
Extraction Tool	<u>0570726000</u>
Applicator for M21 1A	<u>0571383000</u>
Bench Press, 26-32	
AWG Wire	
Side-Feed Applicator	<u>0571383200</u>
For Full-Auto Machine	

This document was generated on 04/05/2013

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION