

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19007-0073
Status: Active
Description: InsulKrimp™ Female Fully Insulated Quick Disconnect Flag for 14-16 AWG Wire, Tab 6.35 x 0.81mm, 94 V-0 Material

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-008 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E79133

General

Product Family Quick Disconnects
Series 19007
Crimp Quality Equipment Yes
Product Name InsulKrimp™
Type Quick Disconnect
UPC 800756384818

Physical

Barrel Type Closed
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Resin Nylon
Net Weight 1.234/g
Orientation Flag
Packaging Type Bag
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -65°C to +105°C
Wire Insulation Diameter 5.08mm
Wire Size AWG 14, 16
Wire Size mm² 1.00 - 2.60

Electrical


Voltage - Maximum 600V

Material Info

Old Part Number BB-2221V

Reference - Drawing Numbers

Product Specification PS-19902-008, PS-19902-011, PS-19902-013
Sales Drawing SD-19007-002

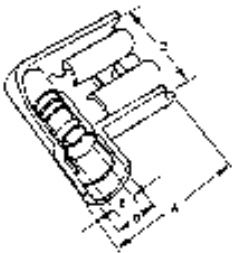

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19007Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	0640014100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640054100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION