

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51111-0300](#)
Status: **Active**
Description: 2.50mm Pitch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Retainer, 3 Circuits

Documents:

3D Model	Product Specification PS-51111-003 (PDF)
Drawing (PDF)	Packaging Specification SPK-51111-001 (PDF)
Product Specification PS-51111-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	51111
Application	Signal, Wire-to-Board, Wire-to-Wire
Product Name	N/A
UPC	800754307871


Physical

Circuits (maximum)	3
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Net Weight	573.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-51111-001
Product Specification	PS-51111-001, PS-51111-003, RPS-51111-005, RPS-51111-007
Sales Drawing	SD-51111-**00

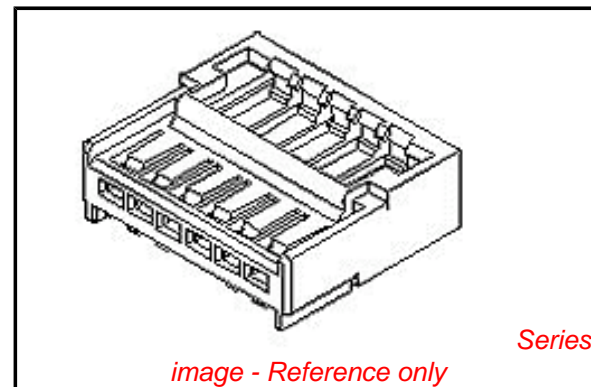

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[51111Series](#)

Mates With

[51112](#) , [51112 With Retainer](#) , [53561](#) , [53730](#)

Use With

[50397](#) , [51113](#)