


TYPES DESCRIPTION

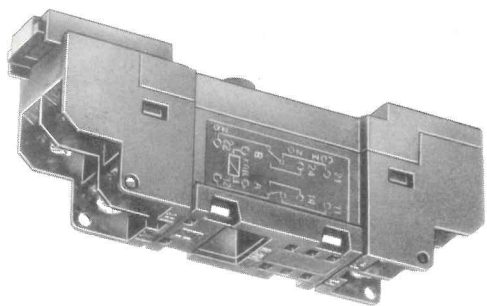

95.45

SCREW TERMINAL SOCKET

Panel or DIN 46277 rail mounting

- TYPE 95.42 For relays type 40.21
- TYPE 95.43 For relays type 40.31
- TYPE 95.45 For relays type 40.51 - 40.52 - 40.61


ACCESSORIES

TYPE 95.51 Retaining clip

CHARACTERISTICS

LOAD : 10A 250 V (5A max. each circuit)
 INSULATION RESISTANCE : $\geq 1,000 M\Omega$
 DIELECTRIC STRENGTH : $\geq 2 KV r.m.s.$
 BODY MATERIAL : Self-extinguishing PPE m glass reinforced
 TERMINALS MATERIAL : Cu Sn 6 Silver plated

Approved by :

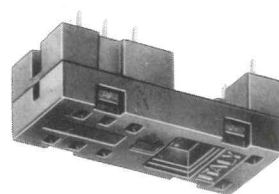

95.15

P.C.B. SOCKET

- TYPE 95.12 For relays type 40.21
- TYPE 95.13 For relays type 40.31
- TYPE 95.15 For relays type 40.51 - 40.52 - 40.61

ACCESSORIES

TYPE 95.51 Retaining clip

CHARACTERISTICS

LOAD : 10A 250 V (5A max. each circuit)
 INSULATION RESISTANCE : $\geq 1,000 M\Omega$
 DIELECTRIC STRENGTH : $\geq 1,5 KV r.m.s.$
 BODY MATERIAL : Self-extinguishing PPE m glass reinforced
 TERMINALS MATERIAL : Cu Sn 6 Tin plated

Approved by :

