

Thin Film Chip Resistor 0805



Features

- Thin Film NiCr resistance element
- Precision tolerance from $\pm 0.1\%$
- Extremely low TCR from ± 5 to ± 50 PPM/ $^{\circ}\text{C}$
- Special packaging 1,000 pcs. / 2,000 pcs. per reel available

Application

Medical equipment
Testing/Measuring equipment
Communication device, cellphone GPS, PDA
Automatic equipment controller
Printer equipment
Converters

Performance Specification

Short Time Overload : $\pm 0.5\%$ Max.
Insulation Resistance : Min. 1,000M Ω
Humidity (Steady State) : $\pm 0.3\%$ Max.
Load Life : $\pm 0.2\%$; $>7\text{k}\Omega$ $\pm 0.5\%$ Max.
Terminal Bending : $\pm 0.2\%$ Max.
Solderability : Min. 95% Coverage
Resistance to Soldering Heat : $\pm 0.2\%$ Max.


Standard

Type	Power Rating at +70 $^{\circ}\text{C}$	Max. Working Voltage	Max. Overload Voltage	T.C.R. PPM/ $^{\circ}\text{C}$	Tolerance %	Resistance Range (Special low)	Resistance Range	Resistance Range (Special High)
MCTC05 0805	1/10W	100V	200V	± 25 ± 50	$\pm 0.1\%$	4.7 Ω to 9.76 Ω	10 Ω to 1M Ω	1.1M Ω to 2M Ω

Thin Film Chip Resistor 0805



Dimension

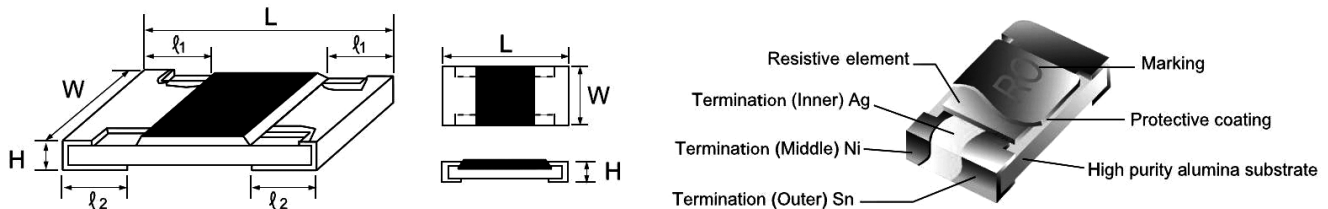

Type	Dimension (mm)				
	L	W	H	ℓ ₁	ℓ ₂
MCTC05 0805	2 ±0.15	1.25 ±0.15	0.55 ±0.1	0.35 ±0.25	0.4 ±0.25

Note:

1) Standard Operating Temp. : -55°C to +155°C

Part Number Table

Description	Part Number
Resistor, 100R, 0805 0.1% 25PPM 100mW	MCTC0525B1000T5E
Resistor, 1K, 0805 0.1% 25PPM 100mW	MCTC0525B1001T5E
Resistor, 10K, 100mW, 0.1%	MCTC0525B1002T5E
Resistor, 100K, 0805 0.1% 25PPM 100mW	MCTC0525B1003T5E
Resistor, 10R, 0805 0.1% 25PPM 100mW	MCTC0525B100JT5E
Resistor, 102R, 0805 0.1% 25PPM 100mW	MCTC0525B1020T5E
Resistor, 1K02, 0805 0.1% 25PPM 100mW	MCTC0525B1021T5E
Resistor, 10K2, 0805 0.1% 25PPM 100mW	MCTC0525B1022T5E
Resistor, 102K, 0805 0.1% 25PPM 100mW	MCTC0525B1023T5E
Resistor, 10R2, 0805 0.1% 25PPM 100mW	MCTC0525B102JT5E
Resistor, 105R, 0805 0.1% 25PPM 100mW	MCTC0525B1050T5E
Resistor, 1K05, 0805 0.1% 25PPM 100mW	MCTC0525B1051T5E
Resistor, 10K5, 0805 0.1% 25PPM 100mW	MCTC0525B1052T5E
Resistor, 105K, 0805 0.1% 25PPM 100mW	MCTC0525B1053T5E
Resistor, 10R5, 0805 0.1% 25PPM 100mW	MCTC0525B105JT5E
Resistor, 107R, 0805 0.1% 25PPM 100mW	MCTC0525B1070T5E
Resistor, 1K07, 0805 0.1% 25PPM 100mW	MCTC0525B1071T5E
Resistor, 10K7, 0805 0.1% 25PPM 100mW	MCTC0525B1072T5E
Resistor, 107K, 0805 0.1% 25PPM 100mW	MCTC0525B1073T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 10R7, 0805 0.1% 25PPM 100mW	MCTC0525B107JT5E
Resistor, 110R, 0805 0.1% 25PPM 100mW	MCTC0525B1100T5E
Resistor, 1K1, 0805 0.1% 25PPM 100mW	MCTC0525B1101T5E
Resistor, 11K, 0805 0.1% 25PPM 100mW	MCTC0525B1102T5E
Resistor, 110K, 0805 0.1% 25PPM 100mW	MCTC0525B1103T5E
Resistor, 11R, 0805 0.1% 25PPM 100mW	MCTC0525B110JT5E
Resistor, 113R, 0805 0.1% 25PPM 100mW	MCTC0525B1130T5E
Resistor, 1K13, 0805 0.1% 25PPM 100mW	MCTC0525B1131T5E
Resistor, 11K3, 0805 0.1% 25PPM 100mW	MCTC0525B1132T5E
Resistor, 113K, 0805 0.1% 25PPM 100mW	MCTC0525B1133T5E
Resistor, 11R3, 0805 0.1% 25PPM 100mW	MCTC0525B113JT5E
Resistor, 115R, 0805 0.1% 25PPM 100mW	MCTC0525B1150T5E
Resistor, 1K15, 0805 0.1% 25PPM 100mW	MCTC0525B1151T5E
Resistor, 11K5, 0805 0.1% 25PPM 100mW	MCTC0525B1152T5E
Resistor, 115K, 0805 0.1% 25PPM 100mW	MCTC0525B1153T5E
Resistor, 11R5, 0805 0.1% 25PPM 100mW	MCTC0525B115JT5E
Resistor, 118R, 0805 0.1% 25PPM 100mW	MCTC0525B1180T5E
Resistor, 1K18, 0805 0.1% 25PPM 100mW	MCTC0525B1181T5E
Resistor, 11K8, 0805 0.1% 25PPM 100mW	MCTC0525B1182T5E
Resistor, 118K, 0805 0.1% 25PPM 100mW	MCTC0525B1183T5E
Resistor, 11R8, 0805 0.1% 25PPM 100mW	MCTC0525B118JT5E
Resistor, 121R, 0805 0.1% 25PPM 100mW	MCTC0525B1210T5E
Resistor, 1K21, 0805 0.1% 25PPM 100mW	MCTC0525B1211T5E
Resistor, 12K1, 0805 0.1% 25PPM 100mW	MCTC0525B1212T5E
Resistor, 121K, 0805 0.1% 25PPM 100mW	MCTC0525B1213T5E
Resistor, 12R1, 0805 0.1% 25PPM 100mW	MCTC0525B121JT5E
Resistor, 124R, 0805 0.1% 25PPM 100mW	MCTC0525B1240T5E
Resistor, 1K24, 0805 0.1% 25PPM 100mW	MCTC0525B1241T5E
Resistor, 12K4, 0805 0.1% 25PPM 100mW	MCTC0525B1242T5E
Resistor, 124K, 0805 0.1% 25PPM 100mW	MCTC0525B1243T5E
Resistor, 12R4, 0805 0.1% 25PPM 100mW	MCTC0525B124JT5E
Resistor, 127R, 0805 0.1% 25PPM 100mW	MCTC0525B1270T5E
Resistor, 1K27, 0805 0.1% 25PPM 100mW	MCTC0525B1271T5E
Resistor, 12K7, 0805 0.1% 25PPM 100mW	MCTC0525B1272T5E
Resistor, 127K, 0805 0.1% 25PPM 100mW	MCTC0525B1273T5E
Resistor, 12R7, 0805 0.1% 25PPM 100mW	MCTC0525B127JT5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 130R, 0805 0.1% 25PPM 100mW	MCTC0525B1300T5E
Resistor, 1K3, 0805 0.1% 25PPM 100mW	MCTC0525B1301T5E
Resistor, 13K, 0805 0.1% 25PPM 100mW	MCTC0525B1302T5E
Resistor, 130K, 0805 0.1% 25PPM 100mW	MCTC0525B1303T5E
Resistor, 13R, 0805 0.1% 25PPM 100mW	MCTC0525B130JT5E
Resistor, 133R, 0805 0.1% 25PPM 100mW	MCTC0525B1330T5E
Resistor, 1K33, 0805 0.1% 25PPM 100mW	MCTC0525B1331T5E
Resistor, 13K3, 0805 0.1% 25PPM 100mW	MCTC0525B1332T5E
Resistor, 133K, 0805 0.1% 25PPM 100mW	MCTC0525B1333T5E
Resistor, 13R3, 0805 0.1% 25PPM 100mW	MCTC0525B133JT5E
Resistor, 137R, 0805 0.1% 25PPM 100mW	MCTC0525B1370T5E
Resistor, 1K37, 0805 0.1% 25PPM 100mW	MCTC0525B1371T5E
Resistor, 13K7, 0805 0.1% 25PPM 100mW	MCTC0525B1372T5E
Resistor, 137K, 0805 0.1% 25PPM 100mW	MCTC0525B1373T5E
Resistor, 13R7, 0805 0.1% 25PPM 100mW	MCTC0525B137JT5E
Resistor, 140R, 0805 0.1% 25PPM 100mW	MCTC0525B1400T5E
Resistor, 1K4, 0805 0.1% 25PPM 100mW	MCTC0525B1401T5E
Resistor, 14K, 0805 0.1% 25PPM 100mW	MCTC0525B1402T5E
Resistor, 140K, 0805 0.1% 25PPM 100mW	MCTC0525B1403T5E
Resistor, 14R, 0805 0.1% 25PPM 100mW	MCTC0525B140JT5E
Resistor, 143R, 0805 0.1% 25PPM 100mW	MCTC0525B1430T5E
Resistor, 1K43, 0805 0.1% 25PPM 100mW	MCTC0525B1431T5E
Resistor, 14K3, 0805 0.1% 25PPM 100mW	MCTC0525B1432T5E
Resistor, 143K, 0805 0.1% 25PPM 100mW	MCTC0525B1433T5E
Resistor, 14R3, 0805 0.1% 25PPM 100mW	MCTC0525B143JT5E
Resistor, 147R, 0805 0.1% 25PPM 100mW	MCTC0525B1470T5E
Resistor, 1K47, 0805 0.1% 25PPM 100mW	MCTC0525B1471T5E
Resistor, 14K7, 0805 0.1% 25PPM 100mW	MCTC0525B1472T5E
Resistor, 147K, 0805 0.1% 25PPM 100mW	MCTC0525B1473T5E
Resistor, 14R7, 0805 0.1% 25PPM 100mW	MCTC0525B147JT5E
Resistor, 150R, 0805 0.1% 25PPM 100mW	MCTC0525B1500T5E
Resistor, 1K5, 0805 0.1% 25PPM 100mW	MCTC0525B1501T5E
Resistor, 15K, 0805 0.1% 25PPM 100mW	MCTC0525B1502T5E
Resistor, 150K, 0805 0.1% 25PPM 100mW	MCTC0525B1503T5E
Resistor, 15R, 0805 0.1% 25PPM 100mW	MCTC0525B150JT5E
Resistor, 154R, 0805 0.1% 25PPM 100mW	MCTC0525B1540T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 1K54, 0805 0.1% 25PPM 100mW	MCTC0525B1541T5E
Resistor, 15K4, 0805 0.1% 25PPM 100mW	MCTC0525B1542T5E
Resistor, 154K, 0805 0.1% 25PPM 100mW	MCTC0525B1543T5E
Resistor, 15R4, 0805 0.1% 25PPM 100mW	MCTC0525B154JT5E
Resistor, 158R, 0805 0.1% 25PPM 100mW	MCTC0525B1580T5E
Resistor, 1K58, 0805 0.1% 25PPM 100mW	MCTC0525B1581T5E
Resistor, 15K8, 0805 0.1% 25PPM 100mW	MCTC0525B1582T5E
Resistor, 158K, 0805 0.1% 25PPM 100mW	MCTC0525B1583T5E
Resistor, 15R8, 0805 0.1% 25PPM 100mW	MCTC0525B158JT5E
Resistor, 162R, 0805 0.1% 25PPM 100mW	MCTC0525B1620T5E
Resistor, 1K62, 0805 0.1% 25PPM 100mW	MCTC0525B1621T5E
Resistor, 16K2, 0805 0.1% 25PPM 100mW	MCTC0525B1622T5E
Resistor, 162K, 0805 0.1% 25PPM 100mW	MCTC0525B1623T5E
Resistor, 16R2, 0805 0.1% 25PPM 100mW	MCTC0525B162JT5E
Resistor, 165R, 0805 0.1% 25PPM 100mW	MCTC0525B1650T5E
Resistor, 1K65, 0805 0.1% 25PPM 100mW	MCTC0525B1651T5E
Resistor, 16K5, 0805 0.1% 25PPM 100mW	MCTC0525B1652T5E
Resistor, 165K, 0805 0.1% 25PPM 100mW	MCTC0525B1653T5E
Resistor, 16R5, 0805 0.1% 25PPM 100mW	MCTC0525B165JT5E
Resistor, 169R, 0805 0.1% 25PPM 100mW	MCTC0525B1690T5E
Resistor, 1K69, 0805 0.1% 25PPM 100mW	MCTC0525B1691T5E
Resistor, 16K9, 0805 0.1% 25PPM 100mW	MCTC0525B1692T5E
Resistor, 169K, 0805 0.1% 25PPM 100mW	MCTC0525B1693T5E
Resistor, 16R9, 0805 0.1% 25PPM 100mW	MCTC0525B169JT5E
Resistor, 174R, 0805 0.1% 25PPM 100mW	MCTC0525B1740T5E
Resistor, 1K74, 0805 0.1% 25PPM 100mW	MCTC0525B1741T5E
Resistor, 17K4, 0805 0.1% 25PPM 100mW	MCTC0525B1742T5E
Resistor, 174K, 0805 0.1% 25PPM 100mW	MCTC0525B1743T5E
Resistor, 17R4, 0805 0.1% 25PPM 100mW	MCTC0525B174JT5E
Resistor, 178R, 0805 0.1% 25PPM 100mW	MCTC0525B1780T5E
Resistor, 1K78, 0805 0.1% 25PPM 100mW	MCTC0525B1781T5E
Resistor, 17K8, 0805 0.1% 25PPM 100mW	MCTC0525B1782T5E
Resistor, 178K, 0805 0.1% 25PPM 100mW	MCTC0525B1783T5E
Resistor, 17R8, 0805 0.1% 25PPM 100mW	MCTC0525B178JT5E
Resistor, 182R, 0805 0.1% 25PPM 100mW	MCTC0525B1820T5E
Resistor, 1K82, 0805 0.1% 25PPM 100mW	MCTC0525B1821T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 18K2, 0805 0.1% 25PPM 100mW	MCTC0525B1822T5E
Resistor, 182K, 0805 0.1% 25PPM 100mW	MCTC0525B1823T5E
Resistor, 18R2, 0805 0.1% 25PPM 100mW	MCTC0525B182JT5E
Resistor, 187R, 0805 0.1% 25PPM 100mW	MCTC0525B1870T5E
Resistor, 1K87, 0805 0.1% 25PPM 100mW	MCTC0525B1871T5E
Resistor, 18K7, 0805 0.1% 25PPM 100mW	MCTC0525B1872T5E
Resistor, 187K, 0805 0.1% 25PPM 100mW	MCTC0525B1873T5E
Resistor, 18R7, 0805 0.1% 25PPM 100mW	MCTC0525B187JT5E
Resistor, 1K91, 0805 0.1% 25PPM 100mW	MCTC0525B1911T5E
Resistor, 19K1, 0805 0.1% 25PPM 100mW	MCTC0525B1912T5E
Resistor, 191K, 0805 0.1% 25PPM 100mW	MCTC0525B1913T5E
Resistor, 191R, 0805 0.1% 25PPM 100mW	MCTC0525B191ET5E
Resistor, 19R1, 0805 0.1% 25PPM 100mW	MCTC0525B191JT5E
Resistor, 196R, 0805 0.1% 25PPM 100mW	MCTC0525B1960T5E
Resistor, 1K96, 0805 0.1% 25PPM 100mW	MCTC0525B1961T5E
Resistor, 19K6, 0805 0.1% 25PPM 100mW	MCTC0525B1962T5E
Resistor, 196K, 0805 0.1% 25PPM 100mW	MCTC0525B1963T5E
Resistor, 19R6, 0805 0.1% 25PPM 100mW	MCTC0525B196JT5E
Resistor, 200R, 0805 0.1% 25PPM 100mW	MCTC0525B2000T5E
Resistor, 2K, 0805 0.1% 25PPM 100mW	MCTC0525B2001T5E
Resistor, 20K, 0805 0.1% 25PPM 100mW	MCTC0525B2002T5E
Resistor, 200K, 0805 0.1% 25PPM 100mW	MCTC0525B2003T5E
Resistor, 20R, 0805 0.1% 25PPM 100mW	MCTC0525B200JT5E
Resistor, 205R, 0805 0.1% 25PPM 100mW	MCTC0525B2050T5E
Resistor, 2K05, 0805 0.1% 25PPM 100mW	MCTC0525B2051T5E
Resistor, 20K5, 0805 0.1% 25PPM 100mW	MCTC0525B2052T5E
Resistor, 205K, 0805 0.1% 25PPM 100mW	MCTC0525B2053T5E
Resistor, 20R5, 0805 0.1% 25PPM 100mW	MCTC0525B205JT5E
Resistor, 210R, 0805 0.1% 25PPM 100mW	MCTC0525B2100T5E
Resistor, 2K1, 0805 0.1% 25PPM 100mW	MCTC0525B2101T5E
Resistor, 21K, 0805 0.1% 25PPM 100mW	MCTC0525B2102T5E
Resistor, 210K, 0805 0.1% 25PPM 100mW	MCTC0525B2103T5E
Resistor, 21R, 0805 0.1% 25PPM 100mW	MCTC0525B210JT5E
Resistor, 215R, 0805 0.1% 25PPM 100mW	MCTC0525B2150T5E
Resistor, 2K15, 0805 0.1% 25PPM 100mW	MCTC0525B2151T5E
Resistor, 21K5, 0805 0.1% 25PPM 100mW	MCTC0525B2152T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 215K, 0805 0.1% 25PPM 100mW	MCTC0525B2153T5E
Resistor, 21R5, 0805 0.1% 25PPM 100mW	MCTC0525B215JT5E
Resistor, 221R, 0805 0.1% 25PPM 100mW	MCTC0525B2210T5E
Resistor, 2K21, 0805 0.1% 25PPM 100mW	MCTC0525B2211T5E
Resistor, 22K1, 0805 0.1% 25PPM 100mW	MCTC0525B2212T5E
Resistor, 221K, 0805 0.1% 25PPM 100mW	MCTC0525B2213T5E
Resistor, 22R1, 0805 0.1% 25PPM 100mW	MCTC0525B221JT5E
Resistor, 226R, 0805 0.1% 25PPM 100mW	MCTC0525B2260T5E
Resistor, 2K26, 0805 0.1% 25PPM 100mW	MCTC0525B2261T5E
Resistor, 22K6, 0805 0.1% 25PPM 100mW	MCTC0525B2262T5E
Resistor, 226K, 0805 0.1% 25PPM 100mW	MCTC0525B2263T5E
Resistor, 22R6, 0805 0.1% 25PPM 100mW	MCTC0525B226JT5E
Resistor, 232R, 0805 0.1% 25PPM 100mW	MCTC0525B2320T5E
Resistor, 2K32, 0805 0.1% 25PPM 100mW	MCTC0525B2321T5E
Resistor, 23K2, 0805 0.1% 25PPM 100mW	MCTC0525B2322T5E
Resistor, 232K, 0805 0.1% 25PPM 100mW	MCTC0525B2323T5E
Resistor, 23R2, 0805 0.1% 25PPM 100mW	MCTC0525B232JT5E
Resistor, 237R, 0805 0.1% 25PPM 100mW	MCTC0525B2370T5E
Resistor, 2K37, 0805 0.1% 25PPM 100mW	MCTC0525B2371T5E
Resistor, 23K7, 0805 0.1% 25PPM 100mW	MCTC0525B2372T5E
Resistor, 237K, 0805 0.1% 25PPM 100mW	MCTC0525B2373T5E
Resistor, 23R7, 0805 0.1% 25PPM 100mW	MCTC0525B237JT5E
Resistor, 243R, 0805 0.1% 25PPM 100mW	MCTC0525B2430T5E
Resistor, 2K43, 0805 0.1% 25PPM 100mW	MCTC0525B2431T5E
Resistor, 24K3, 0805 0.1% 25PPM 100mW	MCTC0525B2432T5E
Resistor, 243K, 0805 0.1% 25PPM 100mW	MCTC0525B2433T5E
Resistor, 24R3, 0805 0.1% 25PPM 100mW	MCTC0525B243JT5E
Resistor, 249R, 0805 0.1% 25PPM 100mW	MCTC0525B2490T5E
Resistor, 2K49, 0805 0.1% 25PPM 100mW	MCTC0525B2491T5E
Resistor, 24K9, 0805 0.1% 25PPM 100mW	MCTC0525B2492T5E
Resistor, 249K, 0805 0.1% 25PPM 100mW	MCTC0525B2493T5E
Resistor, 24R9, 0805 0.1% 25PPM 100mW	MCTC0525B249JT5E
Resistor, 255R, 0805 0.1% 25PPM 100mW	MCTC0525B2550T5E
Resistor, 2K55, 0805 0.1% 25PPM 100mW	MCTC0525B2551T5E
Resistor, 25K5, 0805 0.1% 25PPM 100mW	MCTC0525B2552T5E
Resistor, 255K, 0805 0.1% 25PPM 100mW	MCTC0525B2553T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 25R5, 0805 0.1% 25PPM 100mW	MCTC0525B255JT5E
Resistor, 261R, 0805 0.1% 25PPM 100mW	MCTC0525B2610T5E
Resistor, 2K61, 0805 0.1% 25PPM 100mW	MCTC0525B2611T5E
Resistor, 26K1, 0805 0.1% 25PPM 100mW	MCTC0525B2612T5E
Resistor, 261K, 0805 0.1% 25PPM 100mW	MCTC0525B2613T5E
Resistor, 26R1, 0805 0.1% 25PPM 100mW	MCTC0525B261JT5E
Resistor, 267R, 0805 0.1% 25PPM 100mW	MCTC0525B2670T5E
Resistor, 2K67, 0805 0.1% 25PPM 100mW	MCTC0525B2671T5E
Resistor, 26K7, 0805 0.1% 25PPM 100mW	MCTC0525B2672T5E
Resistor, 267K, 0805 0.1% 25PPM 100mW	MCTC0525B2673T5E
Resistor, 26R7, 0805 0.1% 25PPM 100mW	MCTC0525B267JT5E
Resistor, 274R, 0805 0.1% 25PPM 100mW	MCTC0525B2740T5E
Resistor, 2K74, 0805 0.1% 25PPM 100mW	MCTC0525B2741T5E
Resistor, 27K4, 0805 0.1% 25PPM 100mW	MCTC0525B2742T5E
Resistor, 274K, 0805 0.1% 25PPM 100mW	MCTC0525B2743T5E
Resistor, 27R4, 0805 0.1% 25PPM 100mW	MCTC0525B274JT5E
Resistor, 280R, 0805 0.1% 25PPM 100mW	MCTC0525B2800T5E
Resistor, 2K8, 0805 0.1% 25PPM 100mW	MCTC0525B2801T5E
Resistor, 28K, 0805 0.1% 25PPM 100mW	MCTC0525B2802T5E
Resistor, 280K, 0805 0.1% 25PPM 100mW	MCTC0525B2803T5E
Resistor, 28R, 0805 0.1% 25PPM 100mW	MCTC0525B280JT5E
Resistor, 287R, 0805 0.1% 25PPM 100mW	MCTC0525B2870T5E
Resistor, 2K87, 0805 0.1% 25PPM 100mW	MCTC0525B2871T5E
Resistor, 28K7, 0805 0.1% 25PPM 100mW	MCTC0525B2872T5E
Resistor, 287K, 0805 0.1% 25PPM 100mW	MCTC0525B2873T5E
Resistor, 28R7, 0805 0.1% 25PPM 100mW	MCTC0525B287JT5E
Resistor, 294R, 0805 0.1% 25PPM 100mW	MCTC0525B2940T5E
Resistor, 2K94, 0805 0.1% 25PPM 100mW	MCTC0525B2941T5E
Resistor, 29K4, 0805 0.1% 25PPM 100mW	MCTC0525B2942T5E
Resistor, 294K, 0805 0.1% 25PPM 100mW	MCTC0525B2943T5E
Resistor, 29R4, 0805 0.1% 25PPM 100mW	MCTC0525B294JT5E
Resistor, 301R, 0805 0.1% 25PPM 100mW	MCTC0525B3010T5E
Resistor, 3K01, 0805 0.1% 25PPM 100mW	MCTC0525B3011T5E
Resistor, 30K1, 0805 0.1% 25PPM 100mW	MCTC0525B3012T5E
Resistor, 301K, 0805 0.1% 25PPM 100mW	MCTC0525B3013T5E
Resistor, 30R1, 0805 0.1% 25PPM 100mW	MCTC0525B301JT5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 3K09, 0805 0.1% 25PPM 100mW	MCTC0525B3091T5E
Resistor, 30K9, 0805 0.1% 25PPM 100mW	MCTC0525B3092T5E
Resistor, 309K, 0805 0.1% 25PPM 100mW	MCTC0525B3093T5E
Resistor, 309R, 0805 0.1% 25PPM 100mW	MCTC0525B309ET5E
Resistor, 30R9, 0805 0.1% 25PPM 100mW	MCTC0525B309JT5E
Resistor, 316R, 0805 0.1% 25PPM 100mW	MCTC0525B3160T5E
Resistor, 3K16, 0805 0.1% 25PPM 100mW	MCTC0525B3161T5E
Resistor, 31K6, 0805 0.1% 25PPM 100mW	MCTC0525B3162T5E
Resistor, 316K, 0805 0.1% 25PPM 100mW	MCTC0525B3163T5E
Resistor, 31R6, 0805 0.1% 25PPM 100mW	MCTC0525B316JT5E
Resistor, 324R, 0805 0.1% 25PPM 100mW	MCTC0525B3240T5E
Resistor, 3K24, 0805 0.1% 25PPM 100mW	MCTC0525B3241T5E
Resistor, 32K4, 0805 0.1% 25PPM 100mW	MCTC0525B3242T5E
Resistor, 324K, 0805 0.1% 25PPM 100mW	MCTC0525B3243T5E
Resistor, 32R4, 0805 0.1% 25PPM 100mW	MCTC0525B324JT5E
Resistor, 332R, 0805 0.1% 25PPM 100mW	MCTC0525B3320T5E
Resistor, 3K32, 0805 0.1% 25PPM 100mW	MCTC0525B3321T5E
Resistor, 33K2, 0805 0.1% 25PPM 100mW	MCTC0525B3322T5E
Resistor, 332K, 0805 0.1% 25PPM 100mW	MCTC0525B3323T5E
Resistor, 33R2, 0805 0.1% 25PPM 100mW	MCTC0525B332JT5E
Resistor, 340R, 0805 0.1% 25PPM 100mW	MCTC0525B3400T5E
Resistor, 3K4, 0805 0.1% 25PPM 100mW	MCTC0525B3401T5E
Resistor, 34K, 0805 0.1% 25PPM 100mW	MCTC0525B3402T5E
Resistor, 340K, 0805 0.1% 25PPM 100mW	MCTC0525B3403T5E
Resistor, 34R, 0805 0.1% 25PPM 100mW	MCTC0525B340JT5E
Resistor, 348R, 0805 0.1% 25PPM 100mW	MCTC0525B3480T5E
Resistor, 34K8, 0805 0.1% 25PPM 100mW	MCTC0525B3482T5E
Resistor, 348K, 0805 0.1% 25PPM 100mW	MCTC0525B3483T5E
Resistor, 34R8, 0805 0.1% 25PPM 100mW	MCTC0525B348JT5E
Resistor, 357R, 0805 0.1% 25PPM 100mW	MCTC0525B3570T5E
Resistor, 3K57, 0805 0.1% 25PPM 100mW	MCTC0525B3571T5E
Resistor, 35K7, 0805 0.1% 25PPM 100mW	MCTC0525B3572T5E
Resistor, 357K, 0805 0.1% 25PPM 100mW	MCTC0525B3573T5E
Resistor, 35R7, 0805 0.1% 25PPM 100mW	MCTC0525B357JT5E
Resistor, 365R, 0805 0.1% 25PPM 100mW	MCTC0525B3650T5E
Resistor, 3K65, 0805 0.1% 25PPM 100mW	MCTC0525B3651T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 36K5, 0805 0.1% 25PPM 100mW	MCTC0525B3652T5E
Resistor, 365K, 0805 0.1% 25PPM 100mW	MCTC0525B3653T5E
Resistor, 36R5, 0805 0.1% 25PPM 100mW	MCTC0525B365JT5E
Resistor, 374R, 0805 0.1% 25PPM 100mW	MCTC0525B3740T5E
Resistor, 3K74, 0805 0.1% 25PPM 100mW	MCTC0525B3741T5E
Resistor, 37K4, 0805 0.1% 25PPM 100mW	MCTC0525B3742T5E
Resistor, 374K, 0805 0.1% 25PPM 100mW	MCTC0525B3743T5E
Resistor, 37R4, 0805 0.1% 25PPM 100mW	MCTC0525B374JT5E
Resistor, 383R, 0805 0.1% 25PPM 100mW	MCTC0525B3830T5E
Resistor, 3K83, 0805 0.1% 25PPM 100mW	MCTC0525B3831T5E
Resistor, 38K3, 0805 0.1% 25PPM 100mW	MCTC0525B3832T5E
Resistor, 383K, 0805 0.1% 25PPM 100mW	MCTC0525B3833T5E
Resistor, 38R3, 0805 0.1% 25PPM 100mW	MCTC0525B383JT5E
Resistor, 392R, 0805 0.1% 25PPM 100mW	MCTC0525B3920T5E
Resistor, 3K92, 0805 0.1% 25PPM 100mW	MCTC0525B3921T5E
Resistor, 39K2, 0805 0.1% 25PPM 100mW	MCTC0525B3922T5E
Resistor, 392K, 0805 0.1% 25PPM 100mW	MCTC0525B3923T5E
Resistor, 39R2, 0805 0.1% 25PPM 100mW	MCTC0525B392JT5E
Resistor, 402R, 0805 0.1% 25PPM 100mW	MCTC0525B4020T5E
Resistor, 4K02, 0805 0.1% 25PPM 100mW	MCTC0525B4021T5E
Resistor, 40K2, 0805 0.1% 25PPM 100mW	MCTC0525B4022T5E
Resistor, 402K, 0805 0.1% 25PPM 100mW	MCTC0525B4023T5E
Resistor, 40R2, 0805 0.1% 25PPM 100mW	MCTC0525B402JT5E
Resistor, 412R, 0805 0.1% 25PPM 100mW	MCTC0525B4120T5E
Resistor, 4K12, 0805 0.1% 25PPM 100mW	MCTC0525B4121T5E
Resistor, 41K2, 0805 0.1% 25PPM 100mW	MCTC0525B4122T5E
Resistor, 412K, 0805 0.1% 25PPM 100mW	MCTC0525B4123T5E
Resistor, 41R2, 0805 0.1% 25PPM 100mW	MCTC0525B412JT5E
Resistor, 422R, 0805 0.1% 25PPM 100mW	MCTC0525B4220T5E
Resistor, 4K22, 0805 0.1% 25PPM 100mW	MCTC0525B4221T5E
Resistor, 42K2, 0805 0.1% 25PPM 100mW	MCTC0525B4222T5E
Resistor, 42R2, 0805 0.1% 25PPM 100mW	MCTC0525B422JT5E
Resistor, 432R, 0805 0.1% 25PPM 100mW	MCTC0525B4320T5E
Resistor, 4K32, 0805 0.1% 25PPM 100mW	MCTC0525B4321T5E
Resistor, 43K2, 0805 0.1% 25PPM 100mW	MCTC0525B4322T5E
Resistor, 432K, 0805 0.1% 25PPM 100mW	MCTC0525B4323T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 43R2, 0805 0.1% 25PPM 100mW	MCTC0525B432JT5E
Resistor, 442R, 0805 0.1% 25PPM 100mW	MCTC0525B4420T5E
Resistor, 4K42, 0805 0.1% 25PPM 100mW	MCTC0525B4421T5E
Resistor, 44K2, 0805 0.1% 25PPM 100mW	MCTC0525B4422T5E
Resistor, 442K, 0805 0.1% 25PPM 100mW	MCTC0525B4423T5E
Resistor, 44R2, 0805 0.1% 25PPM 100mW	MCTC0525B442JT5E
Resistor, 453R, 0805 0.1% 25PPM 100mW	MCTC0525B4530T5E
Resistor, 4K53, 0805 0.1% 25PPM 100mW	MCTC0525B4531T5E
Resistor, 45K3, 0805 0.1% 25PPM 100mW	MCTC0525B4532T5E
Resistor, 453K, 0805 0.1% 25PPM 100mW	MCTC0525B4533T5E
Resistor, 45R3, 0805 0.1% 25PPM 100mW	MCTC0525B453JT5E
Resistor, 464R, 0805 0.1% 25PPM 100mW	MCTC0525B4640T5E
Resistor, 4K64, 0805 0.1% 25PPM 100mW	MCTC0525B4641T5E
Resistor, 46K4, 0805 0.1% 25PPM 100mW	MCTC0525B4642T5E
Resistor, 464K, 0805 0.1% 25PPM 100mW	MCTC0525B4643T5E
Resistor, 46R4, 0805 0.1% 25PPM 100mW	MCTC0525B464JT5E
Resistor, 475R, 0805 0.1% 25PPM 100mW	MCTC0525B4750T5E
Resistor, 4K75, 0805 0.1% 25PPM 100mW	MCTC0525B4751T5E
Resistor, 47K5, 0805 0.1% 25PPM 100mW	MCTC0525B4752T5E
Resistor, 475K, 0805 0.1% 25PPM 100mW	MCTC0525B4753T5E
Resistor, 47R5, 0805 0.1% 25PPM 100mW	MCTC0525B475JT5E
Resistor, 487R, 0805 0.1% 25PPM 100mW	MCTC0525B4870T5E
Resistor, 4K87, 0805 0.1% 25PPM 100mW	MCTC0525B4871T5E
Resistor, 48K7, 0805 0.1% 25PPM 100mW	MCTC0525B4872T5E
Resistor, 487K, 0805 0.1% 25PPM 100mW	MCTC0525B4873T5E
Resistor, 48R7, 0805 0.1% 25PPM 100mW	MCTC0525B487JT5E
Resistor, 499R, 0805 0.1% 25PPM 100mW	MCTC0525B4990T5E
Resistor, 4K99, 0805 0.1% 25PPM 100mW	MCTC0525B4991T5E
Resistor, 49K9, 0805 0.1% 25PPM 100mW	MCTC0525B4992T5E
Resistor, 499K, 0805 0.1% 25PPM 100mW	MCTC0525B4993T5E
Resistor, 49R9, 0805 0.1% 25PPM 100mW	MCTC0525B499JT5E
Resistor, 511R, 0805 0.1% 25PPM 100mW	MCTC0525B5110T5E
Resistor, 5K11, 0805 0.1% 25PPM 100mW	MCTC0525B5111T5E
Resistor, 51K1, 0805 0.1% 25PPM 100mW	MCTC0525B5112T5E
Resistor, 511K, 0805 0.1% 25PPM 100mW	MCTC0525B5113T5E
Resistor, 51R1, 0805 0.1% 25PPM 100mW	MCTC0525B511JT5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 523R, 0805 0.1% 25PPM 100mW	MCTC0525B5230T5E
Resistor, 5K23, 0805 0.1% 25PPM 100mW	MCTC0525B5231T5E
Resistor, 52K3, 0805 0.1% 25PPM 100mW	MCTC0525B5232T5E
Resistor, 523K, 0805 0.1% 25PPM 100mW	MCTC0525B5233T5E
Resistor, 52R3, 0805 0.1% 25PPM 100mW	MCTC0525B523JT5E
Resistor, 536R, 0805 0.1% 25PPM 100mW	MCTC0525B5360T5E
Resistor, 5K36, 0805 0.1% 25PPM 100mW	MCTC0525B5361T5E
Resistor, 53K6, 0805 0.1% 25PPM 100mW	MCTC0525B5362T5E
Resistor, 536K, 0805 0.1% 25PPM 100mW	MCTC0525B5363T5E
Resistor, 53R6, 0805 0.1% 25PPM 100mW	MCTC0525B536JT5E
Resistor, 549R, 0805 0.1% 25PPM 100mW	MCTC0525B5490T5E
Resistor, 5K49, 0805 0.1% 25PPM 100mW	MCTC0525B5491T5E
Resistor, 54K9, 0805 0.1% 25PPM 100mW	MCTC0525B5492T5E
Resistor, 549K, 0805 0.1% 25PPM 100mW	MCTC0525B5493T5E
Resistor, 54R9, 0805 0.1% 25PPM 100mW	MCTC0525B549JT5E
Resistor, 562R, 0805 0.1% 25PPM 100mW	MCTC0525B5620T5E
Resistor, 5K62, 0805 0.1% 25PPM 100mW	MCTC0525B5621T5E
Resistor, 56K2, 0805 0.1% 25PPM 100mW	MCTC0525B5622T5E
Resistor, 562K, 0805 0.1% 25PPM 100mW	MCTC0525B5623T5E
Resistor, 56R2, 0805 0.1% 25PPM 100mW	MCTC0525B562JT5E
Resistor, 576R, 0805 0.1% 25PPM 100mW	MCTC0525B5760T5E
Resistor, 5K76, 0805 0.1% 25PPM 100mW	MCTC0525B5761T5E
Resistor, 57K6, 0805 0.1% 25PPM 100mW	MCTC0525B5762T5E
Resistor, 576K, 0805 0.1% 25PPM 100mW	MCTC0525B5763T5E
Resistor, 57R6, 0805 0.1% 25PPM 100mW	MCTC0525B576JT5E
Resistor, 590R, 0805 0.1% 25PPM 100mW	MCTC0525B5900T5E
Resistor, 5K9, 0805 0.1% 25PPM 100mW	MCTC0525B5901T5E
Resistor, 59K, 0805 0.1% 25PPM 100mW	MCTC0525B5902T5E
Resistor, 590K, 0805 0.1% 25PPM 100mW	MCTC0525B5903T5E
Resistor, 59R, 0805 0.1% 25PPM 100mW	MCTC0525B590JT5E
Resistor, 604R, 0805 0.1% 25PPM 100mW	MCTC0525B6040T5E
Resistor, 6K04, 0805 0.1% 25PPM 100mW	MCTC0525B6041T5E
Resistor, 60K4, 0805 0.1% 25PPM 100mW	MCTC0525B6042T5E
Resistor, 604K, 0805 0.1% 25PPM 100mW	MCTC0525B6043T5E
Resistor, 60R4, 0805 0.1% 25PPM 100mW	MCTC0525B604JT5E
Resistor, 619R, 0805 0.1% 25PPM 100mW	MCTC0525B6190T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 6K19, 0805 0.1% 25PPM 100mW	MCTC0525B6191T5E
Resistor, 61K9, 0805 0.1% 25PPM 100mW	MCTC0525B6192T5E
Resistor, 619K, 0805 0.1% 25PPM 100mW	MCTC0525B6193T5E
Resistor, 61R9, 0805 0.1% 25PPM 100mW	MCTC0525B619JT5E
Resistor, 634R, 0805 0.1% 25PPM 100mW	MCTC0525B6340T5E
Resistor, 6K34, 0805 0.1% 25PPM 100mW	MCTC0525B6341T5E
Resistor, 63K4, 0805 0.1% 25PPM 100mW	MCTC0525B6342T5E
Resistor, 634K, 0805 0.1% 25PPM 100mW	MCTC0525B6343T5E
Resistor, 63R4, 0805 0.1% 25PPM 100mW	MCTC0525B634JT5E
Resistor, 649R, 0805 0.1% 25PPM 100mW	MCTC0525B6490T5E
Resistor, 6K49, 0805 0.1% 25PPM 100mW	MCTC0525B6491T5E
Resistor, 64K9, 0805 0.1% 25PPM 100mW	MCTC0525B6492T5E
Resistor, 649K, 0805 0.1% 25PPM 100mW	MCTC0525B6493T5E
Resistor, 64R9, 0805 0.1% 25PPM 100mW	MCTC0525B649JT5E
Resistor, 665R, 0805 0.1% 25PPM 100mW	MCTC0525B6650T5E
Resistor, 6K65, 0805 0.1% 25PPM 100mW	MCTC0525B6651T5E
Resistor, 66K5, 0805 0.1% 25PPM 100mW	MCTC0525B6652T5E
Resistor, 665K, 0805 0.1% 25PPM 100mW	MCTC0525B6653T5E
Resistor, 66R5, 0805 0.1% 25PPM 100mW	MCTC0525B665JT5E
Resistor, 681R, 0805 0.1% 25PPM 100mW	MCTC0525B6810T5E
Resistor, 6K81, 0805 0.1% 25PPM 100mW	MCTC0525B6811T5E
Resistor, 68K1, 0805 0.1% 25PPM 100mW	MCTC0525B6812T5E
Resistor, 681K, 0805 0.1% 25PPM 100mW	MCTC0525B6813T5E
Resistor, 68R1, 0805 0.1% 25PPM 100mW	MCTC0525B681JT5E
Resistor, 698R, 0805 0.1% 25PPM 100mW	MCTC0525B6980T5E
Resistor, 6K98, 0805 0.1% 25PPM 100mW	MCTC0525B6981T5E
Resistor, 69K8, 0805 0.1% 25PPM 100mW	MCTC0525B6982T5E
Resistor, 698K, 0805 0.1% 25PPM 100mW	MCTC0525B6983T5E
Resistor, 69R8, 0805 0.1% 25PPM 100mW	MCTC0525B698JT5E
Resistor, 715R, 0805 0.1% 25PPM 100mW	MCTC0525B7150T5E
Resistor, 7K15, 0805 0.1% 25PPM 100mW	MCTC0525B7151T5E
Resistor, 71K5, 0805 0.1% 25PPM 100mW	MCTC0525B7152T5E
Resistor, 715K, 0805 0.1% 25PPM 100mW	MCTC0525B7153T5E
Resistor, 71R5, 0805 0.1% 25PPM 100mW	MCTC0525B715JT5E
Resistor, 732R, 0805 0.1% 25PPM 100mW	MCTC0525B7320T5E
Resistor, 7K32, 0805 0.1% 25PPM 100mW	MCTC0525B7321T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 73K2, 0805 0.1% 25PPM 100mW	MCTC0525B7322T5E
Resistor, 732K, 0805 0.1% 25PPM 100mW	MCTC0525B7323T5E
Resistor, 73R2, 0805 0.1% 25PPM 100mW	MCTC0525B732JT5E
Resistor, 750R, 0805 0.1% 25PPM 100mW	MCTC0525B7500T5E
Resistor, 7K5, 0805 0.1% 25PPM 100mW	MCTC0525B7501T5E
Resistor, 75K, 0805 0.1% 25PPM 100mW	MCTC0525B7502T5E
Resistor, 750K, 0805 0.1% 25PPM 100mW	MCTC0525B7503T5E
Resistor, 75R, 0805 0.1% 25PPM 100mW	MCTC0525B750JT5E
Resistor, 768R, 0805 0.1% 25PPM 100mW	MCTC0525B7680T5E
Resistor, 7K68, 0805 0.1% 25PPM 100mW	MCTC0525B7681T5E
Resistor, 76K8, 0805 0.1% 25PPM 100mW	MCTC0525B7682T5E
Resistor, 768K, 0805 0.1% 25PPM 100mW	MCTC0525B7683T5E
Resistor, 76R8, 0805 0.1% 25PPM 100mW	MCTC0525B768JT5E
Resistor, 787R, 0805 0.1% 25PPM 100mW	MCTC0525B7870T5E
Resistor, 7K87, 0805 0.1% 25PPM 100mW	MCTC0525B7871T5E
Resistor, 78K7, 0805 0.1% 25PPM 100mW	MCTC0525B7872T5E
Resistor, 787K, 0805 0.1% 25PPM 100mW	MCTC0525B7873T5E
Resistor, 78R7, 0805 0.1% 25PPM 100mW	MCTC0525B787JT5E
Resistor, 806R, 0805 0.1% 25PPM 100mW	MCTC0525B8060T5E
Resistor, 8K06, 0805 0.1% 25PPM 100mW	MCTC0525B8061T5E
Resistor, 80K6, 0805 0.1% 25PPM 100mW	MCTC0525B8062T5E
Resistor, 806K, 0805 0.1% 25PPM 100mW	MCTC0525B8063T5E
Resistor, 80R6, 0805 0.1% 25PPM 100mW	MCTC0525B806JT5E
Resistor, 825R, 0805 0.1% 25PPM 100mW	MCTC0525B8250T5E
Resistor, 8K25, 0805 0.1% 25PPM 100mW	MCTC0525B8251T5E
Resistor, 82K5, 0805 0.1% 25PPM 100mW	MCTC0525B8252T5E
Resistor, 825K, 0805 0.1% 25PPM 100mW	MCTC0525B8253T5E
Resistor, 82R5, 0805 0.1% 25PPM 100mW	MCTC0525B825JT5E
Resistor, 845R, 0805 0.1% 25PPM 100mW	MCTC0525B8450T5E
Resistor, 8K45, 0805 0.1% 25PPM 100mW	MCTC0525B8451T5E
Resistor, 84K5, 0805 0.1% 25PPM 100mW	MCTC0525B8452T5E
Resistor, 845K, 0805 0.1% 25PPM 100mW	MCTC0525B8453T5E
Resistor, 84R5, 0805 0.1% 25PPM 100mW	MCTC0525B845JT5E
Resistor, 866R, 0805 0.1% 25PPM 100mW	MCTC0525B8660T5E
Resistor, 8K66, 0805 0.1% 25PPM 100mW	MCTC0525B8661T5E
Resistor, 86K6, 0805 0.1% 25PPM 100mW	MCTC0525B8662T5E
Resistor, 866K, 0805 0.1% 25PPM 100mW	MCTC0525B8663T5E

Thin Film Chip Resistor 0805



Description	Part Number
Resistor, 86R6, 0805 0.1% 25PPM 100mW	MCTC0525B866JT5E
Resistor, 887R, 0805 0.1% 25PPM 100mW	MCTC0525B8870T5E
Resistor, 8K87, 0805 0.1% 25PPM 100mW	MCTC0525B8871T5E
Resistor, 88K7, 0805 0.1% 25PPM 100mW	MCTC0525B8872T5E
Resistor, 887K, 0805 0.1% 25PPM 100mW	MCTC0525B8873T5E
Resistor, 88R7, 0805 0.1% 25PPM 100mW	MCTC0525B887JT5E
Resistor, 909R, 0805 0.1% 25PPM 100mW	MCTC0525B9090T5E
Resistor, 9K09, 0805 0.1% 25PPM 100mW	MCTC0525B9091T5E
Resistor, 90K9, 0805 0.1% 25PPM 100mW	MCTC0525B9092T5E
Resistor, 909K, 0805 0.1% 25PPM 100mW	MCTC0525B9093T5E
Resistor, 90R9, 0805 0.1% 25PPM 100mW	MCTC0525B909JT5E
Resistor, 931R, 0805 0.1% 25PPM 100mW	MCTC0525B9310T5E
Resistor, 9K31, 0805 0.1% 25PPM 100mW	MCTC0525B9311T5E
Resistor, 93K1, 0805 0.1% 25PPM 100mW	MCTC0525B9312T5E
Resistor, 931K, 0805 0.1% 25PPM 100mW	MCTC0525B9313T5E
Resistor, 93R1, 0805 0.1% 25PPM 100mW	MCTC0525B931JT5E
Resistor, 953R, 0805 0.1% 25PPM 100mW	MCTC0525B9530T5E
Resistor, 9K53, 0805 0.1% 25PPM 100mW	MCTC0525B9531T5E
Resistor, 95K3, 0805 0.1% 25PPM 100mW	MCTC0525B9532T5E
Resistor, 953K, 0805 0.1% 25PPM 100mW	MCTC0525B9533T5E
Resistor, 95R3, 0805 0.1% 25PPM 100mW	MCTC0525B953JT5E
Resistor, 976R, 0805 0.1% 25PPM 100mW	MCTC0525B9760T5E
Resistor, 9K76, 0805 0.1% 25PPM 100mW	MCTC0525B9761T5E
Resistor, 97K6, 0805 0.1% 25PPM 100mW	MCTC0525B9762T5E
Resistor, 976K, 0805 0.1% 25PPM 100mW	MCTC0525B9763T5E
Resistor, 97R6, 0805 0.1% 25PPM 100mW	MCTC0525B976JT5E

Important Notice : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp is the registered trademark of the Group. © Premier Farnell plc 2012.