


PRODUCT DATA SHEET

Type	Size	Rating	Description	Part No.
Incandescent	T6	14V 0.08A	T-1¼ Bead Seal Lamp	2182BS

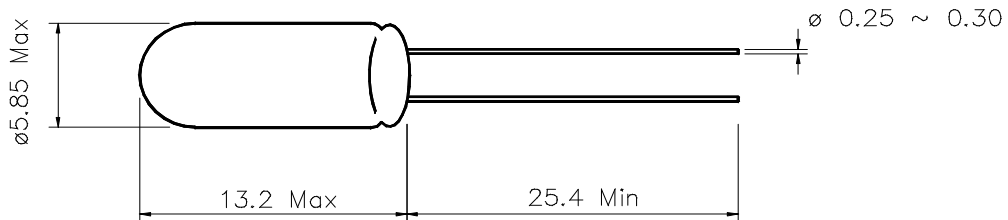

Drawing Not To Scale
All Dimensions In mm

PHOTOMETRY DATA

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE (Hours)
	Min.	Nom.	Max.	Min.	Nom.	Max.	
14.0	72	80	88	2.8	3.8	4.8	15,000

NOTES:

- 1) C-2F filament shape.
- 2) Lead wires 0.25mm diameter x 25.4mm MIN. long, with tinned finish.
- 3) Other lead wire lengths to be supplied according to the purchase order.

Issue No.	Date	C.N. No.	Drawn	Tech	QA	M & P	Sales
1	08/01/98		NR				