

Epson Expression Home XP-205



DATASHEET



The Epson Expression Home XP-205 is part of the Small-in-One range - Epson's smallest ever range of all-in-one home inkjets. This printer, scanner and copier offers cost-effective printing for home users who are looking for the added benefit of Wi-Fi connectivity as well as mobile printing.

The Epson Expression Home XP-205 comes with Epson Connect¹, offering even more flexibility and freedom. It allows users to quickly and easily print documents and photos wirelessly from smartphones and tablet PCs. Additionally, users can print from anywhere in the world by emailing documents and photos directly to the printer.

The XP-205 is Apple AirPrint ready and makes it simple to print emails, photos, web pages and documents directly from iOS devices².

Meanwhile, Google Cloud Print is also supported and allows users to print on the go from a smartphone or computer.


The automatic Wi-Fi set-up³ makes configuring laptops and computers to print and scan wirelessly extremely easy. Users don't need to know their network settings or connect with a USB cable, the XP-205 automatically finds the relevant connection settings in order to configure itself.

Epson's new, Claria Home Ink is ideal for affordable reliable printing, producing crisp, clear text documents and glossy, lab-quality photos. With individual ink cartridges you only have to replace the colour used, saving you money.

Claria Home Ink cartridges are available in standard and XL sizes, with page yields displayed clearly on each pack. Identifying the right ink cartridge for your printer couldn't be simpler – just look out for the Daisy image.

KEY FEATURES

- Save space, save money, save time
- Mobile printing over Wi-Fi and email
- Easy to connect wirelessly
- Only replace the colour used
- Crisp, clear text and glossy photos

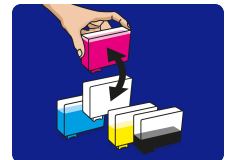

PRODUCT SPECIFICATIONS

TECHNOLOGY

Printing Method	Epson Micro Piezo™ print head
Minimum Droplet Size	3 pl, With Variable-Sized Droplet Technology
Ink Technology	Epson Claria™ Home Ink
Printing Resolution	5,760 x 1,440 dpi

PRINT

Printing Speed ISO/IEC 24734	6.2 Pages/min Monochrome, 3.1 Pages/min Color
Draft printing speed	30 Pages/min Monochrome (plain paper 75 g/m ²), 54 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper)
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

SCAN

Scanning Resolution	1,200 dpi x 2,400 dpi (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

PAPER / MEDIA HANDLING

Number of paper trays	1
Paper Formats	A4, A5, A6, B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter Legal, 9 x 13 cm, 10 x 15 cm, 13 x 18 cm, 13 x 20 cm, 20 x 25 cm, 100 x 148 mm, 16:9
Duplex	Manual
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets

GENERAL

Energy Use	ENERGY STAR® qualified all-in-one, 12 W (standalone copying, ISO/IEC 24712 pattern), 2.7 W (sleep mode)
Product dimensions	390 x 300 x 145 mm (Width x Depth x Height)
Product weight	4.1 kg
Noise Level	5.1 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 37 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode
Compatible Operating Systems	Mac OS 10.5.8 or later, Windows 7, Windows Vista, Windows XP, Windows XP x64
Included Software	ABBYY FineReader® Sprint 8.0 (MacOS), ABBYY FineReader® Sprint 9.0 (Windows), Epson Easy Photo Print, Epson Event Manager
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA PSK (AES)
Mobile and Cloud printing services	Epson Connect (iPrint, Email Print, Remote Print Driver), Apple AirPrint, Google Cloud Print services

OTHER

Warranty	12 months Carry in
----------	--------------------

LOGISTICS INFORMATION

SKU	C11CC49301
Barcode	8715946511207
Dimensions Single Carton	464 x 200 x 380 mm
Carton Weight	5.2 Kg
Country of Origin	Indonesia
Pallet Size Euro	40 Units (4 x 10)
Pallet Size Block	60 Units (6 x 10)

Better Products
for a Better Future

<http://eco.epson.com>



For more information please contact:

Telephone: 0871 222 6702 (UK)+
01 436 7742 (Republic of Ireland)

Web: www.epson.co.uk
www.epson.ie

E-mail: enquiries@epson.co.uk
Chat: etalk.epson-europe.com
Fax: 0871 222 6740

+ Calls cost 10p per minute plus network extras.


Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

Epson Expression Home XP-205

WHAT'S IN THE BOX

- Warranty document
- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges

INK CARTRIDGE COMPATIBILITY

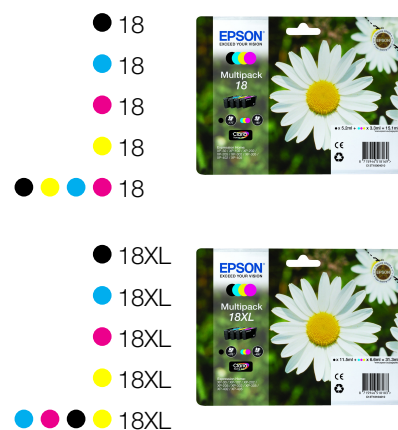

INK YIELD DATA

	18	18XL
Black	175 pages*	470 pages*
Cyan, Magenta, Yellow	180 pages*	450 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. Requires a wireless connection to the internet. For more information, supported languages and supported devices please visit www.epsonconnect.eu
2. iOS 5 and above. AirPrint and the AirPrint logo are trademarks of Apple Inc
3. Automatic set-up compatible with Windows 7, Windows Vista and Mac OS. Initial Wi-Fi set-up requires a USB cable for Windows XP users - not included This printer and original ink cartridges are for sale and use in EMEA only

EPSON®