


**KEMET Part Number: PMR209MB5470M047R30**  
(P409QM473M250AH470)

Capacitor, film, 0.047 uF, +/-20% Tol, -40/+85C, Integrated Resistor (X2), 630V@85C, Lead Spacing=15.2 mm

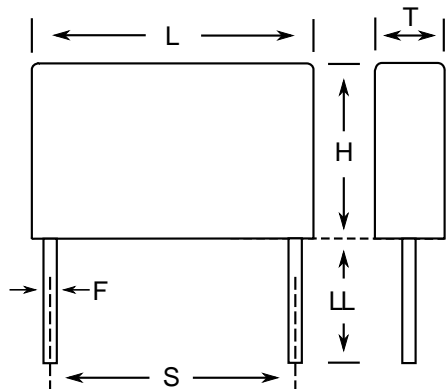

Dimensions (mm)		
Symbol	Dimension	Tolerance
L	18.5	MAX
H	13	MAX
T	7.3	MAX
S	15.2	+/-0.4
LL	30	+5
F	0.8	+/-0.05

Packaging Specifications	
Package Kind:	Bulk
Package Quantity:	400

General Information	
Supplier:	KEMET
Miscellaneous Electrical:	Resistor tol: +/-30%

Specifications	
Capacitance:	0.047 uF
Rated Temperature:	85C
Voltage @ rated temp:	630V
Voltage AC:	250VAC
Tolerance:	+/-20%
Body Type:	Radial Molded
Dielectric:	Metallized Paper
Application:	Integrated Resistor (X2)
Temperature Range:	-40/+85C
Electrical Name (Other):	Resistor
Electrical Value (Other):	47
Electrical Units (Other):	Ohms
Insulation Resistance:	3 GOhm