

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY

MOUNTING HOLE, Ø 0.250"

PART NO.	LENS COLOR	VOLTAGE (DC)	CURRENT [mA]	RATED LIFE HOURS
LED STANDARD SERIES ^[1]				
WL-5100H1	RED	2.0V	20mA	100,000
WL-5100H3	AMBER	2.0V	20mA	100,000
WL-5100H5	GREEN	2.2V	20mA	100,000
WL-5100H6	BLUE ^[4]	3.4V	20mA	100,000
WL-5100H7	YELLOW	2.1V	20mA	100,000
LED 5V SERIES ^[2]				
WL-5102H1-5V	RED	5V-6V	10mA	100,000
WL-5102H3-5V	AMBER	5V-6V	10mA	100,000
WL-5102H5-5V	GREEN	5V-6V	10mA	100,000
WL-5102H6-5V	BLUE ^[4]	5V-6V	10mA	100,000
WL-5102H7-5V	YELLOW	5V-6V	10mA	100,000
LED 12V SERIES ^[2]				
WL-5102H1-12V	RED	12V-14V	10mA	100,000
WL-5102H3-12V	AMBER	12V-14V	10mA	100,000
WL-5102H5-12V	GREEN	12V-14V	10mA	100,000
WL-5102H6-12V	BLUE ^[4]	12V-14V	10mA	100,000
WL-5102H7-12V	YELLOW	12V-14V	10mA	100,000
LED 24V SERIES ^[2]				
WL-5102H1-24V	RED	24V-28V	10mA	100,000
WL-5102H3-24V	AMBER	24V-28V	10mA	100,000
WL-5102H5-24V	GREEN	24V-28V	10mA	100,000
WL-5102H6-24V	BLUE ^[4]	24V-28V	10mA	100,000
WL-5102H7-24V	YELLOW	24V-28V	10mA	100,000

NOTES


1. External series resistor required
2. Due to small size, voltages greater than 2V the appropriate external resistor will be installed in the lead
3. Diffused lens with wide viewing angle standard
4. Blue LED has water clear lens
5. 6" leads with 1/2" strip are standard
6. Storage temperature
 T_{STG} : -25°C - +80°C
7. Ambient temperature
 T_A : -20°C - +60°C
8. Voltage tolerance
 V_{OP} : $\pm 10\%$
9. Body material
Nylon, black
10. Wire gauge
24 AWG
11. Wire strip
1/2"
12. Anode (+)
Red lead

CERTIFICATIONS

RoHS

RoHS
COMPLIANT

DIMENSIONAL CHARACTERISTICS

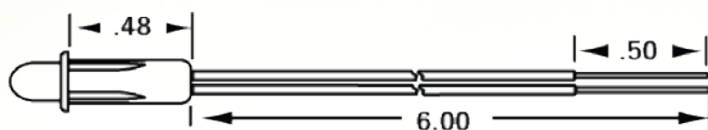

unless otherwise specified, all dimensions are in inches



OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

