

Turned contacts turned crimp male contact for wire gauge 16 - 15.copy.copy.copy.copy

Part No. VN02 040 0012 1C

Series Contacts

Subseries Contact Turned contacts




COMMON CHARACTERISTICS		
Contact diameter		4 mm
Wire gauge from		4
Wire gauge (AWG) from		12
Packaging / supplied as		Single contact
No. of pieces		100
Sex of Contact		Socket
Type of contact		Turned crimp contact
ELECTRICAL CHARACTERISTICS		
Contact resistance	DIN EN 60512-2-1, Test 2a / IEC 60512-2-1, Test 2a	0 m

Turned contacts turned crimp male contact for wire gauge 16 - 15.copy.copy.copy.copy

Part No. VN02 040 0012 1C

Series Contacts

Subseries Contact Turned contacts

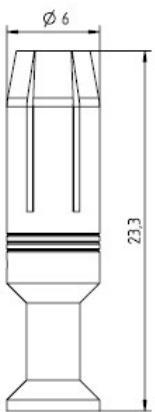

26.06.2013

Drawing Dimensions in mm (Inch)



Turned contacts turned crimp male contact for wire gauge 16 - 15.copy.copy.copy.copy

Part No. VN02 040 0012 1C

Series Contacts

Subseries Contact Turned contacts



Contact arrangement