


Item no.: 2092-1406  
 Product description: 6 POLE PIN SPACING 5 MM / 0.197 IN

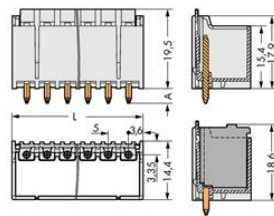

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	light gray
pole count	6
Height	19.5 mm
Height	0.768 in
Width	32.2 mm
Width	1.268 in
Depth	14.4 mm
Depth	0.567 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Solder pin width, diam. [mm]	1.4 mm

Material group  
Customs Tariff No.

I  
85366990

© WAGO Kontakttechnik GmbH & Co. KG  
Specifications are subject to changes and errors may be expected