
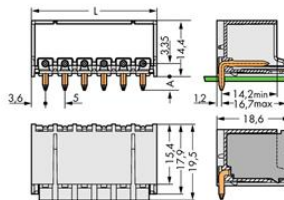


Item no.: 2092-1432
Product description: 12 POLE PIN SPACING 5 MM / 0.197 IN

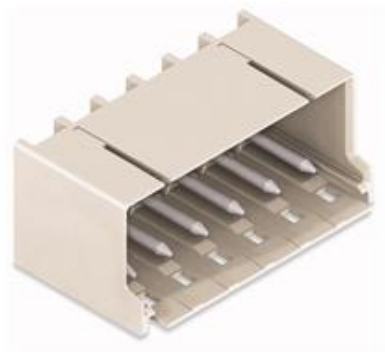

Produkt kann von Bild abweichen / product may differ

RoHS compliant

Color	light gray
pole count	12
Height	14.4 mm
Height	0.567 in
Width	62.2 mm
Width	2.449 in
Depth	19.5 mm
Depth	0.768 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Solder pin width, diam. [mm]	1.4 mm

Material group
Customs Tariff No.

I
85366990

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected