


RJ-11 Flat-Satin Telephone Cable, 4-Wire, Crossed-Pinning, 25-ft. (7.6-m)

MFG Part Number: EL04M-25

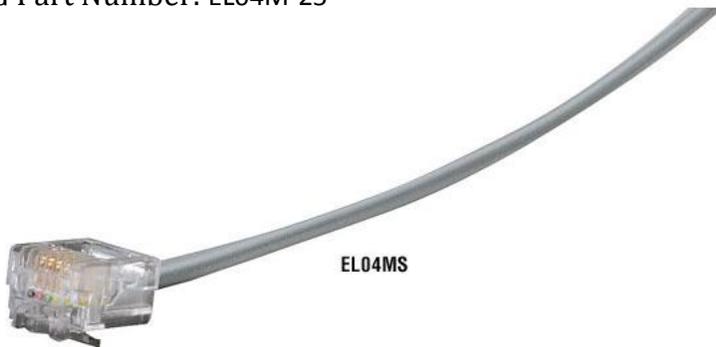

Description

RJ-11 Flat-Satin Telephone Cable, 4-Wire, Crossed-Pinning, 25-ft. (7.6-m)

Quick Facts

- High-quality flat-satin cable for data and voice applications.
- For typical telephone use.
- Stranded conductor.
- Guaranteed for life!

Further Details

- All-purpose cables are for voice and data applications running up to 1 Mbps.
- Not recommended for Token Ring or Ethernet applications.

Technical Specifications for RJ-11 Flat-Satin Telephone Cable, 4-Wire, Crossed-Pinning, 25-ft. (7.6-m):

Cable Construction — Gray flat satin, PVC

Conductor Gauge — 28 AWG

Distance (Maximum) — As per equipment specifications

Mutual Capacitance — 22 pF/ft.

Resistance — 45 ohms/1000 ft.

Connectors — 4-wire

NOTE: The 4-Wire Cable (EL04M, Cross-Pinning) is for typical telephone use.

NOTE: 6-wire versions also available.