


RJ-45 Modular Cable, 6-Wire, Straight-Pinning, 7-ft. (2.1-m)

MFG Part Number: EL08MS-07

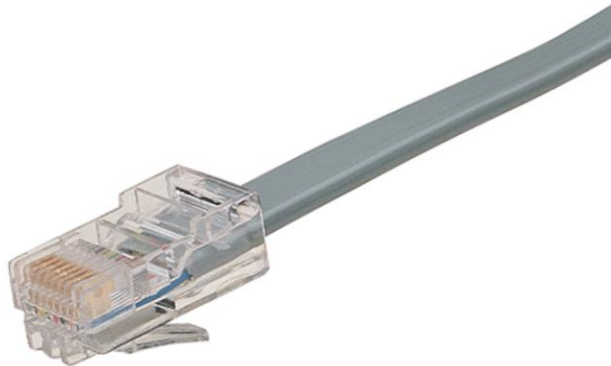

Description

RJ-45 Modular Cable, 8-Wire, Straight-Pinning, 7-ft. (2.1-m)

Quick Facts

- All-purpose flat-satin cable for voice and data applications running up to 1 Mbps.
- Stranded conductor.
- Guaranteed for life!

Further Details

- Not recommended for Token Ring or Ethernet applications.

Technical Specifications for RJ-45 Modular Cable, 7-ft. (2.1-m):

Cable Construction — Gray flat satin, PVC

Conductor Gauge — 28 AWG

Distance (Maximum) — As per equipment specifications

Mutual Capacitance — 22 pF/ft.

Resistance — 45 ohms/1000 ft.

Connectors — 8-wire