


**HEADER STRAIGHT SOLDER PIN, 1X1 MM / 0.039X 0.039 IN 10 POLE PIN  
SPACING 7.62 MM / 0.3 IN WITH CLOSED END MATING DIRECTION  
PERPENDICULAR TO PCB**

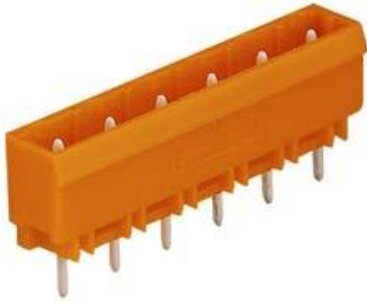

Technical data: 231-740/001-000

Product group	3 (Multi Conn. System)
Weight	4 g
Color	orange
pole count	10
Height	12 mm
Height	0.472 in
Width	76.58 mm
Width	3.015 in
Depth	8.4 mm
Depth	0.331 in
Pin spacing from	7.62 mm
Pin spacing from	0.3 in
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	6 kV
Current intensity EN	12 A
Pollution degree	2
Measured voltage EN	1000 V
Measured shock voltage	6 kV
Current intensity EN	12 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated