




ANSI Standard Quick Wire Sockets



'Easy 'jab-in' connection'

- Standard in-line quick wire socket allowing rapid termination of wires
- Easy 'jab-in' connection, just push-in wire & tighten screw
- Accepts standard round plug pins
- Available in Thermocouple types K, J, T
- For Types K, J, T contacts are made from true Thermocouple alloys
- Contacts are polarised to prevent incorrect connection
- Colour coded in accordance with ANSI specification
- Maximum continuous temperature 220 deg°C

T/C Type	Colour Code (ANSI)	+Positive (alloy type)	-Negative (alloy type)	Labfacility Code	Farnell order Code
K	Yellow	+Nickel Chromium	-Nickel Alloy	AS-K-MQ	234-7153
J	Black	+Iron	-Copper Nickel	AS-J-MQ	234-7152
T	Blue	+Copper	-Copper Nickel	AS-T-MQ	234-7154

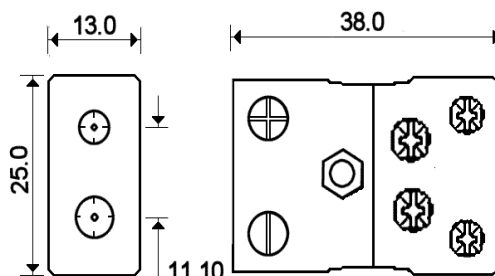

FAR043/0613 ANSI Standard Quick Wire Sockets

About Labfacility

Formed in 1971, Labfacility specialize in the field of Temperature and Process Measurement.

We are the largest UK manufacturer of both temperature sensors and thermocouple connectors

Quality & Service

Quality and Service are key elements in the continued growth of Labfacility.

Technical support is always freely available from our experienced technical sales teams and the company has ISO9001 accreditation.

Contact Details

Email
sales@labfacility.com

Website
www.labfacility.com