


KEMET Part Number: C340C683J1G5TA
(C340C683J1G5TA)



Capacitor, ceramic, 0.068 uF, +/-5% Tol, 100V, C0G, Lead Spacing=0.2"

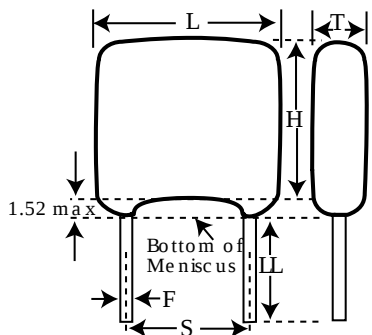

Dimensions (in)		
Symbol	Dimension	Tolerance
L	0.4	MAX
H	0.46	MAX
T	0.15	MAX
S	0.2	+/-0.03
LL	0.276	MIN
F	0.02	+0.004/-0.001
K	0.02	

Notes:
-Rated voltage
-TC/Dielectric

General Information	
Supplier:	KEMET

Specifications	
Capacitance:	0.068 uF
Lead Spacing:	0.2"
Voltage:	100V
Temperature Coefficient:	C0G
Tolerance:	+/-5%
Application:	Commercial Standard
Temperature Range:	-55/+125C
Body Type:	Radial Conformal (Dipped)
Lead Type:	pcleads
Lead Form:	Straight
Termination Type:	Tin (Sn)

Packaging Specifications	
Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	100