


CIRCUIT BOARD HARDWARE

MDLSP1/MDLSP2 Metric Mini Dual Locking Support Post




MDLSP1 (Fig. 1)		MDLSP2 (Fig. 2)			Standard Pack: 1000/Bag
Material: Nylon 6/6, RMS-01 Color: Natural	Material: UL94 V0 Nylon 6/6, RMS-19 Color: Natural	Material: Nylon 6/6, RMS-01 Color: Natural	Material: Nylon 6/6, RMS-01 Color: Black	Material: UL94 V0 Nylon 6/6, RMS-19 Color: Natural	"A" Standoff Height
MDLSP1-02M-01	MDLSP1-02M-19	MDLSP2-02M-01	MDLSP2-02M-01BK	MDLSP2-02M-19	2
MDLSP1-03M-01	MDLSP1-03M-19	MDLSP2-03M-01	MDLSP2-03M-01BK	MDLSP2-03M-19	3
MDLSP1-04M-01	MDLSP1-04M-19	MDLSP2-04M-01	MDLSP2-04M-01BK	MDLSP2-04M-19	4
MDLSP1-05M-01	MDLSP1-05M-19	MDLSP2-05M-01	MDLSP2-05M-01BK	MDLSP2-05M-19	5
MDLSP1-06M-01	MDLSP1-06M-19	MDLSP2-06M-01	MDLSP2-06M-01BK	MDLSP2-06M-19	6
MDLSP1-07M-01	MDLSP1-07M-19	MDLSP2-07M-01	MDLSP2-07M-01BK	MDLSP2-07M-19	7
MDLSP1-08M-01	MDLSP1-08M-19	MDLSP2-08M-01	MDLSP2-08M-01BK	MDLSP2-08M-19	8
MDLSP1-09M-01	MDLSP1-09M-19	MDLSP2-09M-01	MDLSP2-09M-01BK	MDLSP2-09M-19	9
MDLSP1-10M-01	MDLSP1-10M-19	MDLSP2-10M-01	MDLSP2-10M-01BK	MDLSP2-10M-19	10
MDLSP1-12M-01	MDLSP1-12M-19	MDLSP2-12M-01	MDLSP2-12M-01BK	MDLSP2-12M-19	12
MDLSP1-14M-01	MDLSP1-14M-19	MDLSP2-14M-01	MDLSP2-14M-01BK	MDLSP2-14M-19	14
MDLSP1-16M-01	MDLSP1-16M-19	MDLSP2-16M-01	MDLSP2-16M-01BK	MDLSP2-16M-19	16
MDLSP1-18M-01	MDLSP1-18M-19	MDLSP2-18M-01	MDLSP2-18M-01BK	MDLSP2-18M-19	18
MDLSP1-20M-01	MDLSP1-20M-19	MDLSP2-20M-01	MDLSP2-20M-01BK	MDLSP2-20M-19	20
MDLSP1-22M-01	MDLSP1-22M-19	MDLSP2-22M-01	MDLSP2-22M-01BK	MDLSP2-22M-19	22

Top Hole: Snap-lock: 2.5 ± 0.05
Panel Thickness: 1.65 Max.

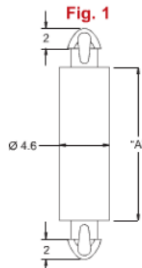

Bottom Hole: Snap-lock: 2.5 ± 0.05
Panel Thickness: 1.65 Max.

Top Hole: Snap-lock: 3.5 ± 0.05
Panel Thickness: 1.65 Max.

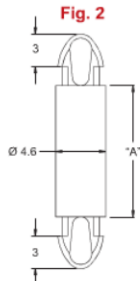


Bottom Hole: Snap-lock: 3.5 ± 0.05
Panel Thickness: 1.65 Max.

MDLSPK Metric Mini Dual Locking Support Post




MDLSPK1 (Fig. 1)		MDLSPK2 (Fig. 2)		Standard Pack: 1000/Bag
Material: Nylon 6/6, RMS-01 Color: Natural	Material: UL94 V0 Nylon 6/6, RMS-19 Color: Natural	Material: Nylon 6/6, RMS-01m Color: Natural	Material: UL94 V0 Nylon 6/6, RMS-19 Color: Natural	"A" Standoff Height
MDLSPK1-02M-01	MDLSPK1-02M-19	MDLSPK2-02M-01	MDLSPK2-02M-19	2
MDLSPK1-03M-01	MDLSPK1-03M-19	MDLSPK2-03M-01	MDLSPK2-03M-19	3
MDLSPK1-04M-01	MDLSPK1-04M-19	MDLSPK2-04M-01	MDLSPK2-04M-19	4
MDLSPK1-06M-01	MDLSPK1-06M-19	MDLSPK2-06M-01	MDLSPK2-06M-19	6
MDLSPK1-08M-01	MDLSPK1-08M-19	MDLSPK2-08M-01	MDLSPK2-08M-19	8
MDLSPK1-10M-01	MDLSPK1-10M-19	MDLSPK2-10M-01	MDLSPK2-10M-19	10
MDLSPK1-12M-01	MDLSPK1-12M-19	MDLSPK2-12M-01	MDLSPK2-12M-19	12
MDLSPK1-14M-01	MDLSPK1-14M-19	MDLSPK2-14M-01	MDLSPK2-14M-19	14
MDLSPK1-16M-01	MDLSPK1-16M-19	MDLSPK2-16M-01	MDLSPK2-16M-19	16
MDLSPK1-18M-01	MDLSPK1-18M-19	MDLSPK2-18M-01	MDLSPK2-18M-19	18
MDLSPK1-20M-01	MDLSPK1-20M-19	MDLSPK2-20M-01	MDLSPK2-20M-19	20
MDLSPK1-22M-01	MDLSPK1-22M-19	MDLSPK2-22M-01	MDLSPK2-22M-19	22

Top Hole: Snap-lock: 2.5 ± 0.05
Panel Thickness: 3.6 Max.

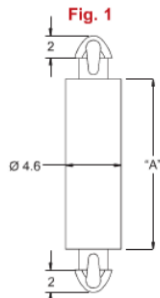

Bottom Hole: Snap-lock: 2.5 ± 0.05
Panel Thickness: 1.6 Max.

Top Hole: Snap-lock: 3.5 ± 0.05
Panel Thickness: 3.6 Max.

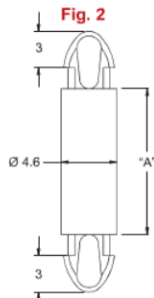

Bottom Hole: Snap-lock: 3.5 ± 0.05
Panel Thickness: 1.6 Max.