



FFB.1S.405.CLAC52

MECHANICAL DETAILS

Shell Style Model FFB* : Straight plug
cable collet and safety locking
ring


Keying Circular (can rotate), plug has
male contact(s)

Housing Material Brass (chrome plated) shell and
collet nut, nickel plated brass
latch sleeve and mid pieces

Cable Fixing 4.2 - 5.2 mm

Variant 2 :

	A	L	M	S2
Mm.	12	45	34	8.5
In.	0.47	1.77	1.34	0.33

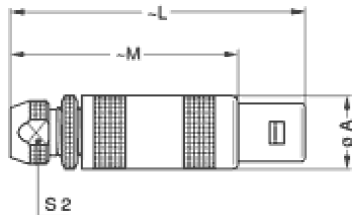

Available Download

[high_voltage.pdf](#)


PERFORMANCE DETAIL

Insert 1S.405 : 1 High Voltage

Insulator L: PEEK

Specifications

Contact Type: Solder

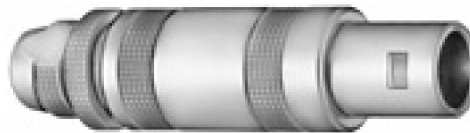

OTHER CHARACTERISTICS

Shell Style/Model Libellé

Temp (min) -55°C

Temp (max) +250°C

Humidity (max): <=95% [at 60 deg C /140 F]

Vibration: 15 g [10 Hz - 2000 Hz]

Shock Resistance: 100 g [6 ms]

Salt Spray >144 hr

Climatical 50/175/21

Shielding (min): 75 dB (10 MHz)

Shielding (min): 40 dB (1 GHz)

IP Rating 50



Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)