



FFB.1S.405.CLAC62

MECHANICAL DETAILS

Shell Style Model FFB* : Straight plug
cable collet and safety locking ring


Keying Circular (can rotate), plug has male contact(s)

Housing Material Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces

Cable Fixing 5.2 - 6.2 mm

Variant 2 :

	A	L	M	S2
Mm.	12	45	34	8.5
In.	0.47	1.77	1.34	0.33

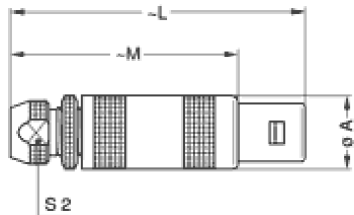


PERFORMANCE DETAIL

Insert 1S.405 : 1 High Voltage

Insulator L: PEEK

Specifications

Contact Type: Solder

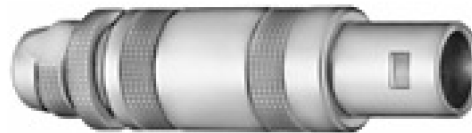

OTHER CHARACTERISTICS

Shell Style/Model Libellé

Temp (min) -55°C

Temp (max) +250°C

Humidity (max): <=95% [at 60 deg C /140 F]

Vibration: 15 g [10 Hz - 2000 Hz]

Shock Resistance: 100 g [6 ms]

Salt Spray >144 hr

Climatical 50/175/21

Shielding (min): 75 dB (10 MHz)

Shielding (min): 40 dB (1 GHz)

IP Rating 50



Available Download

[high_voltage.pdf](#)

Related links

- [Contact](#)
- [Quote Request](#)
- [Catalogs Downloads](#)
- [Catalogs Requests](#)
- [Sample Request](#)
- [3D drawings](#)