


KEMET Part Number: PME271Y422MR30
(P271HE222M250A)

Capacitor, film, 2200 pF, +/-20% Tol, -40/+100C, Safety: Y2, 250VAC, Lead Spacing=10.2 mm

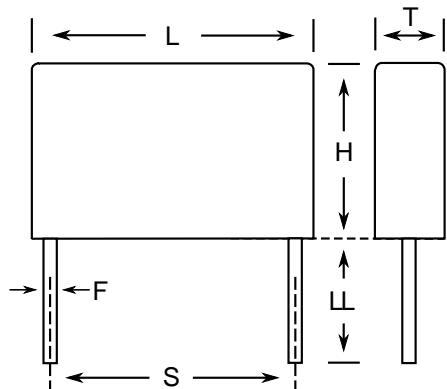

Dimensions (mm)

Symbol	Dimension	Tolerance
L	13.5	MAX
H	7.5	MAX
T	3.9	MAX
S	10.2	+/-0.4
LL	30	+5
F	0.6	+/-0.05

Packaging Specifications

Package Kind:	Bulk
Package Quantity:	1000

General Information

Supplier:	KEMET
------------------	-------

Specifications

Capacitance:	2200 pF
Rated Temperature:	100° C
Voltage AC:	250VAC
Tolerance:	+/-20%
Body Type:	Radial Molded
Dielectric:	Metallized Paper
Application:	Safety: Y2
Temperature Range:	-40/+100C
Electrical Name (Other):	Self Resonant Frequency
Electrical Value (Other):	37
Electrical Units (Other):	mHz
Dissipation Factor @ 1 kHz:	1.3%
Insulation Resistance:	12 GOhm
Maximum dVdT:	2000v/us

Agency Approvals

Approvals:	ENEC,UL,cUL,CQC
-------------------	-----------------