


DEC1X3J220JC4B

" # " indicates a package specification code.



< List of part numbers with package codes >
DEC1X3J220JC4B

Shape

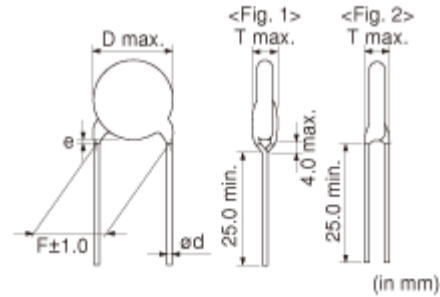

Lead Code	Coating Extension e	ø d	Style
A3	Up to the end of crimp	0.6±0.05	Fig. 1
C4	3.0 max.	0.6±0.05	Fig. 2



- L size or outer diameter D (mm)
- T size
- Lead spacing F
- Lead diameter d
- Paint dripping e

- 9.0 mm max.
- 7.0 mm max.
- 10.0 ± 1.0mm
- 0.6 ± 0.05mm
- 3.0mm max.

Specifications

- Capacitance
- Rated voltage
- Temperature characteristics (complied standard)
- Temperature coefficient
- Temperature range of temperature characteristics
- Operating temperature range

- 22pF ± 5%
- 6300Vdc
- SL(JIS)
- +350 to -1000ppm/
- 20 to 85
- 25 to 85

References

	Packaging	Packing in bulk	Specifications	Minimum quantity
B				250

⚠ Attention

- This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it ' s specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.